


# 8 Port ISA RS-232 Serial Interface with Extended "AT" Interrupts



Model  
OMG-COMM8-A  
**\$439**

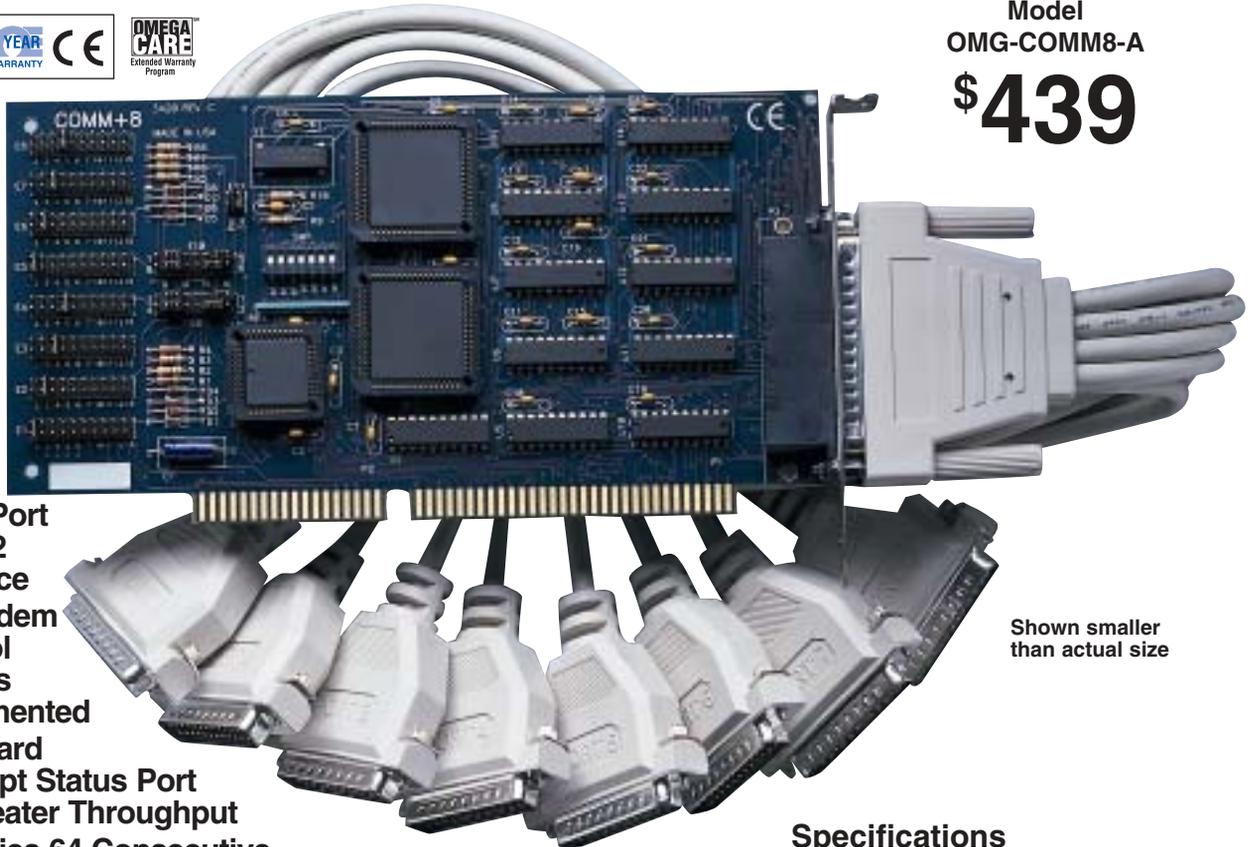

Shown smaller than actual size

- ✓ Eight Port RS-232 Interface
- ✓ All Modem Control Signals Implemented
- ✓ On Board Interrupt Status Port for Greater Throughput
- ✓ Occupies 64 Consecutive I/O Locations User Selectable as: Consecutive with DIP-Switch or Customizable with PAL Option
- ✓ Sharable IRQ Level (2-5, 7, 10-12, and 15)
- ✓ 16654 Buffered UART Standard-Full Array of Advanced UARTS Available
- ✓ Compatible with DOS, WIN 95/98/Me/NT/2000/XP, QNX and Other Operating Systems
- ✓ Includes Software for DOS Interrupt Buffering
- ✓ Windows NT Installation Utility for Simple Set-up
- ✓ Includes DOS Utilities, Windows Advanced COM Driver and Help Files to Simplify Installation

The OMG-COMM8-A provides the PC with eight RS-232 Asynchronous ports for terminals, data collection and other devices. This product includes extended "AT" interrupts, extended address range for UNIX, XENIX and QNX compatibility, and an interrupt status port for greater data throughput. Set each port to a separate interrupt or share a single interrupt across multiple ports under Windows NT.

WIN 95/98/Me/NT/2000/XP drivers are included as well as support for Linux, QNX and DOS. The drivers provide IRQ sharing, advanced UART support and serial diagnostic utilities.

## Specifications

**Communications Chip:** 16654 UART  
**Number of Ports:** eight RS-232  
**Max. Data Rate:** OMG-COMM8-A: 460.8k bps (depends on distance)  
**Max. Data Distance:** up to 50 ft.  
**Operating Temperature:** 0 to 122°F (0 to 50°C)  
**Storage Temperature:** -4 to 158°F (-20 to 70°C)  
**Humidity Range:** 10-90% RH  
**Current Specifications:** +5V @ 200 mA, +12 V @ 115 mA, -12 V @ 165 mA  
**Connector(s):** on board DB-78 to (8) DB-25P; DB-9P connectors optional  
**Physical Dimensions:** 7.0 L x 4.2" H (17.78 x 10.66 cm)

## To Order (Specify Model Number)

Model Number	Price	Description
OMG-COMM8-A	\$439	Eight port RS-232 interface
OMG-COMM8-A-DB9	439	Eight port RS-232 interface with DB-9P Connector
OMG-HICOM/9	99	Driver software for up to 9 Windows 3.1x ports

Comes with complete operator's manual, octopus cable and serial utility disk.

**Ordering Example:** OMG-COMM8-A eight port RS-232 interface and OMEGACARE<sup>SM</sup> 1-year extended warranty (adds 1 year to standard 1-year warranty), \$439 + 43 = \$482.

# omega.co.uk<sup>®</sup>

Your One-Stop Source for Process Measurement and Control!

Freephone 0800 488 488 | International +44(0) 161 777 6622 | Fax +44(0) 161 777 6622 | Sales@omega.co.uk

[www.omega.co.uk](http://www.omega.co.uk)



#### UNITED STATES

[www.omega.com](http://www.omega.com)

1-800-TC-OMEGA  
Stamford, CT.

#### CANADA

[www.omega.ca](http://www.omega.ca)

Laval(Quebec)  
1-800-TC-OMEGA

#### GERMANY

[www.omega.de](http://www.omega.de)

Deckenfronn, Germany  
0800-8266342

#### UNITED KINGDOM

[www.omega.co.uk](http://www.omega.co.uk)

Manchester, England  
0800-488-488  
+44-(0)161-777-6611

#### FRANCE

[www.omega.fr](http://www.omega.fr)

0800-466-342

#### BENELUX

[www.omega.nl](http://www.omega.nl)

0800-099-33-44



## More than 100,000 Products Available!

### • Temperature

Calibrators, Connectors, General Test and Measurement Instruments, Handheld Instruments for Temperature Measurement, Ice Point References, Indicating Labels, Crayons, Cements and Lacquers, Infrared Temperature Measurement Instruments, Recorders, Relative Humidity Measurement Instruments, PT100 Probes, PT100 Elements, Temperature & Process Meters, Timers and Counters, Temperature and Process Controllers and Power Switching Devices, Thermistor Elements, Probes and Assemblies, Thermocouples, Thermowells and Head and Well Assemblies, Transmitters, Thermocouple Wire, RTD Probes

### • Flow and Level

Air Velocity Indicators, Doppler Flowmeters, Level Measurement, Magnetic Flowmeters, Mass Flowmeters, Pitot Tubes, Pumps, Rotameters, Turbine and Paddle Wheel Flowmeters, Ultrasonic Flowmeters, Valves, Variable Area Flowmeters, Vortex Shedding Flowmeters

### • pH and Conductivity

Conductivity Instrumentation, Dissolved Oxygen Instrumentation, Environmental Instrumentation, pH Electrodes and Instruments, Water and Soil Analysis Instrumentation

### • Data Acquisition

Communication Products and Converters, Data Acquisition and Analysis Software, Data Loggers Plug-in Cards, Signal Conditioners, USB, RS232, RS485, Ethernet and Parallel Port Data Acquisition Systems, Wireless Transmitters and Receivers

### • Pressure, Strain and Force

Displacement Transducers, Dynamic Measurement Force Sensors, Instrumentation for Pressure and Strain Measurements, Load Cells, Pressure Gauges, Pressure Reference Section, Pressure Switches, Pressure Transducers, Proximity Transducers, Regulators, Pressure Transmitters, Strain Gauges, Torque Transducers, Valves

### • Heaters

Band Heaters, Cartridge Heaters, Circulation Heaters, Comfort Heaters, Controllers, Meters and Switching Devices, Flexible Heaters, General Test and Measurement Instruments, Heater Hook-up Wire, Heating Cable Systems, Immersion Heaters, Process Air and Duct, Heaters, Radiant Heaters, Strip Heaters, Tubular Heaters