


OMG-VERSACOMM4-EX

Four Port ISA RS-232 Interface for DOS,
Windows 3.1x/95/98/ME/NT/2000/XP and OS/2



\$199
Basic Unit

- ✓ Four Port RS-232 Interface
- ✓ Each Port Designed to Maximize DOS and Windows 3.1x/95/98/ME/NT/2000/XP Communications
- ✓ 16554 Buffered UART std/Full Array of Advanced UARTS Available
- ✓ Supports Standard PC Data Rates and "Quad" Data Rates up to 460.8 Kbps
- ✓ Flexible Address Selection Via Dip-Switch
- ✓ Ten Interrupt Selections Including (3-7, 9-12, and 15)
- ✓ Interrupts Can be Shared or Individually Selected Per Port to Simplify Installation
- ✓ Onboard Interrupt Status Port Provides Efficient Interrupt Sharing
- ✓ Compatible with DOS, Windows 3.1x/95/98/ME/NT/2000/XP and Other Operating Systems
- ✓ Includes DOS Utilities, Windows Advanced COM Drivers and Help Files to Simplify Installation

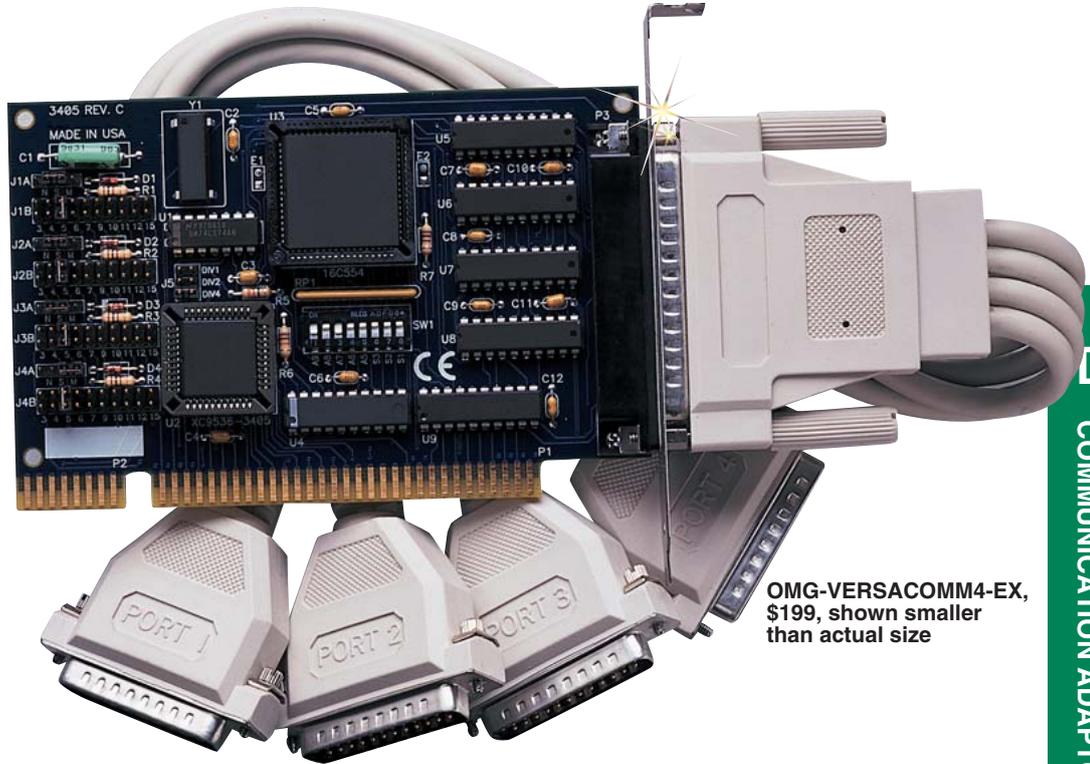

OMG-VERSACOMM4-EX, \$199, shown smaller than actual size

This product features extended interrupt support, individually selectable or sharable interrupts, and an onboard interrupt status port for maximum Windows flexibility.

Windows 95/98/ME/NT/2000/XP drivers are included, as well as support for DOS. The drivers provide IRQ sharing, advanced UART support and serial diagnostic utilities.

Specifications
Communications Chip: 16554 UART
Number of Ports: four RS-232

Max. Data Rate: 460.8 Kbps
Max. Data Distance: up to XX (50')
Operating Temperature: 0 to 50°C (0 to 122°F)
Storage Temperature: -20 to 70°C (-4 to 158°F)
Humidity Range: 10 to 90% RH
Current Specifications: +5V @ 210 mA, ±12V @ 80 mA ea.
Connector(s): DB-37 to (4) DB-25P or DB-37 to (4) DB-9P
Cable Length: 91.44 cm (36")
Dimensions: 5.2 L x 3.4" H (13.21 x 8.64 cm)

ALL MODELS AVAILABLE FOR FAST DELIVERY!

To Order (Specify Model Number)

Model Number	Price	Description
OMG-VERSACOMM4-EX-DB25	\$199	Four port RS-232 interface (DB-25 cable included)
OMG-VERSACOMM4-EX-DB9	199	Four port RS-232 interface (DB-9 cable included)

Comes with complete operator's manual and serial utility disk.

To order with optional 16654 UART, add suffix "-SS" to part number and add \$20 to price.

Ordering Example: **OMG-VERSACOMM4-EX-DB25-SS**, four port RS-232 interface with DB-25 cable and 16654 UART upgrade, and **OMEGACARESM** 1 year extended warranty (adds 1 year to standard 1 year warranty), \$219 + 25 = **\$244.**

The OMG-VERSACOMM4-EX provides the PC with four RS-232 Async links to data collection equipment and other devices.

omega.co.uk[®]

Your One-Stop Source for Process Measurement and Control!

Freephone 0800 488 488 | International +44(0) 161 777 6622 | Fax +44(0) 161 777 6622 | Sales@omega.co.uk

www.omega.co.uk



UNITED STATES

www.omega.com

1-800-TC-OMEGA

Stamford, CT.

CANADA

www.omega.ca

Laval(Quebec)

1-800-TC-OMEGA

GERMANY

www.omega.de

Deckenpfronn, Germany

0800-8266342

UNITED KINGDOM

www.omega.co.uk

Manchester, England

0800-488-488

FRANCE

www.omega.fr

088-466-342

CZECH REPUBLIC

www.omegaeng.cz

Karviná, Czech Republic

596-311-899

BENELUX

www.omega.nl

0800-099-33-44



More than 100,000 Products Available!

• Temperature

Calibrators, Connectors, General Test and Measurement Instruments, Handheld Instruments for Temperature Measurement, Ice Point References, Indicating Labels, Crayons, Cements and Lacquers, Infrared Temperature Measurement Instruments, Recorders, Relative Humidity Measurement Instruments, PT100 Probes, PT100 Elements, Temperature & Process Meters, Timers and Counters, Temperature and Process Controllers and Power Switching Devices, Thermistor Elements, Probes and Assemblies, Thermocouples, Thermowells and Head and Well Assemblies, Transmitters, Thermocouple Wire, RTD Probes

• Flow and Level

Air Velocity Indicators, Doppler Flowmeters, Level Measurement, Magnetic Flowmeters, Mass Flowmeters, Pitot Tubes, Pumps, Rotameters, Turbine and Paddle Wheel Flowmeters, Ultrasonic Flowmeters, Valves, Variable Area Flowmeters, Vortex Shedding Flowmeters

• pH and Conductivity

Conductivity Instrumentation, Dissolved Oxygen Instrumentation, Environmental Instrumentation, pH Electrodes and Instruments, Water and Soil Analysis Instrumentation

• Data Acquisition

Auto-Dialers and Alarm Monitoring Systems, Communication Products and Converters, Data Acquisition and Analysis Software, Data Loggers Plug-in Cards, Signal Conditioners, USB, RS232, RS485 and Parallel Port Data Acquisition Systems, Wireless Transmitters and Receivers

• Pressure, Strain and Force

Displacement Transducers, Dynamic Measurement Force Sensors, Instrumentation for Pressure and Strain Measurements, Load Cells, Pressure Gauges, Pressure Reference Section, Pressure Switches, Pressure Transducers, Proximity Transducers, Regulators, Pressure Transmitters, Strain Gauges, Torque Transducers, Valves

• Heaters

Band Heaters, Cartridge Heaters, Circulation Heaters, Comfort Heaters, Controllers, Meters and Switching Devices, Flexible Heaters, General Test and Measurement Instruments, Heater Hook-up Wire, Heating Cable Systems, Immersion Heaters, Process Air and Duct, Heaters, Radiant Heaters, Strip Heaters, Tubular Heaters