

HIGH PERFORMANCE FAN HEATER

FOR PANEL, DIN RAIL OR FOOT-MOUNT

NEW

CR030/130 Series Starts at \$196



- Compact DIN Rail, Panel Mount or Foot-Mounted Fan Heater
- Maintains Minimum Operating Temperatures in Enclosures
- Helps to Prevent Failure of Electronic Components Caused by Condensation and Corrosion
- Built-In Overheat Protection
- Integrated Adjustable Thermostat or Fixed Hygrostat
- Double Insulated Plastic Housing



CR03003059900, \$196, shown smaller than actual size.



CR13013059900, \$206, shown smaller than actual size.

SPECIFICATIONS

Heating Element: High performance cartridge heater

Heat Sink: Extruded aluminum profile

Overheat Protection: Built-in temperature limiter

Axial Fan (Ball Bearing): Service life 50,000h @ 25°C (77°F)

Air Flow, Free Blowing: 160 m³/h (94 cfm)

Connection: 2-pole terminal AWG 16 max (1.5 mm²) with strain relief, clamping torque 0.8 Nm max

Mounting:

CR030: M5 screws (not included)

CR130: Clip for 35 mm DIN rail, EN 60 715 or M6 screws (not included)

Position: Preferably horizontal

Wiring Compartment: Plastic, UL94V-0, black

Dimensions:

CR030: 168 x 145 x 99 mm (6.6 x 5.7 x 3.9")

CR130: 182 x 160 x 99 mm (7.2 x 6.3 x 3.9")



Weight: 1.4 kg (3.1 lb)

Operating Temperature: 0 to 60°C (32 to 140°F)

Storage Temperature: -45 to 70°C (-49 to 158°F)

Protection Class: II (double isolated)

Protection Type: NEMA 2 (IP20)

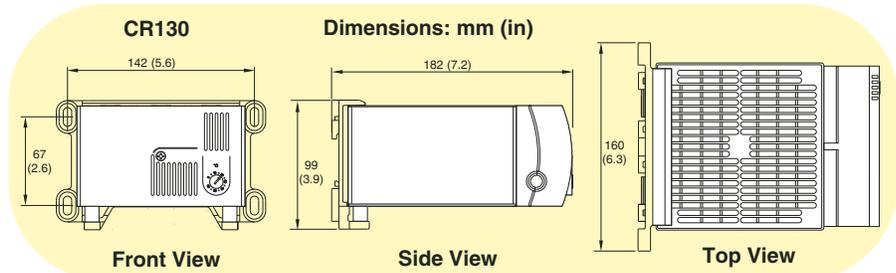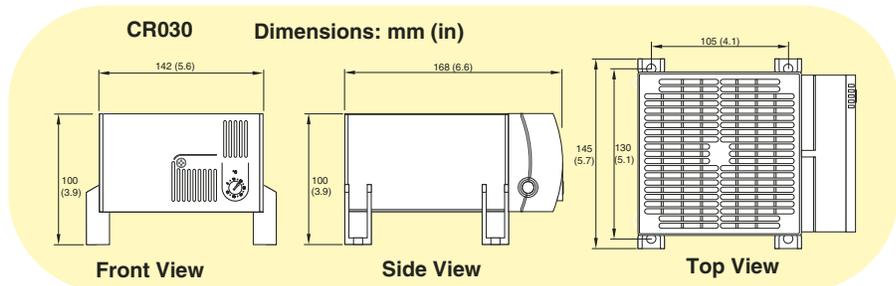

To Order (Specify Model Number)

AVAILABLE FOR FAST DELIVERY!

MODEL NO.	PRICE	DESCRIPTION
CR03003059900	\$196	Fan heaters, 950 W, 120 Vac with adjustable thermostat 0 to 60°C (32 to 140°F), foot mount
CR13013059900	206	Fan heaters, 950 W, 120 Vac with adjustable thermostat 0 to 60°C (32 to 140°F), DIN or panel mount
XBANS3575P	9	DIN rail 35 x 7.5 mm x 2 m (1.4 x 0.30" x 6') slotted

Comes complete with operator's manual.

Ordering Examples: CR03003059900, foot-mounted fan heater, \$196. CR13013059900, DIN or panel mounted fan heater, \$206.

omega.co.uk[®]

Your One-Stop Source for Process Measurement and Control!

Freephone 0800 488 488 | International +44(0) 161 777 6622 | Fax +44(0) 161 777 6622 | Sales@omega.co.uk

www.omega.co.uk



UNITED STATES

www.omega.com

1-800-TC-OMEGA
Stamford, CT.

UNITED KINGDOM

www.omega.co.uk

Manchester, England
0800-488-488
+44-(0)161-777-6611

CANADA

www.omega.ca

Laval(Quebec)
1-800-TC-OMEGA

FRANCE

www.omega.fr

0800-466-342

GERMANY

www.omega.de

Deckenfronn, Germany
0800-8266342

BENELUX

www.omega.nl

0800-099-33-44



More than 100,000 Products Available!

• Temperature

Calibrators, Connectors, General Test and Measurement Instruments, Handheld Instruments for Temperature Measurement, Ice Point References, Indicating Labels, Crayons, Cements and Lacquers, Infrared Temperature Measurement Instruments, Recorders, Relative Humidity Measurement Instruments, PT100 Probes, PT100 Elements, Temperature & Process Meters, Timers and Counters, Temperature and Process Controllers and Power Switching Devices, Thermistor Elements, Probes and Assemblies, Thermocouples, Thermowells and Head and Well Assemblies, Transmitters, Thermocouple Wire, RTD Probes

• Flow and Level

Air Velocity Indicators, Doppler Flowmeters, Level Measurement, Magnetic Flowmeters, Mass Flowmeters, Pitot Tubes, Pumps, Rotameters, Turbine and Paddle Wheel Flowmeters, Ultrasonic Flowmeters, Valves, Variable Area Flowmeters, Vortex Shedding Flowmeters

• pH and Conductivity

Conductivity Instrumentation, Dissolved Oxygen Instrumentation, Environmental Instrumentation, pH Electrodes and Instruments, Water and Soil Analysis Instrumentation

• Data Acquisition

Communication Products and Converters, Data Acquisition and Analysis Software, Data Loggers Plug-in Cards, Signal Conditioners, USB, RS232, RS485, Ethernet and Parallel Port Data Acquisition Systems, Wireless Transmitters and Receivers

• Pressure, Strain and Force

Displacement Transducers, Dynamic Measurement Force Sensors, Instrumentation for Pressure and Strain Measurements, Load Cells, Pressure Gauges, Pressure Reference Section, Pressure Switches, Pressure Transducers, Proximity Transducers, Regulators, Pressure Transmitters, Strain Gauges, Torque Transducers, Valves

• Heaters

Band Heaters, Cartridge Heaters, Circulation Heaters, Comfort Heaters, Controllers, Meters and Switching Devices, Flexible Heaters, General Test and Measurement Instruments, Heater Hook-up Wire, Heating Cable Systems, Immersion Heaters, Process Air and Duct, Heaters, Radiant Heaters, Strip Heaters, Tubular Heaters