

# OS36 Series Accessories

## Cooling Jacket Kit for OS36 and OS36-2



**OS36-APC**  
\$439, shown smaller than actual size.





**OS36-GMK**,  
\$85, shown smaller than actual size.



The water cooling system consists of a seamless monotube, to eliminate the possibility of leaking joints. The seamless tubing extends 1 m (3') from the rear of the housing for convenience.

- ✔ Seamless Copper Monotube Cooling Coil
- ✔ Complete Equipment for Air Cooling and/or Water Cooling
- ✔ Air Purge Included
- ✔ Super-Efficient Design for Low Air or Low Water Use
- ✔ Water Cooling to 540°C (1000°F) with as Little as 0.05 gpm (190 cc/min)

Extraordinarily efficient in design, the OS36-APC needs water flow rate of only 0.05 gpm (190 cc/min.) to protect an infrared thermocouple at 540°C (1000°F). This convenient and inexpensive kit makes it possible to use either the OS36 or OS36-2 with air, water or both for service in harsh environments. Measuring only 25 x 100 mm (4 x 1") overall, the OS36-APC is small enough to fit into tight areas to closely monitor process temperatures up close (in the optimum position). It can withstand the harshest environments with its all stainless steel housing.

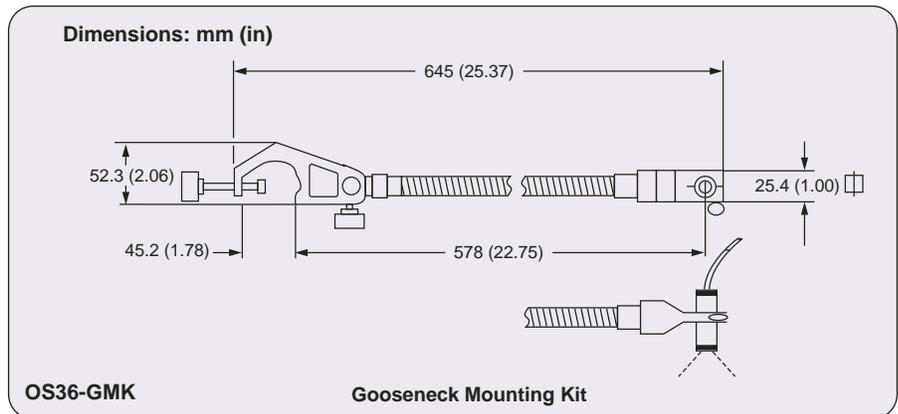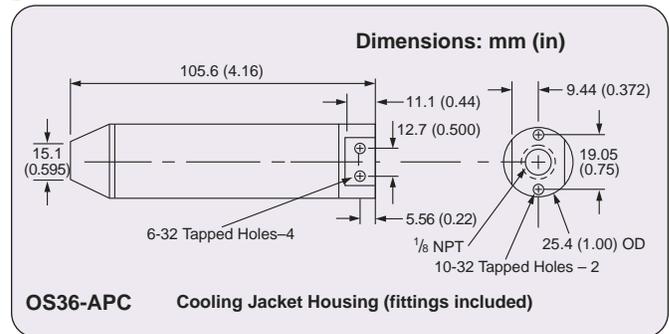

**AVAILABLE FOR FAST DELIVERY!**

<b>To Order (Specify Model Number)</b>		
Model Number	Price	Description
<b>OS36-APC</b>	<b>\$439</b>	Cooling jacket for OS36 and OS36-2, includes manual
<b>OS36-GMK</b>	<b>85</b>	Gooseneck mounting kit
<b>OS36-APK-120</b>	<b>179</b>	Air pump kit for air purge supply for OS36-2 and OS36-5, 120 Vac, 1960 cc/min (120 cu-in/min)
<b>OS36-APK-12</b>	<b>169</b>	Air pump kit for air purge supply for OS36-2 and OS36-5, 12 Vdc, 1960 cc/min (120 cu-in/min)
<b>OS36-MB2</b>	<b>35</b>	Stainless steel mounting bracket for OS36-5, OS36-10, OS37-10, OS38-10, OS37-100 and OS38-100

# omega.co.uk<sup>®</sup>

Your One-Stop Source for Process Measurement and Control!

Freephone 0800 488 488 | International +44(0) 161 777 6622 | Fax +44(0) 161 777 6622 | Sales@omega.co.uk

[www.omega.co.uk](http://www.omega.co.uk)



#### UNITED STATES

[www.omega.com](http://www.omega.com)

1-800-TC-OMEGA  
Stamford, CT.

#### UNITED KINGDOM

[www.omega.co.uk](http://www.omega.co.uk)

Manchester, England  
0800-488-488  
+44-(0)161-777-6611

#### CANADA

[www.omega.ca](http://www.omega.ca)

Laval(Quebec)  
1-800-TC-OMEGA

#### FRANCE

[www.omega.fr](http://www.omega.fr)

0800-466-342

#### GERMANY

[www.omega.de](http://www.omega.de)

Deckenfronn, Germany  
0800-8266342

#### BENELUX

[www.omega.nl](http://www.omega.nl)

0800-099-33-44



## More than 100,000 Products Available!

### • Temperature

Calibrators, Connectors, General Test and Measurement Instruments, Handheld Instruments for Temperature Measurement, Ice Point References, Indicating Labels, Crayons, Cements and Lacquers, Infrared Temperature Measurement Instruments, Recorders, Relative Humidity Measurement Instruments, PT100 Probes, PT100 Elements, Temperature & Process Meters, Timers and Counters, Temperature and Process Controllers and Power Switching Devices, Thermistor Elements, Probes and Assemblies, Thermocouples, Thermowells and Head and Well Assemblies, Transmitters, Thermocouple Wire, RTD Probes

### • Flow and Level

Air Velocity Indicators, Doppler Flowmeters, Level Measurement, Magnetic Flowmeters, Mass Flowmeters, Pitot Tubes, Pumps, Rotameters, Turbine and Paddle Wheel Flowmeters, Ultrasonic Flowmeters, Valves, Variable Area Flowmeters, Vortex Shedding Flowmeters

### • pH and Conductivity

Conductivity Instrumentation, Dissolved Oxygen Instrumentation, Environmental Instrumentation, pH Electrodes and Instruments, Water and Soil Analysis Instrumentation

### • Data Acquisition

Communication Products and Converters, Data Acquisition and Analysis Software, Data Loggers Plug-in Cards, Signal Conditioners, USB, RS232, RS485, Ethernet and Parallel Port Data Acquisition Systems, Wireless Transmitters and Receivers

### • Pressure, Strain and Force

Displacement Transducers, Dynamic Measurement Force Sensors, Instrumentation for Pressure and Strain Measurements, Load Cells, Pressure Gauges, Pressure Reference Section, Pressure Switches, Pressure Transducers, Proximity Transducers, Regulators, Pressure Transmitters, Strain Gauges, Torque Transducers, Valves

### • Heaters

Band Heaters, Cartridge Heaters, Circulation Heaters, Comfort Heaters, Controllers, Meters and Switching Devices, Flexible Heaters, General Test and Measurement Instruments, Heater Hook-up Wire, Heating Cable Systems, Immersion Heaters, Process Air and Duct, Heaters, Radiant Heaters, Strip Heaters, Tubular Heaters