



TYPE 3R SCREW COVER ENCLOSURES

Starts at
\$24



- 0.060" Galvannealed Steel
- Spot Weld Construction
- Rain Cap
- Mounting Hole In Back of Enclosure
- Slip On Removable Screw
- Padlocking Provisions
- No Gasket
- No Subpanel or Provisions
- Ground Studs on Door and Body
- Optional Mounting Straps Available

Application


Designed to house electrical controls instruments and components in an outdoor environment. Protects against rain, sleet and snow.

Finish

ANSI-61 gray powder coating inside and out over phosphatized surfaces.

Industry Standards


NEMA Type 3
UL Listed Type 3R
CSA Type 3R
IEC 60529 IP 32

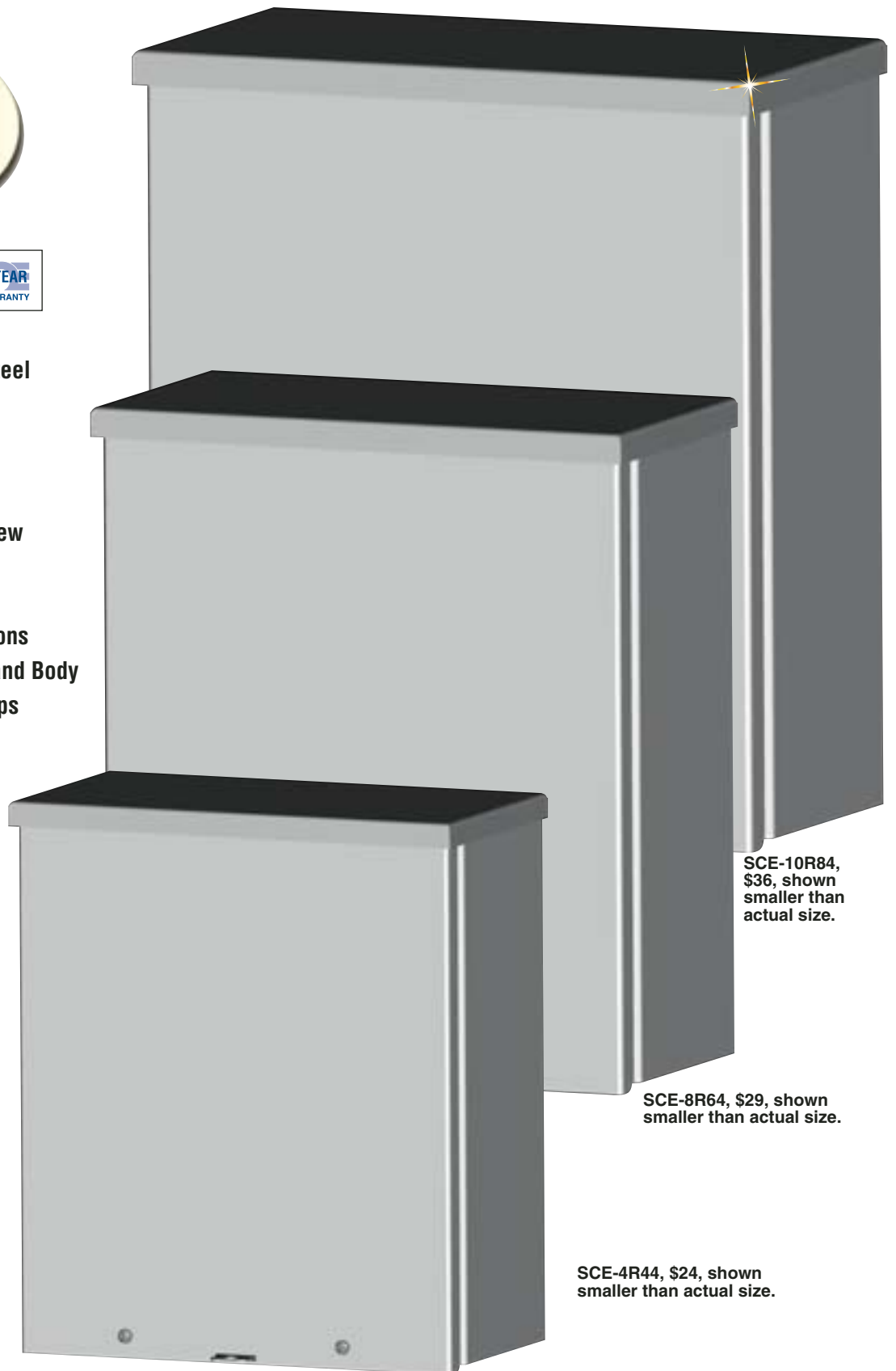

SCE-10R84, \$36, shown smaller than actual size.

SCE-8R64, \$29, shown smaller than actual size.

SCE-4R44, \$24, shown smaller than actual size.

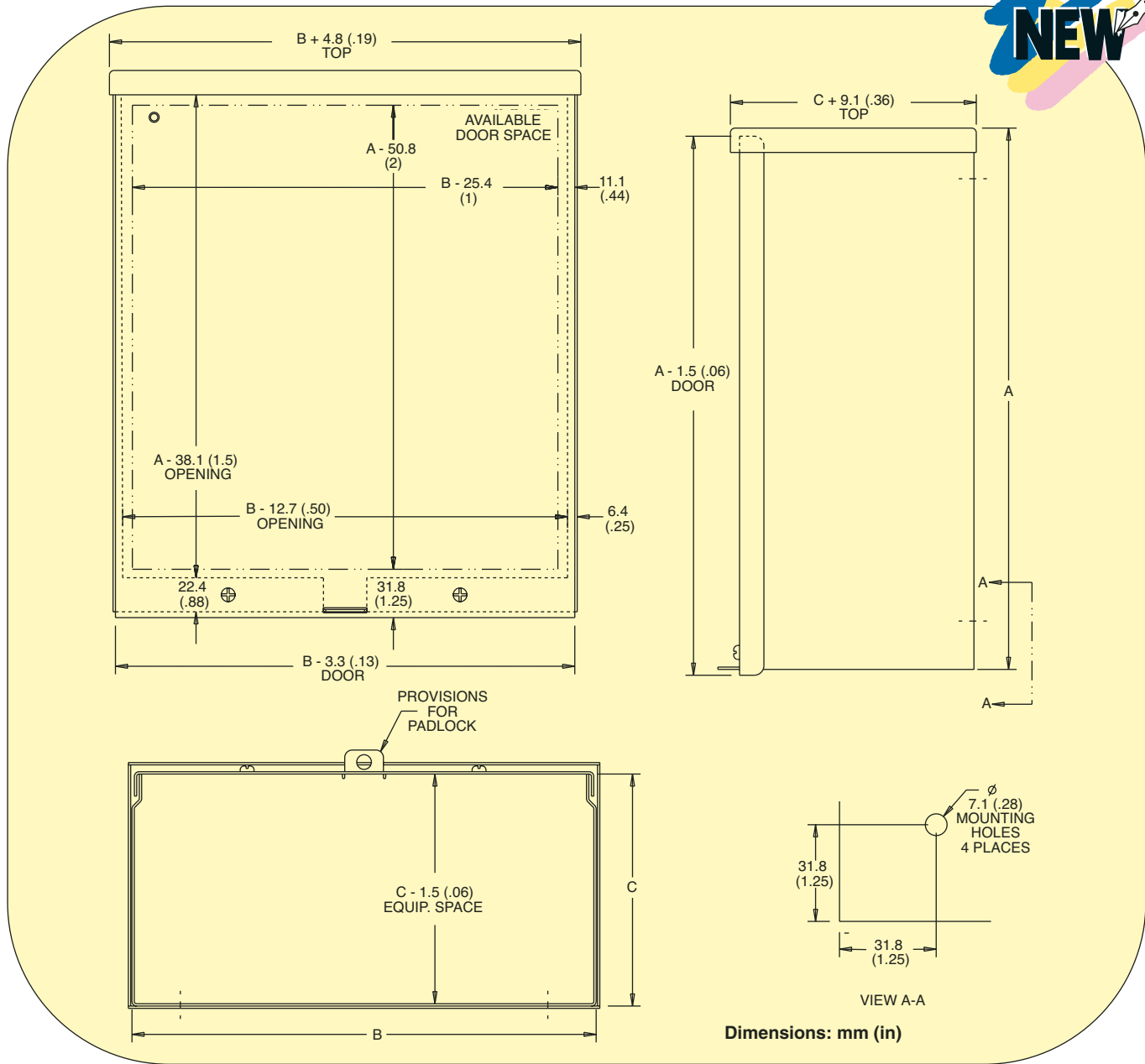

To Order (Specify Model Number)

STOCKED FOR IMMEDIATE DELIVERY!

MODEL NO.	PRICE	DESCRIPTION	HEIGHT (in) (A)	WIDTH (in) (B)	DEPTH (in) (C)
SCE-4R44	\$24	Type 3R screw cover	4.00	4.00	4.00
SCE-6R64	25	Type 3R screw cover	6.00	6.00	4.00
SCE-6R66	26	Type 3R screw cover	6.00	6.00	6.00
SCE-8R64	29	Type 3R screw cover	8.00	6.00	4.00
SCE-8R66	32	Type 3R screw cover	8.00	6.00	6.00
SCE-10R84	36	Type 3R screw cover	10.00	8.00	4.00
SCE-10R86	38	Type 3R screw cover	10.00	8.00	6.00
SCE-10R104	43	Type 3R screw cover	10.00	10.00	4.00
SCE-10R106	50	Type 3R screw cover	10.00	10.00	6.00
SCE-12R104	54	Type 3R screw cover	12.00	10.00	4.00
SCE-12R106	56	Type 3R screw cover	12.00	10.00	6.00
SCE-12R124	59	Type 3R screw cover	12.00	12.00	4.00
SCE-12R126	63	Type 3R screw cover	12.00	12.00	6.00

Ordering Example: SCE-4R44, Type 3R screw cover enclosure, \$24.



UNITED STATES

www.omega.com
1-800-TC-OMEGA
Stamford, CT.

CANADA

www.omega.ca
Laval(Quebec)
1-800-TC-OMEGA

GERMANY

www.omega.de
Deckenpfronn, Germany
0800-8266342

UNITED KINGDOM

www.omega.co.uk
Manchester, England
0800-488-488

FRANCE

www.omega.fr
Guyancourt, France
088-466-342

CZECH REPUBLIC

www.omegaeng.cz
Karviná, Czech Republic
596-311-899

BENELUX

www.omega.nl
Amstelveen, NL
0800-099-33-44



More than 100,000 Products Available!

• Temperature

Calibrators, Connectors, General Test and Measurement Instruments, Glass Bulb Thermometers, Handheld Instruments for Temperature Measurement, Ice Point References, Indicating Labels, Crayons, Cements and Lacquers, Infrared Temperature Measurement Instruments, Recorders Relative Humidity Measurement Instruments, RTD Probes, Elements and Assemblies, Temperature & Process Meters, Timers and Counters, Temperature and Process Controllers and Power Switching Devices, Thermistor Elements, Probes and Assemblies, Thermocouples Thermowells and Head and Well Assemblies, Transmitters, Wire

• Flow and Level

Air Velocity Indicators, Doppler Flowmeters, Level Measurement, Magnetic Flowmeters, Mass Flowmeters, Pitot Tubes, Pumps, Rotameters, Turbine and Paddle Wheel Flowmeters, Ultrasonic Flowmeters, Valves, Variable Area Flowmeters, Vortex Shedding Flowmeters

• pH and Conductivity

Conductivity Instrumentation, Dissolved Oxygen Instrumentation, Environmental Instrumentation, pH Electrodes and Instruments, Water and Soil Analysis Instrumentation

• Data Acquisition

Auto-Dialers and Alarm Monitoring Systems, Communication Products and Converters, Data Acquisition and Analysis Software, Data Loggers Plug-in Cards, Signal Conditioners, USB, RS232, RS485 and Parallel Port Data Acquisition Systems, Wireless Transmitters and Receivers

• Pressure, Strain and Force

Displacement Transducers, Dynamic Measurement Force Sensors, Instrumentation for Pressure and Strain Measurements, Load Cells, Pressure Gauges, Pressure Reference Section, Pressure Switches, Pressure Transducers, Proximity Transducers, Regulators, Strain Gages, Torque Transducers, Valves

• Heaters

Band Heaters, Cartridge Heaters, Circulation Heaters, Comfort Heaters, Controllers, Meters and Switching Devices, Flexible Heaters, General Test and Measurement Instruments, Heater Hook-up Wire, Heating Cable Systems, Immersion Heaters, Process Air and Duct, Heaters, Radiant Heaters, Strip Heaters, Tubular Heaters