



TYPE 4X ENVIROLINE® 304 AND 316 SS JUNCTION ENCLOSURES

Starts at
\$75



SCE-604ELJSS, \$75, shown smaller than actual size.

- 0.063" Stainless Steel Type 304 and 316
- Seams Continuously Welded and Ground Smooth
- Flange Trough Collar Around All Sides of Door Opening
- Oil-Resistant Gasket
- Standoffs Provided for Mounting Optional Panels
- Removable Stainless Steel Hinge Pins
- Doors Open 180°
- Black Mini ¼ Turn Latches
- Latches Are Opened or Closed with a Screwdriver
- Sealing Washers and Hole Plugs Included
- Ground Stud on Door and Body
- Optional Mounting Feet Available
- Panels Can Be Special Ordered in Stainless Steel



Application





Designed to house electrical controls, instruments and components in areas, which may be regularly hosed down or are in very wet or oily conditions. Provides protection from dust, dirt, oil, and water. For outdoor application a drip shield is recommended.

Finish

#4 brushed finish on all exterior surfaces. Optional panels are powder coated white.

Industry Standards

NEMA Type 4, 4X, 12 & 13; UL Listed Type 4, 4X & 12; CSA Type 12, 4, & 4X; IEC 60529 IP 66

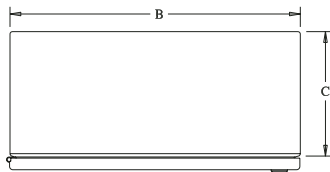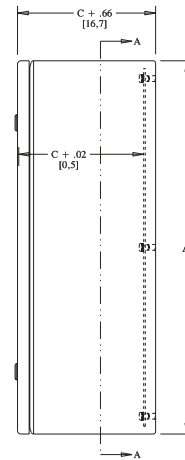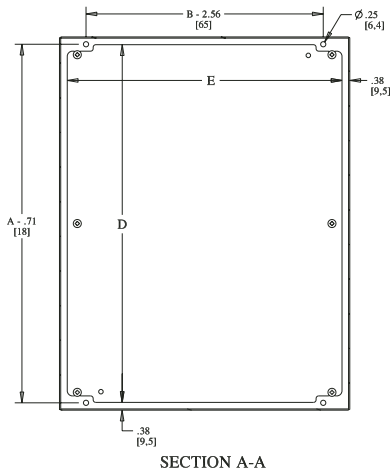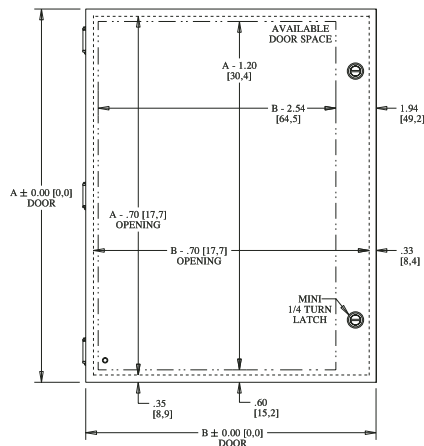

LATCH NOTES:

One latch centered on the door vertically if height is ≤ 14.00 [355,6]

Two latches located 3.00 [76,2] from top & bottom of door if height is > 14.00 [355,6]

Three latches are required if height is > 20.00 [508]

Dimensions: in (mm)

TYPE 4X ENVIROLINE JUNCTION ENCLOSURE

To Order (Specify Model Number)

MOST POPULAR MODELS HIGHLIGHTED!

ENCLOSURES (in)					SUB-PANEL (in)	
MODEL NO.	PRICE	HEIGHT (A)	WIDTH (B)	DEPTH (C)	MODEL NO.	PRICE
TYPE 4X 304 STAINLESS STEEL ENVIROLINE® JUNCTION ENCLOSURES						
SCE-604ELJSS	\$75	6.00	4.00	4.00	SCE-6P4J	\$2
SCE-606ELJSS	84	6.00	6.00	4.00	SCE-6P6J	3
SCE-806ELJSS	100	8.00	6.00	4.00	SCE-8P6J	3
SCE-8066ELJSS	121	8.00	6.00	6.00	SCE-8P6J	3
SCE-1008ELJSS	201	10.00	8.00	4.00	SCE-10P8J	4
SCE-10086ELJSS	214	10.00	8.00	6.00	SCE-10P8J	4
SCE-1210ELJSS	225	12.00	10.00	6.00	SCE-12P10J	6
SCE-12108ELJSS	234	12.00	10.00	8.00	SCE-12P10J	6
SCE-1212ELJSS	243	12.00	12.00	6.00	SCE-12P12J	7
SCE-1412ELJSS	251	14.00	12.00	6.00	SCE-14P12J	7
SCE-14128ELJSS	259	14.00	12.00	8.00	SCE-14P12J	8
SCE-1614ELJSS	307	16.00	14.00	6.00	SCE-16P14J	15
SCE-16148ELJSS	328	16.00	14.00	8.00	SCE-16P14J	15
TYPE 4X 316 STAINLESS STEEL ENVIROLINE® JUNCTION ENCLOSURES						
SCE-604ELJSS6	\$120	6.00	4.00	4.00	SCE-6P4J	2
SCE-606ELJSS6	135	6.00	6.00	4.00	SCE-6P6J	3
SCE-806ELJSS6	161	8.00	6.00	4.00	SCE-8P6J	3
SCE-8066ELJSS6	196	8.00	6.00	6.00	SCE-8P6J	3
SCE-1008ELJSS6	325	10.00	8.00	4.00	SCE-10P8J	4
SCE-10086ELJSS6	346	10.00	8.00	6.00	SCE-10P8J	4
SCE-1210ELJSS6	365	12.00	10.00	6.00	SCE-12P10J	6
SCE-12108ELJSS6	380	12.00	10.00	8.00	SCE-12P10J	6
SCE-1212ELJSS6	393	12.00	12.00	6.00	SCE-12P12J	7
SCE-1412ELJSS6	406	14.00	12.00	6.00	SCE-14P12J	7
SCE-14128ELJSS6	420	14.00	12.00	8.00	SCE-14P12J	7
SCE-1614ELJSS6	497	16.00	14.00	6.00	SCE-16P14J	15
SCE-16148ELJSS6	533	16.00	14.00	8.00	SCE-16P14J	15

Ordering Example: SCE-604ELJSS, Type 4X 304 stainless steel Enviroline® junction enclosure, \$75.



UNITED STATES

www.omega.com
1-800-TC-OMEGA
Stamford, CT.

CANADA

www.omega.ca
Laval(Quebec)
1-800-TC-OMEGA

GERMANY

www.omega.de
Deckenpfronn, Germany
0800-8266342

UNITED KINGDOM

www.omega.co.uk
Manchester, England
0800-488-488

FRANCE

www.omega.fr
Guyancourt, France
088-466-342

CZECH REPUBLIC

www.omegaeng.cz
Karviná, Czech Republic
596-311-899

BENELUX

www.omega.nl
Amstelveen, NL
0800-099-33-44



More than 100,000 Products Available!

• Temperature

Calibrators, Connectors, General Test and Measurement Instruments, Glass Bulb Thermometers, Handheld Instruments for Temperature Measurement, Ice Point References, Indicating Labels, Crayons, Cements and Lacquers, Infrared Temperature Measurement Instruments, Recorders Relative Humidity Measurement Instruments, RTD Probes, Elements and Assemblies, Temperature & Process Meters, Timers and Counters, Temperature and Process Controllers and Power Switching Devices, Thermistor Elements, Probes and Assemblies, Thermocouples Thermowells and Head and Well Assemblies, Transmitters, Wire

• Flow and Level

Air Velocity Indicators, Doppler Flowmeters, Level Measurement, Magnetic Flowmeters, Mass Flowmeters, Pitot Tubes, Pumps, Rotameters, Turbine and Paddle Wheel Flowmeters, Ultrasonic Flowmeters, Valves, Variable Area Flowmeters, Vortex Shedding Flowmeters

• pH and Conductivity

Conductivity Instrumentation, Dissolved Oxygen Instrumentation, Environmental Instrumentation, pH Electrodes and Instruments, Water and Soil Analysis Instrumentation

• Data Acquisition

Auto-Dialers and Alarm Monitoring Systems, Communication Products and Converters, Data Acquisition and Analysis Software, Data Loggers Plug-in Cards, Signal Conditioners, USB, RS232, RS485 and Parallel Port Data Acquisition Systems, Wireless Transmitters and Receivers

• Pressure, Strain and Force

Displacement Transducers, Dynamic Measurement Force Sensors, Instrumentation for Pressure and Strain Measurements, Load Cells, Pressure Gauges, Pressure Reference Section, Pressure Switches, Pressure Transducers, Proximity Transducers, Regulators, Strain Gages, Torque Transducers, Valves

• Heaters

Band Heaters, Cartridge Heaters, Circulation Heaters, Comfort Heaters, Controllers, Meters and Switching Devices, Flexible Heaters, General Test and Measurement Instruments, Heater Hook-up Wire, Heating Cable Systems, Immersion Heaters, Process Air and Duct, Heaters, Radiant Heaters, Strip Heaters, Tubular Heaters