



TYPE 12 FREE-STANDING SINGLE-DOOR, SINGLE-ACCESS ENCLOSURES

SCE-FS Series
Starts at
\$735



- 0.104" Carbon Steel or Stainless Steel
- Concealed Hinge
- Removable and Interchangeable Doors
- Flange Trough Collar Around All Sides of Door Opening
- Seams Continuously Welded and Ground Smooth, No Holes or Knockouts
- Strong, Rigid Construction with Stiffeners Welded On Backs of Single Access Boxes
- Lifting Eyes for Easy Handling
- Black Zinc Die Cast Keylocking/ Padlocking Handle
- 3-Point Latching Mechanism
- Latch Rods Have Rollers for Easier Door Closing
- Removable Print Pocket Provided On Door
- Mounting Channels Welded Horizontally On Sides of Interior Body at Top, Bottom and Middle for Mounting Optional Panels or Rack Mounting Angles
- Oil Resistant Gasket
- Ground Stud on Door

Application

Designed to house a variety of electrical and electronic controls and instruments. Provisions for optional surface mounting or rack mounting of almost any type of equipment. Provides protection from dust, dirt, water and oil. The enclosures are extra deep for applications requiring more interior space.

Finish


White powder coating inside and ANSI-61 recoatable gray finish outside over phosphatized surfaces. Stainless steel enclosures are Type 304 stainless with #4 brushed finish. Optional panels are powder coated white.

Industry Standard

NEMA Type 12 & Type 13
UL Listed Type 12
CSA Type 12
IEC 60529 IP55



SCE-602418FS, \$735, shown smaller than actual size.

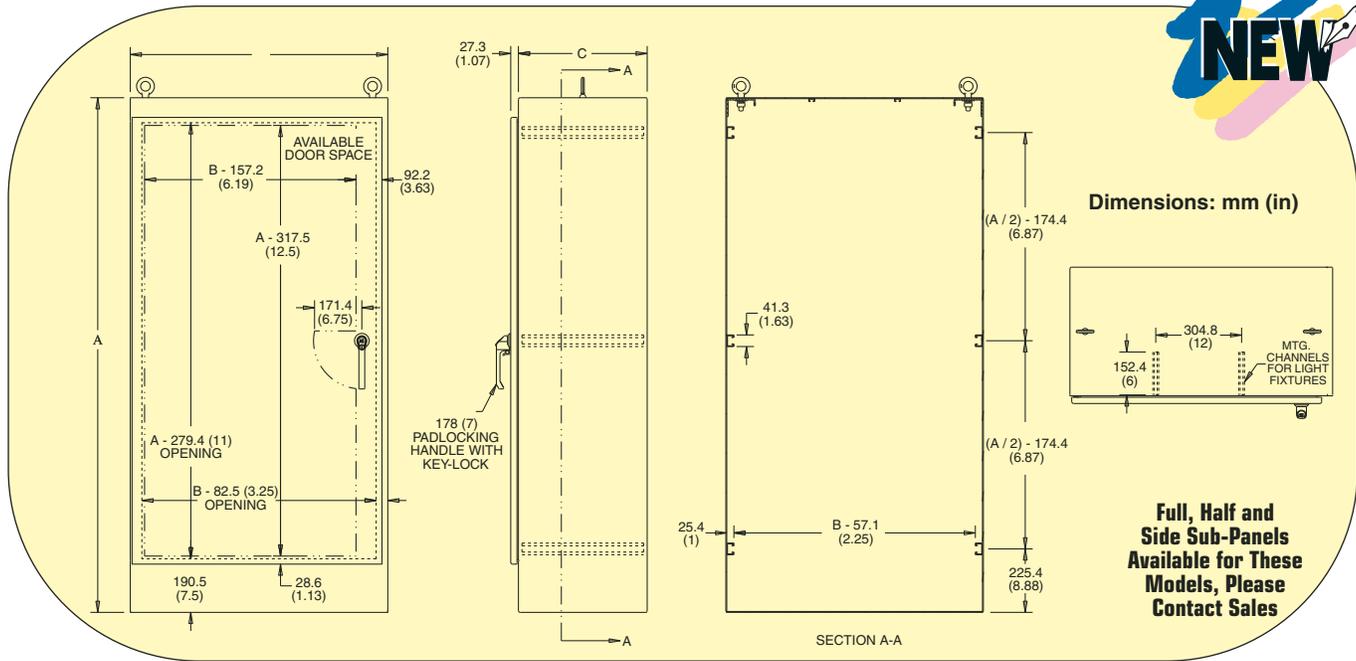

To Order (Specify Model Number)

MOST POPULAR MODELS HIGHLIGHTED!

MODEL NO.	PRICE	DESCRIPTION	HEIGHT (in) (A)	WIDTH (in) (B)	DEPTH (in) (C)
SINGLE ACCESS ENCLOSURES					
SCE-602418FS	\$735	Type 12 free-standing single door	60.00	24.0	18.00
SCE-603624FS	975	Type 12 free-standing single door	60.00	36.00	24.00
SCE-722418FS	815	Type 12 free-standing single door	72.00	24.0	18.00
SCE-722424FS	890	Type 12 free-standing single door	72.00	24.0	24.00
SCE-723018FS	880	Type 12 free-standing single door	72.00	30.00	18.00
SCE-723024FS	980	Type 12 free-standing single door	72.00	30.00	24.00
SCE-723618FS	980	Type 12 free-standing single door	72.00	30.00	6.00
SCE-723624FS	1090	Type 12 free-standing single door	72.00	36.00	4.00
SCE-723630FS	1190	Type 12 free-standing single door	72.00	36.00	6.00
SCE-723636FS	1270	Type 12 free-standing single door	72.00	36.00	4.00
SCE-902420FS	970	Type 12 free-standing single door	90.00	24.00	6.00
SCE-903620FS	1175	Type 12 free-standing single door	90.00	36.00	20.00
SCE-903624FS	1260	Type 12 free-standing single door	90.00	36.00	24.00
SCE-903636FS	1460	Type 12 free-standing single door	90.00	36.00	36.00
SINGLE ACCESS STAINLESS STEEL ENCLOSURES					
SCE-602418SSFS	\$2985	Type 12 free-standing single door	60.00	24.0	18.00
SCE-603624SSFS	3955	Type 12 free-standing single door	60.00	36.00	24.00
SCE-722418SSFS	3309	Type 12 free-standing single door	72.00	24.0	18.00
SCE-722424SSFS	3677	Type 12 free-standing single door	72.00	24.0	24.00
SCE-723018SSFS	3647	Type 12 free-standing single door	72.00	30.00	18.00
SCE-723024SSFS	4046	Type 12 free-standing single door	72.00	30.00	24.00
SCE-723618SSFS	4000	Type 12 free-standing single door	72.00	36.00	18.00
SCE-723624SSFS	4415	Type 12 free-standing single door	72.00	36.00	24.00
SCE-723630SSFS	4836	Type 12 free-standing single door	72.00	36.00	30.00
SCE-723636SSFS	5250	Type 12 free-standing single door	72.00	36.00	36.00
SCE-902420SSFS	3941	Type 12 free-standing single door	90.00	24.00	20.00
SCE-903620SSFS	4783	Type 12 free-standing single door	90.00	36.00	20.00
SCE-903624SSFS	5114	Type 12 free-standing single door	90.00	36.00	24.00
SCE-903636SSFS	6084	Type 12 free-standing single door	90.00	36.00	36.00

Ordering Examples: SCE-602418FS, Type 12 free standing, single-door, single-access enclosure, \$735.
 SCE-723018FS, Type 12 free standing, single-door, single-access enclosure, \$880.

omega.co.uk®

Your One-Stop Source for Process Measurement and Control!

Freephone 0800 488 488 | International +44(0) 161 777 6622 | Fax +44(0) 161 777 6622 | Sales@omega.co.uk

www.omega.co.uk



UNITED STATES

www.omega.com

1-800-TC-OMEGA
Stamford, CT.

UNITED KINGDOM

www.omega.co.uk

Manchester, England
0800-488-488
+44-(0)161-777-6611

CANADA

www.omega.ca

Laval(Quebec)
1-800-TC-OMEGA

FRANCE

www.omega.fr

0800-466-342

GERMANY

www.omega.de

Deckenfronn, Germany
0800-8266342

BENELUX

www.omega.nl

0800-099-33-44



More than 100,000 Products Available!

• Temperature

Calibrators, Connectors, General Test and Measurement Instruments, Handheld Instruments for Temperature Measurement, Ice Point References, Indicating Labels, Crayons, Cements and Lacquers, Infrared Temperature Measurement Instruments, Recorders, Relative Humidity Measurement Instruments, PT100 Probes, PT100 Elements, Temperature & Process Meters, Timers and Counters, Temperature and Process Controllers and Power Switching Devices, Thermistor Elements, Probes and Assemblies, Thermocouples, Thermowells and Head and Well Assemblies, Transmitters, Thermocouple Wire, RTD Probes

• Flow and Level

Air Velocity Indicators, Doppler Flowmeters, Level Measurement, Magnetic Flowmeters, Mass Flowmeters, Pitot Tubes, Pumps, Rotameters, Turbine and Paddle Wheel Flowmeters, Ultrasonic Flowmeters, Valves, Variable Area Flowmeters, Vortex Shedding Flowmeters

• pH and Conductivity

Conductivity Instrumentation, Dissolved Oxygen Instrumentation, Environmental Instrumentation, pH Electrodes and Instruments, Water and Soil Analysis Instrumentation

• Data Acquisition

Communication Products and Converters, Data Acquisition and Analysis Software, Data Loggers Plug-in Cards, Signal Conditioners, USB, RS232, RS485, Ethernet and Parallel Port Data Acquisition Systems, Wireless Transmitters and Receivers

• Pressure, Strain and Force

Displacement Transducers, Dynamic Measurement Force Sensors, Instrumentation for Pressure and Strain Measurements, Load Cells, Pressure Gauges, Pressure Reference Section, Pressure Switches, Pressure Transducers, Proximity Transducers, Regulators, Pressure Transmitters, Strain Gauges, Torque Transducers, Valves

• Heaters

Band Heaters, Cartridge Heaters, Circulation Heaters, Comfort Heaters, Controllers, Meters and Switching Devices, Flexible Heaters, General Test and Measurement Instruments, Heater Hook-up Wire, Heating Cable Systems, Immersion Heaters, Process Air and Duct, Heaters, Radiant Heaters, Strip Heaters, Tubular Heaters