

TYPE 12 FREE-STANDING TWO-DOOR, SINGLE- ACCESS ENCLOSURES



Starts at
\$1229



- 0.104" Carbon Steel or Stainless Steel
- Removable and Interchangeable Doors
- Concealed Hinge
- Seams Continuously Welded and Ground Smooth, No Holes or Knockouts
- Strong, Rigid Construction with Stiffeners Welded On Backs of Single Access Boxes
- Lifting Eyes for Easy Handling
- Black Zinc Die Cast Keylocking/ Padlocking Handle
- 3-Point Latching Mechanism
- Latch Rods have Rollers for Easier Door Closing
- Flange Trough Collar Around All Sides of Door Opening
- Removable Print Pocket Provided On Door
- Flange Trough Collar Around All Sides of Door Opening
- Mounting Channels Welded Horizontally On Sides of Interior Body At Top, Bottom and Middle for Mounting Optional Panels or Rack Mounting Angles
- Oil Resistant Gasket
- Ground Stud on Door



SCE-604818FSD, \$1229, shown smaller than actual size.

Application


Designed to house a variety of electrical and electronic controls and instruments. Provisions for optional surface mounting or rack mounting of almost any type of equipment. Provides protection from dust, dirt, water and oil. The enclosures are extra deep for applications requiring more interior space.

Finish

White powder coating inside and ANSI-61 recoatable gray finish outside over phosphatized surfaces. Stainless steel enclosures are Type 304 stainless with #4 brushed finish. Optional panels are powder coated white.

Industry Standards

NEMA Type 12 & Type 13
UL Listed Type 12
CSA TType 12
IEC 60529 IP 55

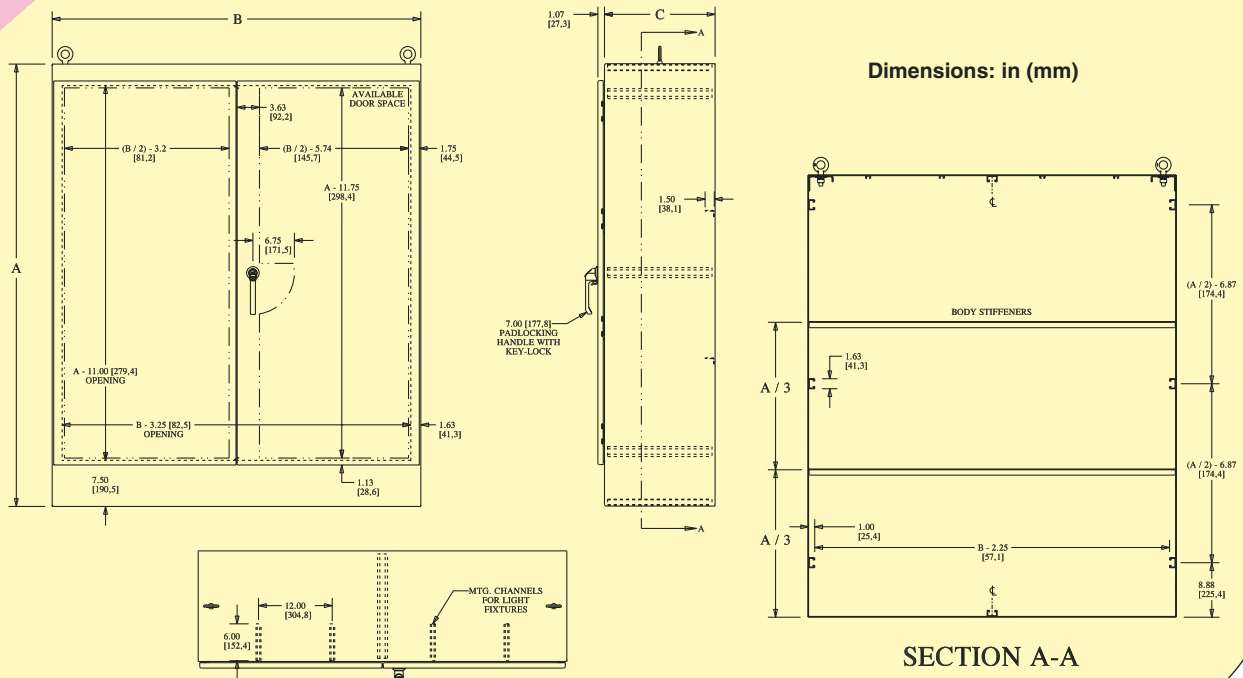

To Order (Specify Model Number)

STOCKED FOR IMMEDIATE DELIVERY!

| MODEL NO. | PRICE | DESCRIPTION | HEIGHT (in) (A) | WIDTH (in) (B) | DEPTH (in) (C) |
|---|--------|--------------------------------|--------------------|-------------------|-------------------|
| SINGLE ACCESS ENCLOSURES | | | | | |
| SCE-604818FSD | \$1229 | Type 12 free-standing two door | 60.00 | 48.00 | 18.00 |
| SCE-724818FSD | 1353 | Type 12 free-standing two door | 72.00 | 48.00 | 18.00 |
| SCE-724824FSD | 1466 | Type 12 free-standing two door | 72.00 | 48.00 | 24.00 |
| SCE-726018FSD | 1523 | Type 12 free-standing two door | 72.00 | 60.00 | 18.00 |
| SCE-726024FSD | 1647 | Type 12 free-standing two door | 72.00 | 60.00 | 24.00 |
| SCE-726036FSD | 1895 | Type 12 free-standing two door | 72.00 | 60.00 | 36.00 |
| SCE-727218FSD | 1692 | Type 12 free-standing two door | 72.00 | 72.00 | 18.00 |
| SCE-727224FSD | 1828 | Type 12 free-standing two door | 72.00 | 72.00 | 24.00 |
| SCE-904820FSD | 1584 | Type 12 free-standing two door | 90.00 | 48.00 | 20.00 |
| SCE-907220FSD | 1998 | Type 12 free-standing two door | 90.00 | 72.00 | 20.00 |
| SCE-907224FSD | 2098 | Type 12 free-standing two door | 90.00 | 72.00 | 24.00 |
| SCE-907236FSD | 2404 | Type 12 free-standing two door | 90.00 | 72.00 | 36.00 |
| SINGLE ACCESS STAINLESS STEEL ENCLOSURES | | | | | |
| SCE-604818SSFSD | \$5407 | Type 12 free-standing two door | 60.00 | 48.00 | 18.00 |
| SCE-724818SSFSD | 5957 | Type 12 free-standing two door | 72.00 | 48.00 | 18.00 |
| SCE-724824SSFSD | 6453 | Type 12 free-standing two door | 72.00 | 48.00 | 24.00 |
| SCE-726018SSFSD | 6700 | Type 12 free-standing two door | 72.00 | 60.00 | 18.00 |
| SCE-726024SSFSD | 7250 | Type 12 free-standing two door | 72.00 | 60.00 | 24.00 |
| SCE-726036SSFSD | 8340 | Type 12 free-standing two door | 72.00 | 30.00 | 36.00 |
| SCE-727218SSFSD | 7446 | Type 12 free-standing two door | 72.00 | 72.00 | 18.00 |
| SCE-727224SSFSD | 8048 | Type 12 free-standing two door | 72.00 | 72.00 | 24.00 |
| SCE-904820SSFSD | 6972 | Type 12 free-standing two door | 90.00 | 48.00 | 20.00 |
| SCE-907220SSFSD | 8792 | Type 12 free-standing two door | 90.00 | 72.00 | 20.00 |
| SCE-907224SSFSD | 9236 | Type 12 free-standing two door | 90.00 | 72.00 | 24.00 |
| SCE-907236SSFSD | 10583 | Type 12 free-standing two door | 90.00 | 72.00 | 36.00 |

Ordering Example: SCE-604818FSD Type 12 free standing, two-door, single access enclosure, \$1229.



UNITED STATES

www.omega.com
1-800-TC-OMEGA
Stamford, CT.

CANADA

www.omega.ca
Laval(Quebec)
1-800-TC-OMEGA

GERMANY

www.omega.de
Deckenpfronn, Germany
0800-8266342

UNITED KINGDOM

www.omega.co.uk
Manchester, England
0800-488-488

FRANCE

www.omega.fr
Guyancourt, France
088-466-342

CZECH REPUBLIC

www.omegaeng.cz
Karviná, Czech Republic
596-311-899

BENELUX

www.omega.nl
Amstelveen, NL
0800-099-33-44



More than 100,000 Products Available!

• Temperature

Calibrators, Connectors, General Test and Measurement Instruments, Glass Bulb Thermometers, Handheld Instruments for Temperature Measurement, Ice Point References, Indicating Labels, Crayons, Cements and Lacquers, Infrared Temperature Measurement Instruments, Recorders Relative Humidity Measurement Instruments, RTD Probes, Elements and Assemblies, Temperature & Process Meters, Timers and Counters, Temperature and Process Controllers and Power Switching Devices, Thermistor Elements, Probes and Assemblies, Thermocouples Thermowells and Head and Well Assemblies, Transmitters, Wire

• Flow and Level

Air Velocity Indicators, Doppler Flowmeters, Level Measurement, Magnetic Flowmeters, Mass Flowmeters, Pitot Tubes, Pumps, Rotameters, Turbine and Paddle Wheel Flowmeters, Ultrasonic Flowmeters, Valves, Variable Area Flowmeters, Vortex Shedding Flowmeters

• pH and Conductivity

Conductivity Instrumentation, Dissolved Oxygen Instrumentation, Environmental Instrumentation, pH Electrodes and Instruments, Water and Soil Analysis Instrumentation

• Data Acquisition

Auto-Dialers and Alarm Monitoring Systems, Communication Products and Converters, Data Acquisition and Analysis Software, Data Loggers Plug-in Cards, Signal Conditioners, USB, RS232, RS485 and Parallel Port Data Acquisition Systems, Wireless Transmitters and Receivers

• Pressure, Strain and Force

Displacement Transducers, Dynamic Measurement Force Sensors, Instrumentation for Pressure and Strain Measurements, Load Cells, Pressure Gauges, Pressure Reference Section, Pressure Switches, Pressure Transducers, Proximity Transducers, Regulators, Strain Gages, Torque Transducers, Valves

• Heaters

Band Heaters, Cartridge Heaters, Circulation Heaters, Comfort Heaters, Controllers, Meters and Switching Devices, Flexible Heaters, General Test and Measurement Instruments, Heater Hook-up Wire, Heating Cable Systems, Immersion Heaters, Process Air and Duct, Heaters, Radiant Heaters, Strip Heaters, Tubular Heaters