


OMG-ULTRA-COMM422

Four Port Automatic ISA RS-422/485 Interface for DOS, Windows 3.1x/95/98/ME/NT/2000/XP and OS/2 Communications

\$319
Basic Model

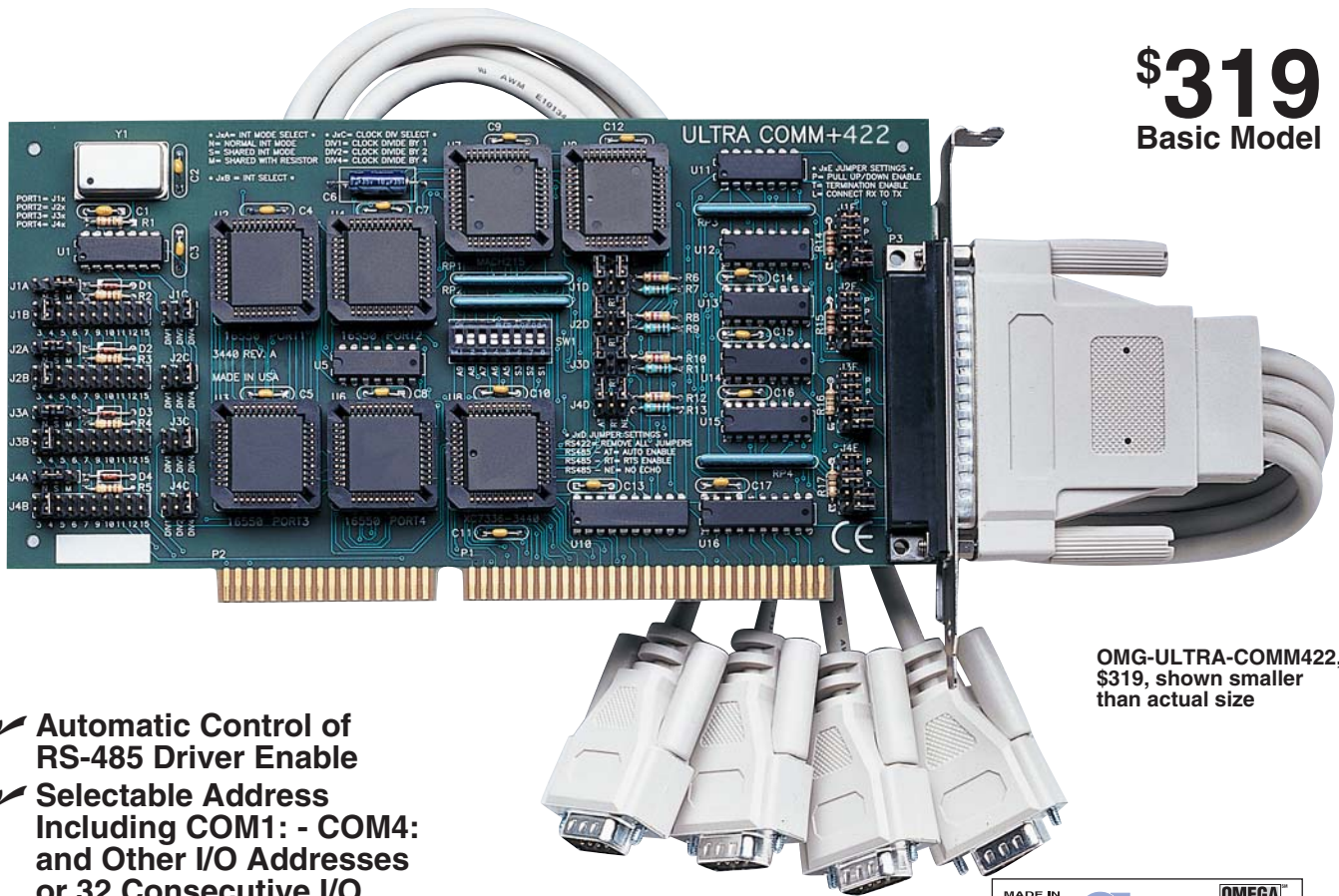

OMG-ULTRA-COMM422, \$319, shown smaller than actual size

- ✓ Automatic Control of RS-485 Driver Enable
- ✓ Selectable Address Including COM1: - COM4: and Other I/O Addresses or 32 Consecutive I/O Locations
- ✓ Selectable and Sharable IRQ Level (2-5, 7, 10-12, and 15)
- ✓ On Board Interrupt Status Port for Greater Throughput
- ✓ Compatible with Existing Communication Drivers
- ✓ Data Rates Supported up to 460K bps
- ✓ Selectable Termination, Echo Mode, Two or Four Wire Operation
- ✓ DB-9P Connectors Providing TD, RD, RTS and CTS
- ✓ Includes DOS Utilities, Windows Advanced COM: Drivers and Help Files to Simplify Installation

The OMG-ULTRA-COMM422 provides the PC with four RS-485/422 Asynchronous links to data collection or other devices. Windows 95/98/ME/NT/2000/XP drivers are included, as well as support for DOS. The drivers provide IRQ sharing, advanced UART support and serial diagnostic utilities.

Specifications
Communications Chip: 16550 UART
Number of Ports: Four RS-422/485



Max. Data Rate: 460K bps
Max. Data Distance: Up to (5000')
RS-485 Operation: two or four wire
Operating Temperature: 0 to 50°C (0 to 122°F)
Storage Temperature: -20 to 70°C (-4 to 158°F)
Humidity Range: 10 to 90% RH
Current Specifications: +5V @ 600mA
Connector(s): Onboard DB-37S to (4) DB-9P
Dimensions: 7.3 L x 4.2" H (18.54 x 10.67 cm)

AVAILABLE FOR FAST DELIVERY!

To Order (Specify Model Number)

Model Number	Price	Description
OMG-ULTRA-COMM422	\$319	Four port automatic RS-422/485 interface (spider cable included)

Comes with complete operator's manual and serial utility disk.

Ordering Example: OMG-ULTRA-COMM422 four port automatic RS-422/485 interface with spider cable, and OMEGACARESM 1-year extended warranty for OMG-ULTRA-COMM422 (adds 1 year to standard 1-year warranty), \$319 + 31 = \$350.

omega.co.uk®

Your One-Stop Source for Process Measurement and Control!

Freephone 0800 488 488 | International +44(0) 161 777 6622 | Fax +44(0) 161 777 6622 | Sales@omega.co.uk

www.omega.co.uk



UNITED STATES

www.omega.com

1-800-TC-OMEGA
Stamford, CT.

UNITED KINGDOM

www.omega.co.uk

Manchester, England
0800-488-488
+44-(0)161-777-6611

CANADA

www.omega.ca

Laval(Quebec)
1-800-TC-OMEGA

FRANCE

www.omega.fr

0800-466-342

GERMANY

www.omega.de

Deckenfronn, Germany
0800-8266342

BENELUX

www.omega.nl

0800-099-33-44



More than 100,000 Products Available!

• Temperature

Calibrators, Connectors, General Test and Measurement Instruments, Handheld Instruments for Temperature Measurement, Ice Point References, Indicating Labels, Crayons, Cements and Lacquers, Infrared Temperature Measurement Instruments, Recorders, Relative Humidity Measurement Instruments, PT100 Probes, PT100 Elements, Temperature & Process Meters, Timers and Counters, Temperature and Process Controllers and Power Switching Devices, Thermistor Elements, Probes and Assemblies, Thermocouples, Thermowells and Head and Well Assemblies, Transmitters, Thermocouple Wire, RTD Probes

• Flow and Level

Air Velocity Indicators, Doppler Flowmeters, Level Measurement, Magnetic Flowmeters, Mass Flowmeters, Pitot Tubes, Pumps, Rotameters, Turbine and Paddle Wheel Flowmeters, Ultrasonic Flowmeters, Valves, Variable Area Flowmeters, Vortex Shedding Flowmeters

• pH and Conductivity

Conductivity Instrumentation, Dissolved Oxygen Instrumentation, Environmental Instrumentation, pH Electrodes and Instruments, Water and Soil Analysis Instrumentation

• Data Acquisition

Communication Products and Converters, Data Acquisition and Analysis Software, Data Loggers Plug-in Cards, Signal Conditioners, USB, RS232, RS485, Ethernet and Parallel Port Data Acquisition Systems, Wireless Transmitters and Receivers

• Pressure, Strain and Force

Displacement Transducers, Dynamic Measurement Force Sensors, Instrumentation for Pressure and Strain Measurements, Load Cells, Pressure Gauges, Pressure Reference Section, Pressure Switches, Pressure Transducers, Proximity Transducers, Regulators, Pressure Transmitters, Strain Gauges, Torque Transducers, Valves

• Heaters

Band Heaters, Cartridge Heaters, Circulation Heaters, Comfort Heaters, Controllers, Meters and Switching Devices, Flexible Heaters, General Test and Measurement Instruments, Heater Hook-up Wire, Heating Cable Systems, Immersion Heaters, Process Air and Duct, Heaters, Radiant Heaters, Strip Heaters, Tubular Heaters