

FTTP Series
Starts at

\$35



By P/N


PFA COMPRESSION FITTINGS FOR TUBING

PFA COMPRESSION


All OMEGA® PFA fittings are equipped with the Grab-Seal System for positive sealing. Installation is quick and easy, and no tools are required. Simply cut tubing to desired length; position nut, Grab-Seal gripper, and ferrule on the tube, and tighten the nut with your fingers.

For most applications, all you need is your hand to make a positive leak-free connection. Applications include biomedical, chemical, petro-chemical, food processing, and semiconductor industries.


Straight Male Adaptor

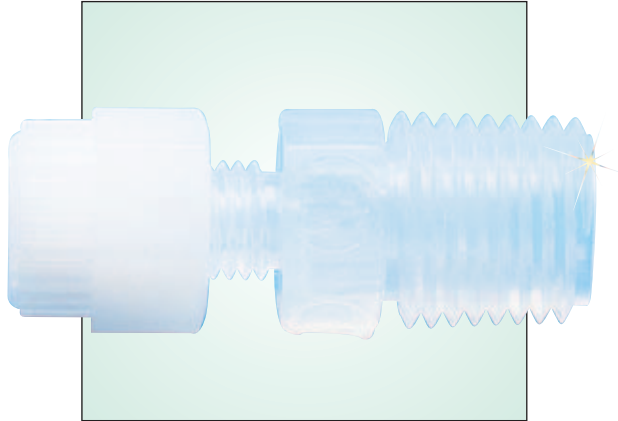

Union Elbow

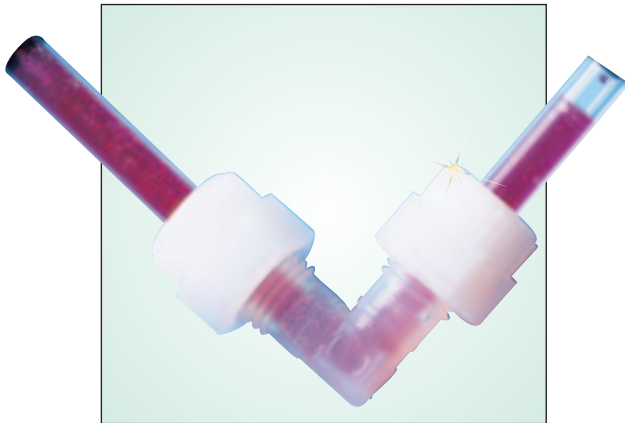

Union Reducer

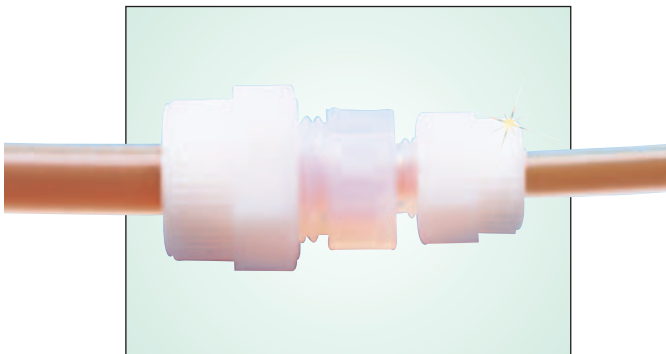

MOST POPULAR MODELS HIGHLIGHTED!

To Order (Specify Model Number)

MODEL NUMBER	PRICE EACH	TUBE OD	PIPE SIZE NPT
FTTP-22	\$35	1/8"	1/8"
FTTP-24	35	1/8"	1/4"
FTTP-42	35	1/4"	1/8"
FTTP-44	35	1/4"	1/4"
FTTP-46	35	1/4"	3/8"
FTTP-48	35	1/4"	1/2"
FTTP-62	45	3/8"	1/8"
FTTP-64	45	3/8"	1/4"
FTTP-66	50	3/8"	3/8"
FTTP-68	50	3/8"	1/2"
FTTP-84	55	1/2"	1/4"
FTTP-86	55	1/2"	3/8"
FTTP-88	55	1/2"	1/2"
FTTP-812	60	1/2"	3/4"
FTTP-128	65	3/4"	1/2"
FTTP-1212	65	3/4"	3/4"
FTTP-1216	75	3/4"	1"
FTTP-1612	120	1"	3/4"
FTTP-1616	120	1"	1"


Ordering Example: FTTP-22, 1/8" OD tube, male connector, \$25.
See pages T-13 to T-35 for a full selection of OMEGAFLEX® tubing.

MODEL NUMBER	PRICE EACH	TUBE OD
FTTP-2	\$45	1/8"
FTTP-4	50	1/4"
FTTP-6	55	3/8"
FTTP-8	70	1/2"
FTTP-12	85	3/4"
FTTP-16	130	1"


MODEL NUMBER	PRICE EACH	TUBE OD	
		OD 1	OD 2
FTTP-24U	\$55	1/8"	1/4"
FTTP-46U	60	1/4"	3/8"
FTTP-48U	65	1/4"	1/2"
FTTP-68U	70	3/8"	1/2"
FTTP-128U	75	3/4"	1/2"
FTTP-1216U	110	3/4"	1"

PFA Compression Fittings


Male Elbow

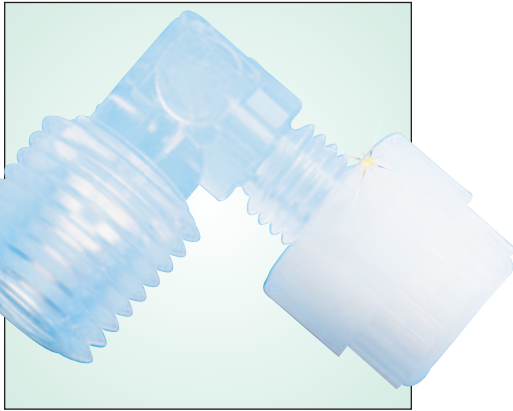


Union Panel Mount

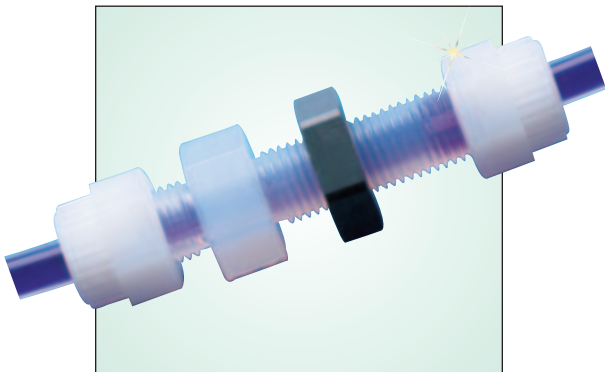

Union

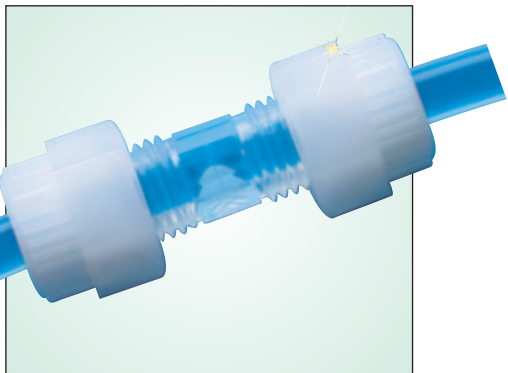

Male Branch Tee

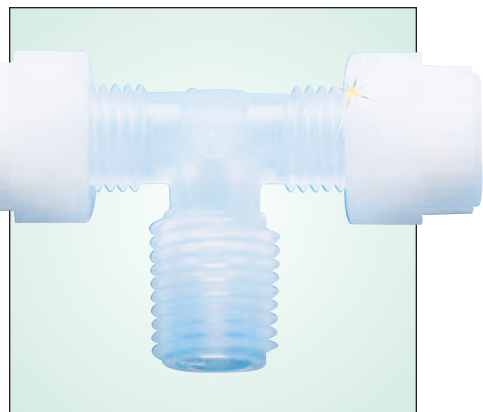

MOST POPULAR MODELS HIGHLIGHTED!

To Order (Specify Model Number)

MODEL NUMBER	PRICE EACH	TUBE OD	PIPE SIZE NPT
FTTP-22E	\$35	1/8"	1/8
FTTP-24E	35	1/8"	1/4
FTTP-42E	35	1/4"	1/8
FTTP-44E	35	1/4"	1/4
FTTP-46E	35	1/4"	3/8
FTTP-62E	45	3/8"	1/8
FTTP-64E	45	3/8"	1/4
FTTP-66E	45	3/8"	3/8
FTTP-68E	45	3/8"	1/2
FTTP-84E	50	1/2"	1/4
FTTP-86E	50	1/2"	3/8
FTTP-88E	50	1/2"	1/2
FTTP-812E	60	1/2"	3/4
FTTP-128E	65	3/4"	1/2
FTTP-1212E	65	3/4"	3/4
FTTP-1216E	75	3/4"	1
FTTP-1612E	120	1"	3/4
FTTP-1616E	120	1"	1


MODEL NUMBER	PRICE EACH	TUBE OD
FTTP-2S	\$60	1/8"
FTTP-4S	65	1/4"
FTTP-6S	75	3/8"
FTTP-8S	90	1/2"
FTTP-12S	95	3/4"
FTTP-16S	155	1"

MODEL NUMBER	PRICE EACH	TUBE OD
FTTP-2SU	\$50	1/8"
FTTP-4SU	55	1/4"
FTTP-6SU	60	3/8"
FTTP-8SU	75	1/2"
FTTP-12SU	90	3/4"
FTTP-16SU	130	1"

MODEL NUMBER	PRICE EACH	TUBE OD	PIPE SIZE NPT
FTTP-2M	\$55	1/8"	1/8
FTTP-4M	55	1/4"	1/4
FTTP-6M	60	3/8"	3/8
FTTP-8M	75	1/2"	1/2
FTTP-12M	90	3/4"	3/4
FTTP-16M	140	1"	1

Ordering Example: FTTP-16M, 1" OD tube, male branch tee, \$140.

Male Run Tee

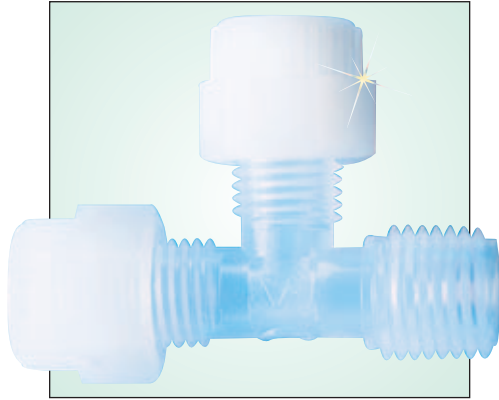


MOST POPULAR MODELS HIGHLIGHTED!

To Order (Specify Model Number)

MODEL NUMBER	PRICE EACH	TUBE OD	PIPE SIZE NPTF
FTTP-2MR	\$50	1/8"	1/8"
FTTP-4MR	50	1/4"	1/4"
FTTP-6MR	60	3/8"	3/8"
FTTP-8MR	75	1/2"	1/2"
FTTP-12MR	90	3/4"	3/4"
FTTP-16MR	150	1"	1"


PFA Tube Accessories

 Nut




MODEL NUMBER	PRICE EACH	TUBE OD
FTTP-2N	\$15	1/8"
FTTP-4N	15	1/4"
FTTP-6N	20	3/8"
FTTP-8N	20	1/2"
FTTP-12N	30	3/4"
FTTP-16N	45	1"

Grab-Seal Gripper

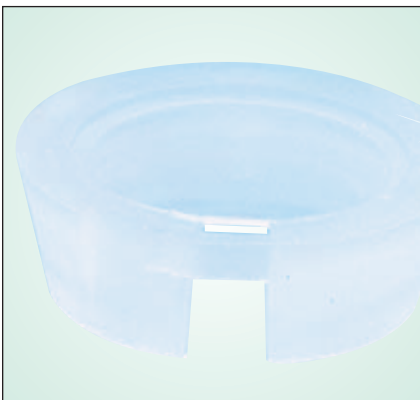

MODEL NUMBER	PRICE EACH	TUBE OD
FTTP-2G	\$10	1/8"
FTTP-4G	10	1/4"
FTTP-6G	10	3/8"
FTTP-8G	10	1/2"
FTTP-12G	10	3/4"
FTTP-16G	30	1"


Grab-Seal Ferrule

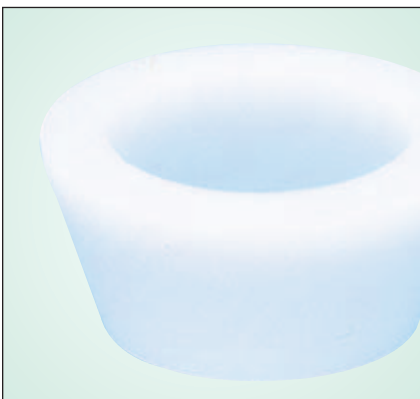

MODEL NUMBER	PRICE EACH	TUBE OD
FTTP-2F	\$10	1/8"
FTTP-4F	10	1/4"
FTTP-6F	10	3/8"
FTTP-8F	10	1/2"
FTTP-12F	10	3/4"
FTTP-16F	25	1"

Ordering Example: FTTP-2N, nut for 1/8" OD tubing, \$15.

 Plug




MOST POPULAR MODELS HIGHLIGHTED!

To Order (Specify Model Number)

MODEL NUMBER	PRICE EACH	TUBE SIZE
FTTP-2P	\$15	1/8"
FTTP-4P	20	1/4"
FTTP-6P	20	3/8"
FTTP-8P	25	1/2"
FTTP-12P	55	3/4"
FTTP-16P	65	1"

Panel Nut


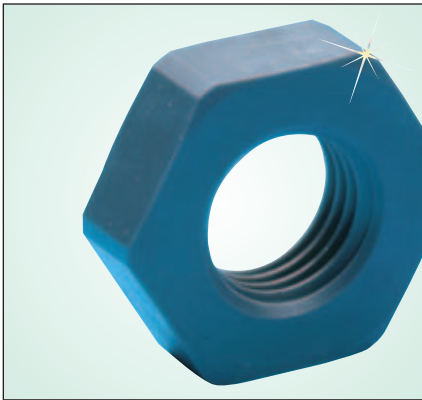


MODEL NUMBER	PRICE EACH	TUBE OD	HEX FLAT
FTTP-2PN	\$15	1/8"	3/4"
FTTP-4PN	15	1/4"	3/4"
FTTP-6PN	20	3/8"	1"
FTTP-8PN	20	1/2"	1 1/4"
FTTP-12PN	30	3/4"	1 5/8"

Ordering Example: FTTP-4PN, panel nut for 1/4" tube OD, \$15.

PFA Tube Accessories

1. Cut tubing to desired length.
2. Loosen the nut, insert tube (the pre-assembled fitting should be ready for use).
3. Tighten the nut.
4. The fitting is now ready for use. No tools are required, but if you decide to use a mechanical device to tighten it, rotate the nut no more than a 1/2 turn past finger-tight.

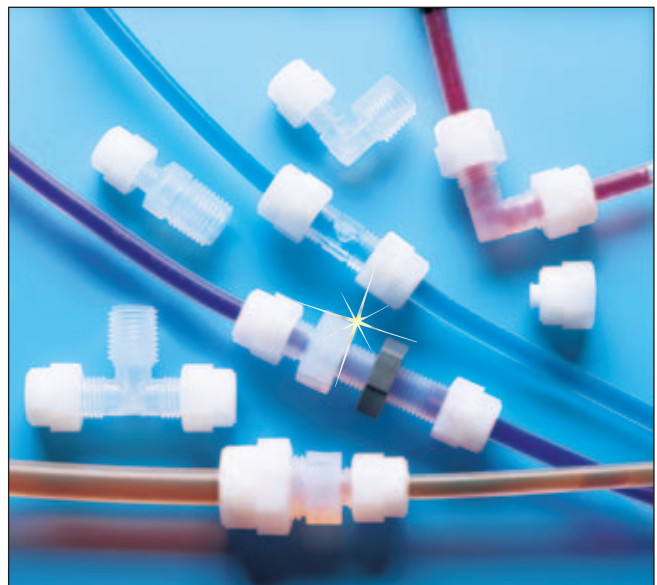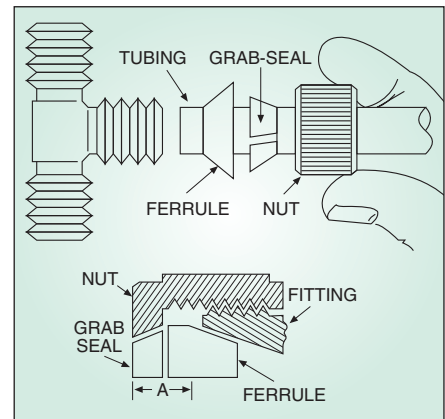

omega.co.uk[®]

Your One-Stop Source for Process Measurement and Control!

Freephone 0800 488 488 | International +44(0) 161 777 6622 | Fax +44(0) 161 777 6622 | Sales@omega.co.uk

www.omega.co.uk



UNITED STATES

www.omega.com

1-800-TC-OMEGA
Stamford, CT.

UNITED KINGDOM

www.omega.co.uk

Manchester, England
0800-488-488
+44-(0)161-777-6611

CANADA

www.omega.ca

Laval(Quebec)
1-800-TC-OMEGA

FRANCE

www.omega.fr

0800-466-342

GERMANY

www.omega.de

Deckenfronn, Germany
0800-8266342

BENELUX

www.omega.nl

0800-099-33-44



More than 100,000 Products Available!

• Temperature

Calibrators, Connectors, General Test and Measurement Instruments, Handheld Instruments for Temperature Measurement, Ice Point References, Indicating Labels, Crayons, Cements and Lacquers, Infrared Temperature Measurement Instruments, Recorders, Relative Humidity Measurement Instruments, PT100 Probes, PT100 Elements, Temperature & Process Meters, Timers and Counters, Temperature and Process Controllers and Power Switching Devices, Thermistor Elements, Probes and Assemblies, Thermocouples, Thermowells and Head and Well Assemblies, Transmitters, Thermocouple Wire, RTD Probes

• Flow and Level

Air Velocity Indicators, Doppler Flowmeters, Level Measurement, Magnetic Flowmeters, Mass Flowmeters, Pitot Tubes, Pumps, Rotameters, Turbine and Paddle Wheel Flowmeters, Ultrasonic Flowmeters, Valves, Variable Area Flowmeters, Vortex Shedding Flowmeters

• pH and Conductivity

Conductivity Instrumentation, Dissolved Oxygen Instrumentation, Environmental Instrumentation, pH Electrodes and Instruments, Water and Soil Analysis Instrumentation

• Data Acquisition

Communication Products and Converters, Data Acquisition and Analysis Software, Data Loggers Plug-in Cards, Signal Conditioners, USB, RS232, RS485, Ethernet and Parallel Port Data Acquisition Systems, Wireless Transmitters and Receivers

• Pressure, Strain and Force

Displacement Transducers, Dynamic Measurement Force Sensors, Instrumentation for Pressure and Strain Measurements, Load Cells, Pressure Gauges, Pressure Reference Section, Pressure Switches, Pressure Transducers, Proximity Transducers, Regulators, Pressure Transmitters, Strain Gauges, Torque Transducers, Valves

• Heaters

Band Heaters, Cartridge Heaters, Circulation Heaters, Comfort Heaters, Controllers, Meters and Switching Devices, Flexible Heaters, General Test and Measurement Instruments, Heater Hook-up Wire, Heating Cable Systems, Immersion Heaters, Process Air and Duct, Heaters, Radiant Heaters, Strip Heaters, Tubular Heaters