

OMEGALEVEL™ CUSTOM SWITCH KITS

DRUM LEVEL INDICATORS

LV-120
Starts at
\$297



- ✓ Easily Customized for Individual Applications
- ✓ Level Switch Kit Features a User-Selectable Normally Open or Normally Closed SPST 20 VA Switch
- ✓ OMEGA LEVEL™ Kit is Expandable to 6 Level Stations



LV-120 (complete drum indicator kit), \$297, shown smaller than actual size.

The LV-120 Series OMEGA LEVEL™ custom switch kits can be assembled and installed vertically in your tank in minutes. Each kit contains all the components for complete assembly of a 1- or 2-station level switch for pipe-plug mounting. Additional level stations may be added (see accessories).

Each Kit Includes:

- 2 level stations (switch, tube, float)
- 1 tube connector
- 1 mounting plug
- 1 tube end fitting
- 3 tube unions
- 2 tube lengths (10")

SPECIFICATIONS

Temperature Range:

LV-121: -17 to 135°C (0 to 275°F);
LV-120: 0.6 to 82°C (33 to 180°F)
in water, -17 to 110°C (0 to 230°F) in oil

Pressure Rating:

316 SS Float: 750 psi
Buna-N Float: 150 psi

Mounting: 2 NPT

Tube/Fitting Size:
½" OD tube

Mounting Attitude:


Vertical ±30°

Lead Wire:

60", 20 AWG,
Teflon® insulated

Max Assembled

Length: 30"
(approx.)

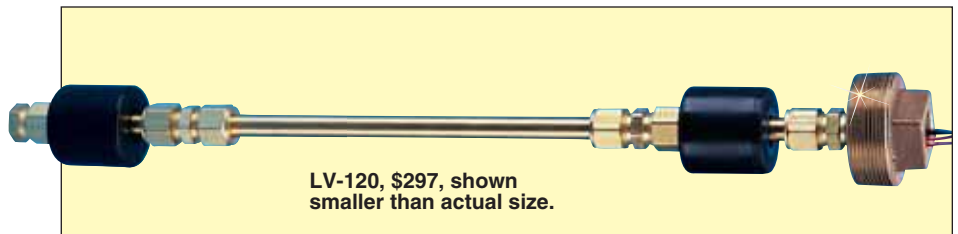

LV-120, \$297, shown smaller than actual size.

To determine fluid specific gravity, add 0.1 to float specific gravity in clean liquids and 0.3 to float specific gravity in dirty or viscous liquids.

See chart on page K-4 for maximum voltage/current ratings.

MOST POPULAR MODEL HIGHLIGHTED!

To Order (Specify Model Number)				
Model No.	Price	Length	Stem/Float	Float Specific Gravity
LV-120	\$297	—	Brass/Buna-N	0.55
LV-121	621	—	316 SS	0.65

OMEGALEVEL™ ACCESSORIES

To Order (Specify Model Number)		
Model No.	Price	Description
SS-12-10-0	\$25	316 SS tube, ½" OD x 10" L
BR-12-10-0	21	Brass tube, ½" OD x 10" L
LV-125	57	Brass/Buna-N float station
LV-126	98	316 SS float station
SS-U-12	90	316 SS ½" tube union
BR-U-12	36	Brass ½" tube union

Ordering Example: LV-121, complete OMEGA LEVEL™ drum level indicator kit with stainless steel stem and float, \$621.

omega.co.uk[®]

Your One-Stop Source for Process Measurement and Control!

Freephone 0800 488 488 | International +44(0) 161 777 6622 | Fax +44(0) 161 777 6622 | Sales@omega.co.uk

www.omega.co.uk



UNITED STATES

www.omega.com

1-800-TC-OMEGA
Stamford, CT.

UNITED KINGDOM

www.omega.co.uk

Manchester, England
0800-488-488
+44-(0)161-777-6611

CANADA

www.omega.ca

Laval(Quebec)
1-800-TC-OMEGA

FRANCE

www.omega.fr

0800-466-342

GERMANY

www.omega.de

Deckenfronn, Germany
0800-8266342

BENELUX

www.omega.nl

0800-099-33-44



More than 100,000 Products Available!

• Temperature

Calibrators, Connectors, General Test and Measurement Instruments, Handheld Instruments for Temperature Measurement, Ice Point References, Indicating Labels, Crayons, Cements and Lacquers, Infrared Temperature Measurement Instruments, Recorders, Relative Humidity Measurement Instruments, PT100 Probes, PT100 Elements, Temperature & Process Meters, Timers and Counters, Temperature and Process Controllers and Power Switching Devices, Thermistor Elements, Probes and Assemblies, Thermocouples, Thermowells and Head and Well Assemblies, Transmitters, Thermocouple Wire, RTD Probes

• Flow and Level

Air Velocity Indicators, Doppler Flowmeters, Level Measurement, Magnetic Flowmeters, Mass Flowmeters, Pitot Tubes, Pumps, Rotameters, Turbine and Paddle Wheel Flowmeters, Ultrasonic Flowmeters, Valves, Variable Area Flowmeters, Vortex Shedding Flowmeters

• pH and Conductivity

Conductivity Instrumentation, Dissolved Oxygen Instrumentation, Environmental Instrumentation, pH Electrodes and Instruments, Water and Soil Analysis Instrumentation

• Data Acquisition

Communication Products and Converters, Data Acquisition and Analysis Software, Data Loggers Plug-in Cards, Signal Conditioners, USB, RS232, RS485, Ethernet and Parallel Port Data Acquisition Systems, Wireless Transmitters and Receivers

• Pressure, Strain and Force

Displacement Transducers, Dynamic Measurement Force Sensors, Instrumentation for Pressure and Strain Measurements, Load Cells, Pressure Gauges, Pressure Reference Section, Pressure Switches, Pressure Transducers, Proximity Transducers, Regulators, Pressure Transmitters, Strain Gauges, Torque Transducers, Valves

• Heaters

Band Heaters, Cartridge Heaters, Circulation Heaters, Comfort Heaters, Controllers, Meters and Switching Devices, Flexible Heaters, General Test and Measurement Instruments, Heater Hook-up Wire, Heating Cable Systems, Immersion Heaters, Process Air and Duct, Heaters, Radiant Heaters, Strip Heaters, Tubular Heaters