



COMPACT ULTRASONIC, SOLID STATE LIQUID LEVEL SWITCH

LVU-A710 Series
Starts at


\$157




- ✓ Easy to Install
- ✓ No Moving Parts
- ✓ Epoxy-Sealed Integral Electronics with Sensor
- ✓ Low-Cost Replacement to Mechanical Float

The LVU-A710 Series compact solid state liquid level switch is a great replacement for mechanical float-type liquid level devices. The switch employs proven ultrasonic technology and solid state integral electronics in a small package.

The LVU-A710 Series provides reliable operation in virtually any liquid, regardless of viscosity. This eliminates problems of stickiness and failure rate due to finite mechanical life inherent in the mechanical float design. The combination of fully epoxy-sealed electronics and ultrasonic sensing technology will provide years of maintenance-free service.

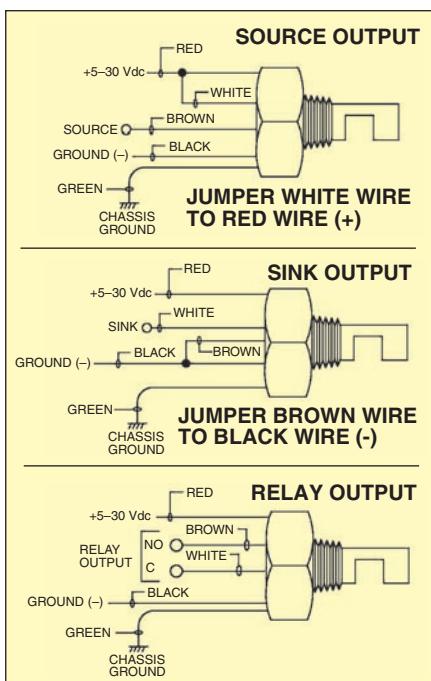

LVU-A713, \$157, shown larger than actual size.

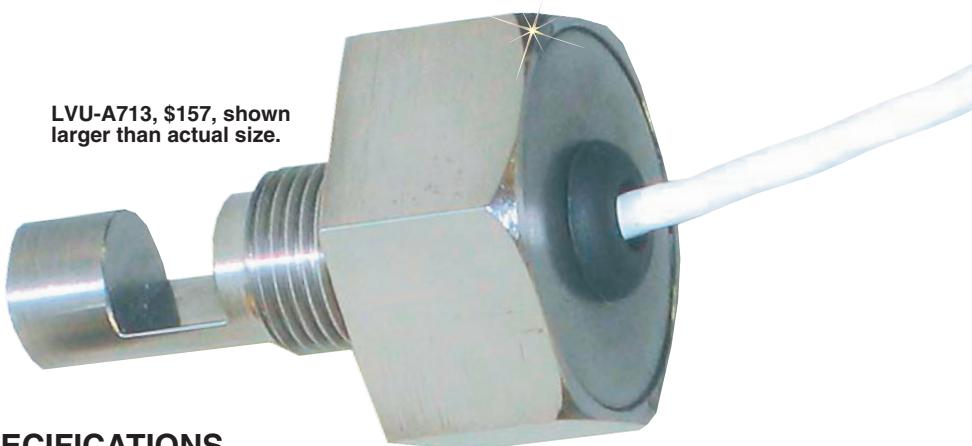

SPECIFICATIONS

Repeatability: 2 mm or better

Delay: 0.5 sec

Input Power: 5 to 30 Vdc

Leakage Current: Less than 50 uA

Outputs:

Source: 100 mA max

Sink: 100 mA max

Relay Output: 1 A SPST (NO, C)

Protection: Transient, reverse polarity

Sensor: 316 LSS


Temperature: -29 to 80°C (-20 to 176°F)

Pressure: Up to 1000 psig (6895 kPa)


Mounting: 1/4 or 1/2 NPT (depending on model number)

Dimensions: mm (in)

LVU-A711, 712, 713

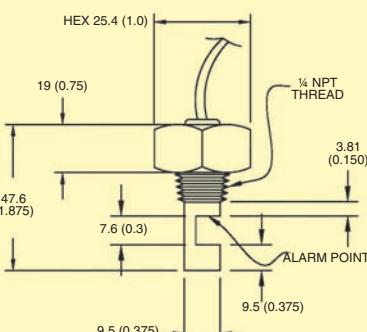

LVU-A714, 715, 716

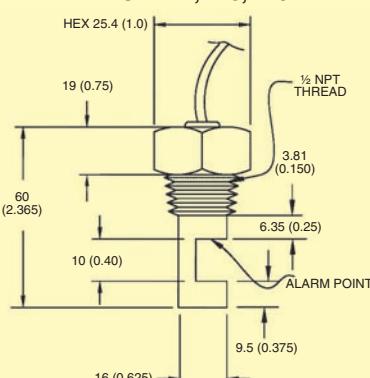

MOST POPULAR MODELS HIGHLIGHTED!

To Order (Specify Model Number)

Model No.	Price	Description
LVU-A711	\$157	1/4 NPT level switch, 316 LSS sinking output
LVU-A712	157	1/4 NPT level switch, 316 LSS sourcing output
LVU-A713	157	1/4 NPT level switch, 316 LSS SPST NO relay
LVU-A714	180	1/2 NPT level switch, 316 LSS sinking output
LVU-A715	180	1/2 NPT level switch, 316 LSS sourcing output
LVU-A716	180	1/2 NPT level switch, 316 LSS SPST NO relay

Accessories

Model No.	Price	Description
PSW-93	\$40	Unregulated 24 Vdc power supply
CM-0490	175	Reference Book: Chemical Process Equipment

Comes complete with operator's manual.

Ordering Examples: LVU-A713, 316 LSS, 1/4 NPT, 1A SPST relay ultrasonic switch, **\$157**.
LVU-A716, 316 LSS, 1/2 NPT, 1A SPST relay ultrasonic switch, **\$180**.





UNITED STATES

www.omega.com

1-800-TC-OMEGA
Stamford, CT.

CANADA

www.omega.ca

Laval(Quebec)
1-800-TC-OMEGA

GERMANY

www.omega.de

Deckenpfronn, Germany
0800-8266342

UNITED KINGDOM

www.omega.co.uk

Manchester, England
0800-488-488
+44-(0)161-777-6611

FRANCE

www.omega.fr

0800-466-342

BENELUX

www.omega.nl

0800-099-33-44



More than 100,000 Products Available!

• Temperature

Calibrators, Connectors, General Test and Measurement Instruments, Handheld Instruments for Temperature Measurement, Ice Point References, Indicating Labels, Crayons, Cements and Lacquers, Infrared Temperature Measurement Instruments, Recorders, Relative Humidity Measurement Instruments, PT100 Probes, PT100 Elements, Temperature & Process Meters, Timers and Counters, Temperature and Process Controllers and Power Switching Devices, Thermistor Elements, Probes and Assemblies, Thermocouples, Thermowells and Head and Well Assemblies, Transmitters, Thermocouple Wire, RTD Probes

• Flow and Level

Air Velocity Indicators, Doppler Flowmeters, Level Measurement, Magnetic Flowmeters, Mass Flowmeters, Pitot Tubes, Pumps, Rotameters, Turbine and Paddle Wheel Flowmeters, Ultrasonic Flowmeters, Valves, Variable Area Flowmeters, Vortex Shedding Flowmeters

• pH and Conductivity

Conductivity Instrumentation, Dissolved Oxygen Instrumentation, Environmental Instrumentation, pH Electrodes and Instruments, Water and Soil Analysis Instrumentation

• Data Acquisition

Communication Products and Converters, Data Acquisition and Analysis Software, Data Loggers, Plug-in Cards, Signal Conditioners, USB, RS232, RS485, Ethernet and Parallel Port Data Acquisition Systems, Wireless Transmitters and Receivers

• Pressure, Strain and Force

Displacement Transducers, Dynamic Measurement Force Sensors, Instrumentation for Pressure and Strain Measurements, Load Cells, Pressure Gauges, Pressure Reference Section, Pressure Switches, Pressure Transducers, Proximity Transducers, Regulators, Pressure Transmitters, Strain Gauges, Torque Transducers, Valves

• Heaters

Band Heaters, Cartridge Heaters, Circulation Heaters, Comfort Heaters, Controllers, Meters and Switching Devices, Flexible Heaters, General Test and Measurement Instruments, Heater Hook-up Wire, Heating Cable Systems, Immersion Heaters, Process Air and Duct, Heaters, Radiant Heaters, Strip Heaters, Tubular Heaters