



# INDUSTRIAL pH INSTRUMENTATION & ELECTRODES

## General Purpose 1/2 MNPT pH Sensor

PHE-7357-10  
\$100



### Applications

- ✓ Potable Water Supplies
- ✓ Cooling Towers
- ✓ Fresh and Salt Water Aquariums
- ✓ Secondary Treated Waste Water

The PHE-7357 sensor is designed for use in most water and waste water applications. The large reservoir of reference electrolyte, coupled with the non-fouling nature of the Porous PTFE liquid junction, assures a long life in general service.


The sensor body reduces the risk of accidental breakage during installation and maintenance by the inclusion of protective lobes around the sensing element. Also available for ORP measurement.

Use of the high temperature version is recommended where service temperatures exceed 80°C (176°F).

PHE-5551 is a double-junction construction with solution ground in a robust PPS Ryton® housing, being highly resistant to electrode poisoning solutions. Standard on these electrodes is a 110°C (230°F) rating.

### Specifications

**pH Range:** 0 to 14 pH  
**Temperature Range:**  
 0°C to 80°C (32 to 176°F) (standard)  
 0°C to 110°C (32 to 230°F) (high temperature)  
**Pressure Range:** 0 to 100 psig  
**Accuracy:** ±0.1% over full range  
**Impedance:** 80 MΩ (standard version)  
 150 MΩ (high temperature version)  
**Reference Cell:**  
 Single junction, KCl/AgCl  
**Reference Junction:** Porous PTFE  
**Wetted Materials:**  
 PPS, PTFE, glass, 316 SS  
**Response Time:**  
 95% of reading in 10 seconds  
**Drift:** Less than 2 mV per week

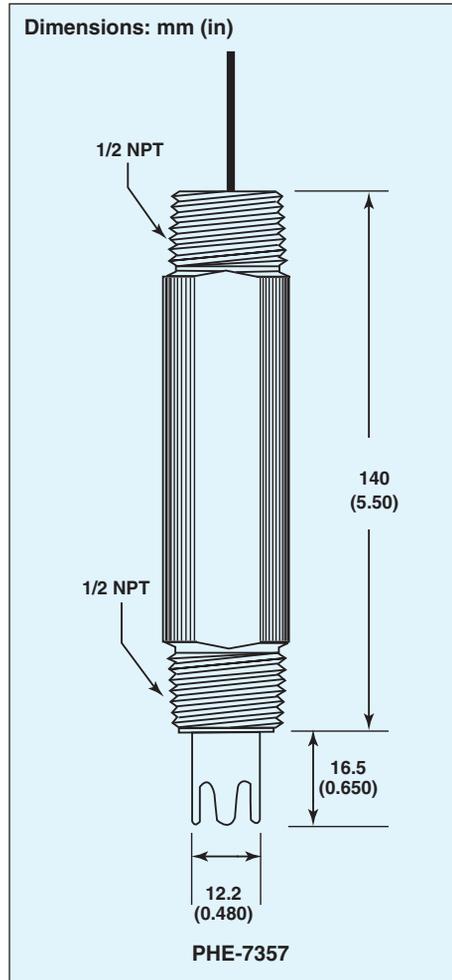

PHE-7357-10, \$100, shown smaller than actual size.

PHE-5551-10, \$125, shown smaller than actual size.

**MOST POPULAR MODEL HIGHLIGHTED!**

### To Order (Specify Model Number)

Model No.	Price	Price w/ATC	Description
PHE-7357-10	\$100	—	General purpose pH sensor
PHE-5551-10-(*)	125	\$165	General purpose pH sensor with solution ground
ORE-7357-10	125	—	ORP probe for clean water
ORE-5551-10	165	—	ORP probe for clean water with solution ground

\* Insert option code from table below.

### Option Code

Order Suffix	Description	Additional Price
-HF	HF/Fluoride resistant	\$50
-HT	High temperature reference cell, standard on PHE/ORE-5551	35
-NA	Na <sup>+</sup> /Sodium ion selective electrode	125

Specify ATC sensor for PHE-5551-10-(\*) only: "-PT100" for 100 Ω Pt RTD or "-PT1K" for 1000 Ω Pt RTD. Comes with standard 4.5 m (15') cable.

**Ordering Examples:** PHE-5551-10-PT1K, general purpose sensor with 1/2 MNPT pH sensor with 1 KΩ Pt RTD ATC and 3 m (10') cable, \$165.

ORE-5551-10, ORP electrode, \$165.

# omega.co.uk<sup>®</sup>

Your One-Stop Source for Process Measurement and Control!

Freephone 0800 488 488 | International +44(0) 161 777 6622 | Fax +44(0) 161 777 6622 | Sales@omega.co.uk

[www.omega.co.uk](http://www.omega.co.uk)



#### UNITED STATES

[www.omega.com](http://www.omega.com)

1-800-TC-OMEGA  
Stamford, CT.

#### UNITED KINGDOM

[www.omega.co.uk](http://www.omega.co.uk)

Manchester, England  
0800-488-488  
+44-(0)161-777-6611

#### CANADA

[www.omega.ca](http://www.omega.ca)

Laval(Quebec)  
1-800-TC-OMEGA

#### FRANCE

[www.omega.fr](http://www.omega.fr)

0800-466-342

#### GERMANY

[www.omega.de](http://www.omega.de)

Deckenfronn, Germany  
0800-8266342

#### BENELUX

[www.omega.nl](http://www.omega.nl)

0800-099-33-44



## More than 100,000 Products Available!

### • Temperature

Calibrators, Connectors, General Test and Measurement Instruments, Handheld Instruments for Temperature Measurement, Ice Point References, Indicating Labels, Crayons, Cements and Lacquers, Infrared Temperature Measurement Instruments, Recorders, Relative Humidity Measurement Instruments, PT100 Probes, PT100 Elements, Temperature & Process Meters, Timers and Counters, Temperature and Process Controllers and Power Switching Devices, Thermistor Elements, Probes and Assemblies, Thermocouples, Thermowells and Head and Well Assemblies, Transmitters, Thermocouple Wire, RTD Probes

### • Flow and Level

Air Velocity Indicators, Doppler Flowmeters, Level Measurement, Magnetic Flowmeters, Mass Flowmeters, Pitot Tubes, Pumps, Rotameters, Turbine and Paddle Wheel Flowmeters, Ultrasonic Flowmeters, Valves, Variable Area Flowmeters, Vortex Shedding Flowmeters

### • pH and Conductivity

Conductivity Instrumentation, Dissolved Oxygen Instrumentation, Environmental Instrumentation, pH Electrodes and Instruments, Water and Soil Analysis Instrumentation

### • Data Acquisition

Communication Products and Converters, Data Acquisition and Analysis Software, Data Loggers Plug-in Cards, Signal Conditioners, USB, RS232, RS485, Ethernet and Parallel Port Data Acquisition Systems, Wireless Transmitters and Receivers

### • Pressure, Strain and Force

Displacement Transducers, Dynamic Measurement Force Sensors, Instrumentation for Pressure and Strain Measurements, Load Cells, Pressure Gauges, Pressure Reference Section, Pressure Switches, Pressure Transducers, Proximity Transducers, Regulators, Pressure Transmitters, Strain Gauges, Torque Transducers, Valves

### • Heaters

Band Heaters, Cartridge Heaters, Circulation Heaters, Comfort Heaters, Controllers, Meters and Switching Devices, Flexible Heaters, General Test and Measurement Instruments, Heater Hook-up Wire, Heating Cable Systems, Immersion Heaters, Process Air and Duct, Heaters, Radiant Heaters, Strip Heaters, Tubular Heaters