



Electrode Adaptors, Connectors and Fill Solutions




Meter Adaptors

	Model No.	Converts Meter From	To Electrode Type	Price
A	PHMA-UB	U.S. Standard	BNC	\$23
B	PHMA-BU	BNC	U.S. Standard	40
C	PHMA-RB	Radiometer	BNC	28
D	PHMA-CB	Corning 5 & 6	BNC	35
E	PHMA-CU	Corning 5 & 6	U.S. Standard	46

Extension Cables for BNC Electrodes

MOST POPULAR MODELS HIGHLIGHTED!

Model No.	Price	Cable Length
PHEC-B3	\$22	1 m (3')
PHEC-B10	27	3 m (10')
PHEC-B10HD	40	3 m (10'), heavy duty
PHEC-B25HD	64	7.6 m (25'), heavy duty
PHEC-B50HD	102	15.2 m (50'), heavy duty

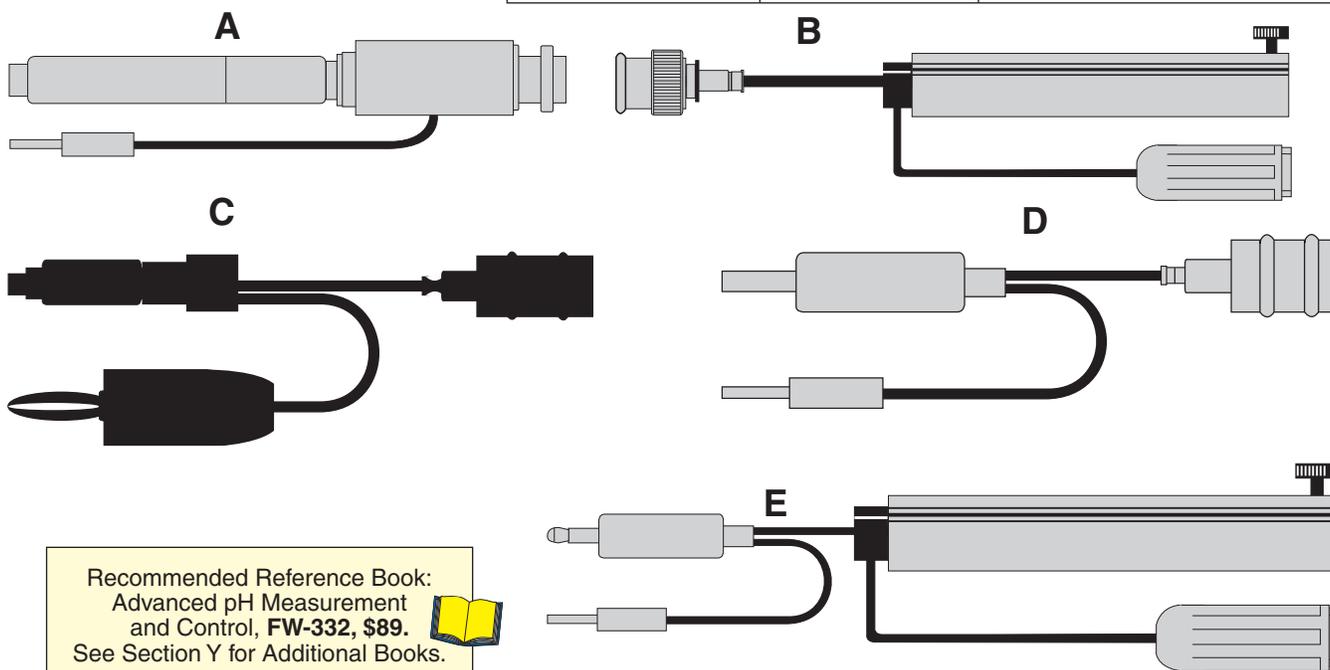

Recommended Reference Book:
Advanced pH Measurement
and Control, **FW-332, \$89.**
See Section Y for Additional Books.



Filling Solutions for Electrodes

MOST POPULAR MODELS HIGHLIGHTED!

Model No.	Description	Uses	Price
PHFS-A500	KCl/AgCl solution, 475 mL bottle with spout	Filling solution for Ag/AgCl reference 3.8 Molar KCl saturated with Ag ⁺	\$40
PHFS-A250	KCl/AgCl solution, 250 mL bottle with spout		18
PHFS-B250	10% KNO ₃ solution, 250 mL bottle with spout	Filling solution used as salt bridge in some double junction electrodes	21
PHFS-C500	3.8 M KCl solution, 475 mL bottle with spout	Filling solution for Calomel electrode and use as salt bridge in some double junction electrodes	26
PHFS-C250	3.8 M KCl solution, 250 mL bottle with spout		18

Ordering Examples: PHFS-A500, KCl/AgCl solution, 475 mL bottle with spout, \$40.
PHEC-B10, 3 m (10') pH extension cable, \$27.

omega.co.uk[®]

Your One-Stop Source for Process Measurement and Control!

Freephone 0800 488 488 | International +44(0) 161 777 6622 | Fax +44(0) 161 777 6622 | Sales@omega.co.uk

www.omega.co.uk



UNITED STATES

www.omega.com

1-800-TC-OMEGA
Stamford, CT.

CANADA

www.omega.ca

Laval(Quebec)
1-800-TC-OMEGA

GERMANY

www.omega.de

Deckenfronn, Germany
0800-8266342

UNITED KINGDOM

www.omega.co.uk

Manchester, England
0800-488-488
+44-(0)161-777-6611

FRANCE

www.omega.fr

0800-466-342

BENELUX

www.omega.nl

0800-099-33-44



More than 100,000 Products Available!

• Temperature

Calibrators, Connectors, General Test and Measurement Instruments, Handheld Instruments for Temperature Measurement, Ice Point References, Indicating Labels, Crayons, Cements and Lacquers, Infrared Temperature Measurement Instruments, Recorders, Relative Humidity Measurement Instruments, PT100 Probes, PT100 Elements, Temperature & Process Meters, Timers and Counters, Temperature and Process Controllers and Power Switching Devices, Thermistor Elements, Probes and Assemblies, Thermocouples, Thermowells and Head and Well Assemblies, Transmitters, Thermocouple Wire, RTD Probes

• Flow and Level

Air Velocity Indicators, Doppler Flowmeters, Level Measurement, Magnetic Flowmeters, Mass Flowmeters, Pitot Tubes, Pumps, Rotameters, Turbine and Paddle Wheel Flowmeters, Ultrasonic Flowmeters, Valves, Variable Area Flowmeters, Vortex Shedding Flowmeters

• pH and Conductivity

Conductivity Instrumentation, Dissolved Oxygen Instrumentation, Environmental Instrumentation, pH Electrodes and Instruments, Water and Soil Analysis Instrumentation

• Data Acquisition

Communication Products and Converters, Data Acquisition and Analysis Software, Data Loggers Plug-in Cards, Signal Conditioners, USB, RS232, RS485, Ethernet and Parallel Port Data Acquisition Systems, Wireless Transmitters and Receivers

• Pressure, Strain and Force

Displacement Transducers, Dynamic Measurement Force Sensors, Instrumentation for Pressure and Strain Measurements, Load Cells, Pressure Gauges, Pressure Reference Section, Pressure Switches, Pressure Transducers, Proximity Transducers, Regulators, Pressure Transmitters, Strain Gauges, Torque Transducers, Valves

• Heaters

Band Heaters, Cartridge Heaters, Circulation Heaters, Comfort Heaters, Controllers, Meters and Switching Devices, Flexible Heaters, General Test and Measurement Instruments, Heater Hook-up Wire, Heating Cable Systems, Immersion Heaters, Process Air and Duct, Heaters, Radiant Heaters, Strip Heaters, Tubular Heaters