

HEAVY DUTY IMMERSION HEATER WITH INTEGRAL THERMOSTAT— 2.5 NPT FITTING

ARMTS-3 Series
Starts at

\$1213



- ✓ Passivated Stainless Steel Wetted
- ✓ 3 Element Heater Design
- ✓ 208, 240, or 480 Vac;
3 Phase Power
- ✓ 3 to 18 kW
- ✓ For Process Water Applications

SPECIFICATIONS

Wattage: 3 to 18 kW


Power: 208, 240 or 480 V;
3 phase power

Sheath: Passivated stainless steel

Screw Plug: 2½ NPT passivated
stainless steel

Thermostat: Bulb and capillary

Enclosure: General purpose,
NEMA-1 rated, or type E2 moisture
resistant/explosion resistant enclosure

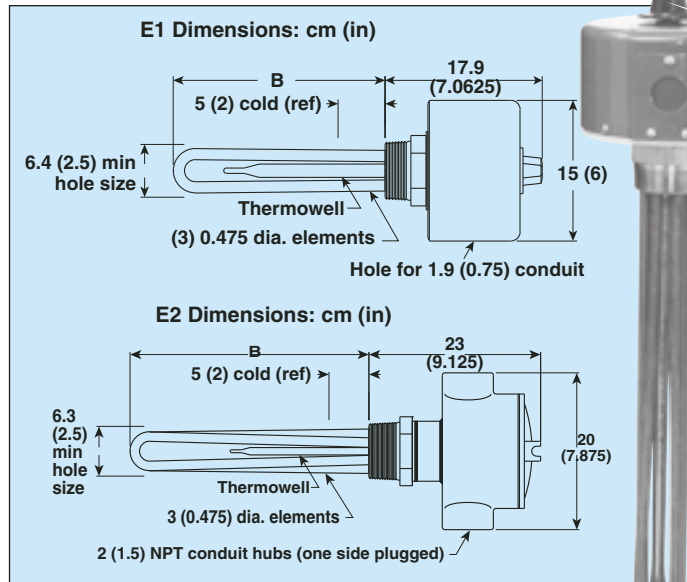

CAUTION AND WARNING!

Fire and electrical shock may result if products are used improperly or installed or used by non-qualified personnel.

ARMTS-3305/240,
\$1145, shown
smaller than
actual size.

ARMTS-3305E2/240,
\$1379, shown smaller
than actual size.

Note: The integral thermostat functions as a temperature control only. This is not a fail safe device. An approved pressure or temperature control should be used with these heaters to assure safe operation. See Section P for our selection of control devices.

AVAILABLE FOR FAST DELIVERY!

To Order (Specify Model Number)

kW	Phase	W/in²	No. Htg. Elem.	Dim. B cm (in)	T-2 Temp Range (60 to 250°F)			T-1 Temp Range (0 to 100°F)		
					Model No.	Price	Weight kg (lb)	Model No.	Price	Weight kg (lb)
ARMTS-3 with General Purpose Terminal Enclosure										
3	3	51	3	18 (7)	ARMTS-3305/*	\$1145	4 (8)	ARMTS-3305T1/*	\$1145	4 (8)
4.5	3	48	3	28 (11)	ARMTS-3455/*	1213	4 (8)	ARMTS-3455T1/*	1213	4 (8)
6	3	48	3	43 (17)	ARMTS-3605/*	1278	4 (9)	ARMTS-3605T1/*	1278	4 (9)
7.5	3	53	3	47 (8.5)	ARMTS-3755/*	1330	5 (10)	ARMTS-3755T1/*	1330	5 (10)
9	3	47	3	61 (24)	ARMTS-3905/*	1411	5 (10)	ARMTS-3905T1/*	1411	5 (10)
12	3	46	3	81 (32)	ARMTS-3120/*	1547	4 (11)	ARMTS-3120T1/*	1547	4 (11)
15	3	46	3	100 (39.5)	ARMTS-3150/*	1679	5 (12)	ARMTS-3150T1/*	1679	5 (12)
18	3	51	3	119 (47)	¹ARMTS-3180/*	1779	6 (13)	¹ARMTS-3180T1/*	1779	6 (13)
ARMTS-3 with Moisture Resistant/Explosion Resistant Enclosure (Type E2)										
3	3	51	3	18 (7)	ARMTS-3305E2/*	\$1379	6 (13)	ARMTS-3305E2T1/*	\$1379	6 (13)
4.5	3	48	3	28 (11)	ARMTS-3455E2/*	1447	6 (13)	ARMTS-3455E2T1/*	1447	6 (13)
6	3	48	3	43 (17)	ARMTS-3605E2/*	1512	5 (12)	ARMTS-3605E2T1/*	1512	6 (14)
7.5	3	53	3	47 (8.5)	ARMTS-3755E2/*	1565	6 (14)	ARMTS-3755E2T1/*	1565	7 (15)
9	3	47	3	61 (24)	ARMTS-3905E2/*	1646	7 (15)	ARMTS-3905E2T1/*	1646	7 (15)
12	3	46	3	81 (32)	ARMTS-3120E2/*	1781	7 (15)	ARMTS-3120E2T1/*	1781	7 (16)
15	3	46	3	100 (39.5)	ARMTS-3150E2/*	1913	8 (17)	ARMTS-3120E2T1/*	1913	8 (17)
18	3	51	3	119 (47)	²ARMTS-3180E2/*	2013	8 (18)	²ARMTS-3180E2T1/*	2013	8 (18)

¹ Not UL Listed or CSA Certified (exceeds 48 amps) ² Not CSA NRTL/C Certified (exceeds 48 amps)

/*Designate voltage, i.e., "240" for 240 Vac or "480" for 480 V.

Ordering Example: ARMTS-3305T1/240/3P, 3 kW heater with a thermostat range of 0 to 100°F powered by 240 Vac, \$1147.

omega.co.uk®

Your One-Stop Source for Process Measurement and Control!

Freephone 0800 488 488 | International +44(0) 161 777 6622 | Fax +44(0) 161 777 6622 | Sales@omega.co.uk

www.omega.co.uk



UNITED STATES

www.omega.com

1-800-TC-OMEGA
Stamford, CT.

CANADA

www.omega.ca

Laval(Quebec)
1-800-TC-OMEGA

GERMANY

www.omega.de

Deckenpfronn, Germany
0800-8266342

UNITED KINGDOM

www.omega.co.uk

Manchester, England
0800-488-488
+44-(0)161-777-6611

FRANCE

www.omega.fr

0800-466-342

BENELUX

www.omega.nl

0800-099-33-44



More than 100,000 Products Available!

• Temperature

Calibrators, Connectors, General Test and Measurement Instruments, Handheld Instruments for Temperature Measurement, Ice Point References, Indicating Labels, Crayons, Cements and Lacquers, Infrared Temperature Measurement Instruments, Recorders, Relative Humidity Measurement Instruments, PT100 Probes, PT100 Elements, Temperature & Process Meters, Timers and Counters, Temperature and Process Controllers and Power Switching Devices, Thermistor Elements, Probes and Assemblies, Thermocouples, Thermowells and Head and Well Assemblies, Transmitters, Thermocouple Wire, RTD Probes

• Flow and Level

Air Velocity Indicators, Doppler Flowmeters, Level Measurement, Magnetic Flowmeters, Mass Flowmeters, Pitot Tubes, Pumps, Rotameters, Turbine and Paddle Wheel Flowmeters, Ultrasonic Flowmeters, Valves, Variable Area Flowmeters, Vortex Shedding Flowmeters

• pH and Conductivity

Conductivity Instrumentation, Dissolved Oxygen Instrumentation, Environmental Instrumentation, pH Electrodes and Instruments, Water and Soil Analysis Instrumentation

• Data Acquisition

Communication Products and Converters, Data Acquisition and Analysis Software, Data Loggers, Plug-in Cards, Signal Conditioners, USB, RS232, RS485, Ethernet and Parallel Port Data Acquisition Systems, Wireless Transmitters and Receivers

• Pressure, Strain and Force

Displacement Transducers, Dynamic Measurement Force Sensors, Instrumentation for Pressure and Strain Measurements, Load Cells, Pressure Gauges, Pressure Reference Section, Pressure Switches, Pressure Transducers, Proximity Transducers, Regulators, Pressure Transmitters, Strain Gauges, Torque Transducers, Valves

• Heaters

Band Heaters, Cartridge Heaters, Circulation Heaters, Comfort Heaters, Controllers, Meters and Switching Devices, Flexible Heaters, General Test and Measurement Instruments, Heater Hook-up Wire, Heating Cable Systems, Immersion Heaters, Process Air and Duct, Heaters, Radiant Heaters, Strip Heaters, Tubular Heaters