

TOUCH-SAFE SMALL HEATER 10 W, 20 W

NEW

CSK060 Series
Starts at
\$27



- Low Surface Temperature
- Double Insulated (Plastic Housing)
- Wide Voltage Range
- Temperature Limiting
- Dynamic Heating Up
- Clip Fixing

These heaters are used in enclosures where condensation is to be prevented or the temperature may not fall below a minimum value. In this way corrosion is avoided and an even temperature is ensured. The heaters are designed for permanent operation.

SPECIFICATIONS

Operating Voltage: 120 to 240 Vac/Vdc* (min 110V, max 265V)

Heating Element: PTC resistor: temperature limiting

Surface Temperature: <85°C (185°F), (according to VDE 0100), except upper protective grille

Connection: 2-pole terminal 2.5 mm² (0.1"), torque 0.8 Nm max

Casing: Plastic according to UL94 V-0, black

Dimensions: 98 x 38 x 75 mm (3.9 x 1.5 x 3.0")

Mounting: Clip for 35 mm (1.4") DIN rail, EN 50022

Fitting Position: Vertical

Operating/Storage Temperature: -45 to 70°C (-49 to 158°F)

Protection Type/Protection Class: NEMA 2 (IP20)/II (double insulated)


Approvals: VDE + UL File No. E150057 (according to UL499 in combination with UL508A)

Note: Other voltages on request

* Operating with voltages below 140 Vac/Vdc reduces heating performance by approximately 10%.



CSK06006030000, \$30, shown actual size.

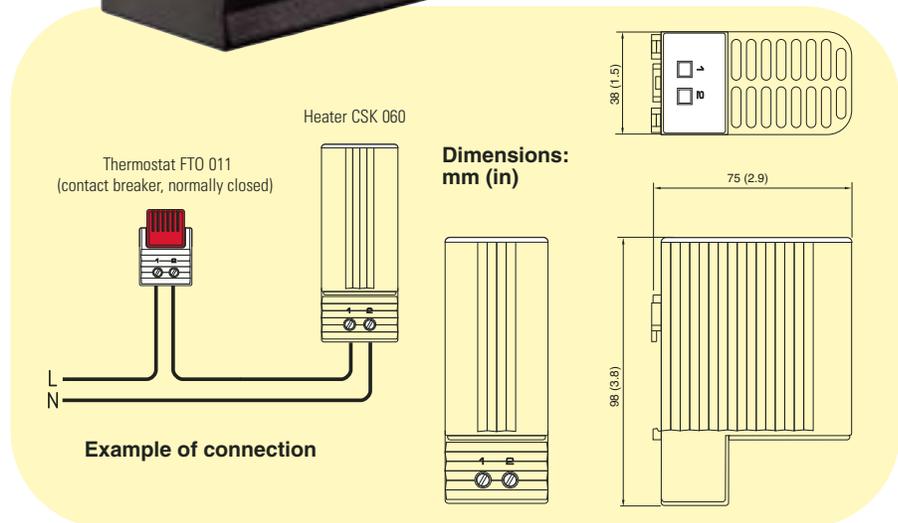

Model No.	Heating Capacity*	Inrush Current Max	Weight
CSK06006040000	10 W	1.0 A	0.20 kg (7.1 oz)
CSK06006030000	20 W	2.5 A	0.30 kg (10.6 oz)

* At 20°C (68°F) ambient temperature.

To Order (Specify Model Number)

AVAILABLE FOR FAST DELIVERY!

MODEL NO.	PRICE	DESCRIPTION
CSK06006030000	\$30	Enclosure heater, 20 W, 120 to 240 Vac/Vdc
CSK06006040000	27	Enclosure heater, 10 W, 120 to 240 Vac/Vdc

Comes complete with operator's manual.

Ordering Examples: CSK06006030000, enclosure heater, \$30. CSK06006040000, enclosure heater, \$27.

omega.co.uk[®]

Your One-Stop Source for Process Measurement and Control!

Freephone 0800 488 488 | International +44(0) 161 777 6622 | Fax +44(0) 161 777 6622 | Sales@omega.co.uk

www.omega.co.uk



UNITED STATES

www.omega.com

1-800-TC-OMEGA
Stamford, CT.

UNITED KINGDOM

www.omega.co.uk

Manchester, England
0800-488-488
+44-(0)161-777-6611

CANADA

www.omega.ca

Laval(Quebec)
1-800-TC-OMEGA

FRANCE

www.omega.fr

0800-466-342

GERMANY

www.omega.de

Deckenfronn, Germany
0800-8266342

BENELUX

www.omega.nl

0800-099-33-44



More than 100,000 Products Available!

• Temperature

Calibrators, Connectors, General Test and Measurement Instruments, Handheld Instruments for Temperature Measurement, Ice Point References, Indicating Labels, Crayons, Cements and Lacquers, Infrared Temperature Measurement Instruments, Recorders, Relative Humidity Measurement Instruments, PT100 Probes, PT100 Elements, Temperature & Process Meters, Timers and Counters, Temperature and Process Controllers and Power Switching Devices, Thermistor Elements, Probes and Assemblies, Thermocouples, Thermowells and Head and Well Assemblies, Transmitters, Thermocouple Wire, RTD Probes

• Flow and Level

Air Velocity Indicators, Doppler Flowmeters, Level Measurement, Magnetic Flowmeters, Mass Flowmeters, Pitot Tubes, Pumps, Rotameters, Turbine and Paddle Wheel Flowmeters, Ultrasonic Flowmeters, Valves, Variable Area Flowmeters, Vortex Shedding Flowmeters

• pH and Conductivity

Conductivity Instrumentation, Dissolved Oxygen Instrumentation, Environmental Instrumentation, pH Electrodes and Instruments, Water and Soil Analysis Instrumentation

• Data Acquisition

Communication Products and Converters, Data Acquisition and Analysis Software, Data Loggers Plug-in Cards, Signal Conditioners, USB, RS232, RS485, Ethernet and Parallel Port Data Acquisition Systems, Wireless Transmitters and Receivers

• Pressure, Strain and Force

Displacement Transducers, Dynamic Measurement Force Sensors, Instrumentation for Pressure and Strain Measurements, Load Cells, Pressure Gauges, Pressure Reference Section, Pressure Switches, Pressure Transducers, Proximity Transducers, Regulators, Pressure Transmitters, Strain Gauges, Torque Transducers, Valves

• Heaters

Band Heaters, Cartridge Heaters, Circulation Heaters, Comfort Heaters, Controllers, Meters and Switching Devices, Flexible Heaters, General Test and Measurement Instruments, Heater Hook-up Wire, Heating Cable Systems, Immersion Heaters, Process Air and Duct, Heaters, Radiant Heaters, Strip Heaters, Tubular Heaters