



SCREW PLUG IMMERSION HEATERS

For Small Tanks

RIN Series
Starts at
\$175

- ✓ ½ and ¾ NPT Brass or Steel Screw Plugs
- ✓ 100 to 1000 Watts
- ✓ 120 and 240V, 1 Phase
- ✓ Dual Pipe Thread Construction
- ✓ Premium Grade Incoloy or Stainless Steel Sheath

These screw plug immersion heaters feature dual pipe thread construction which allows easy installation into your process and quick connection of electrical conduit.

SPECIFICATIONS


Wattage: 100 to 1000 Watt**Power:** 120, or 240V, 1 phase**Watt Density:** 17 to 40 W/in²**Sheath:****Type RIN:** ½ or ¾" diameter
Incoloy sheath**Type RINO:** ½ or ¾" diameter
stainless steel sheath**Screw Plug:****Type RIN:** ½ or ¾ NPT brass fitting**Type RINO:** ½ or ¾ NPT steel fitting

CAUTION AND WARNING!

Fire and electrical shock may result if products are used improperly or installed or used by non-qualified personnel. See inside back cover for additional warning.



RIN-150/120, \$224, shown smaller than actual size

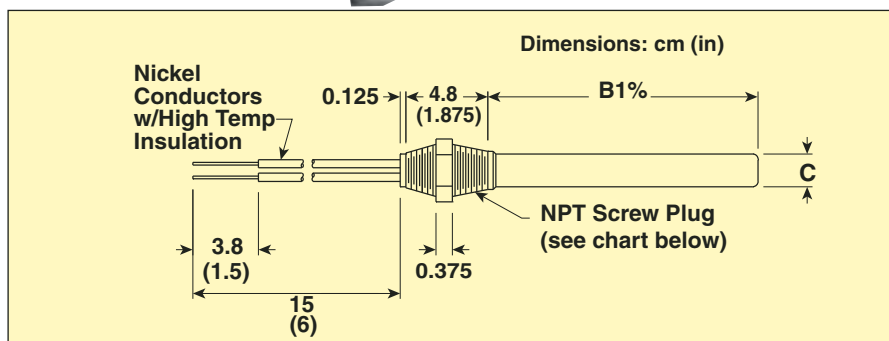

MOST POPULAR MODELS HIGHLIGHTED!

To Order (Specify Model Number)

Watts	Volts	Phase	W/in ²	Dimensions Inches		Pipe Thd.	Model No.	Price	Wt. lb (kg)
				B	C				
RIN Series with Incoloy sheath—brass screw plug									
100	120	1	30	1¾	¾	½	RIN-10/120	\$175	3 (1)
250	120	1	35	3¾	¾	½	RIN-25/120	181	4.5 (2)
250	240	1	35	3¾	¾	½	RIN-25/240	181	4.5 (2)
500	120	1	40	8	¾	½	RIN-50/120	205	10 (5)
500	240	1	40	8	¾	½	RIN-50/240	205	10(5)
750	120	1	40	12	¾	½	RIN-75/120	224	14 (6)
750	240	1	40	12	¾	½	RIN-75/240	224	14(6)
300	120	1	25	5	¾	¾	RIN-130/120	202	8 (3)
300	240	1	25	5	¾	¾	RIN-130/240	202	8 (3)
500	120	1	30	6½	¾	¾	RIN-150/120	224	9 (4)
500	240	1	30	6½	¾	¾	RIN-150/240	224	9 (4)
750	120	1	30	10¾	¾	¾	RIN-175/120	259	13 (6)
750	240	1	30	10¾	¾	¾	RIN-175/240	259	13 (6)
1000	120	1	30	13¾	¾	¾	RIN-1100/120	294	15 (7)
1000	240	1	30	13¾	¾	¾	RIN-1100/240	294	15 (7)
RINO Series with stainless steel sheath—steel screw plug									
150	120	1	20	3¾	¾	½	RINO-15/120	\$197	4 (2)
150	240	1	20	3¾	¾	½	RINO-15/240	197	4 (2)
300	120	1	25	8	¾	½	RINO-30/120	207	10 (5)
300	240	1	25	8	¾	½	RINO-30/240	207	10 (5)
500	120	1	25	12	¾	½	RINO-50/120	243	14 (6)
500	240	1	25	12	¾	½	RINO-50/240	243	14 (6)
200	120	1	17	5	¾	¾	RINO-120/120	235	8 (3)
200	240	1	17	5	¾	¾	RINO-120/240	235	8 (3)
300	120	1	18	6½	¾	¾	RINO-130/120	246	9 (4)
300	240	1	18	6½	¾	¾	RINO-130/240	246	9 (4)
500	120	1	20	10¾	¾	¾	RINO-150/120	266	13 (6)
500	240	1	20	10¾	¾	¾	RINO-150/240	266	13 (6)
600	120	1	18	13¾	¾	¾	RINO-160/120	266	15 (7)
600	240	1	18	13¾	¾	¾	RINO-160/240	266	15 (7)

Ordering Example: RIN-10/120, 100 W, 120V screw plug immersion heater, \$175.

omega.co.uk®

Your One-Stop Source for Process Measurement and Control!

Freephone 0800 488 488 | International +44(0) 161 777 6622 | Fax +44(0) 161 777 6622 | Sales@omega.co.uk

www.omega.co.uk



UNITED STATES

www.omega.com

1-800-TC-OMEGA
Stamford, CT.

CANADA

www.omega.ca

Laval(Quebec)
1-800-TC-OMEGA

GERMANY

www.omega.de

Deckenpfronn, Germany
0800-8266342

UNITED KINGDOM

www.omega.co.uk

Manchester, England
0800-488-488
+44-(0)161-777-6611

FRANCE

www.omega.fr

0800-466-342

BENELUX

www.omega.nl

0800-099-33-44



More than 100,000 Products Available!

• Temperature

Calibrators, Connectors, General Test and Measurement Instruments, Handheld Instruments for Temperature Measurement, Ice Point References, Indicating Labels, Crayons, Cements and Lacquers, Infrared Temperature Measurement Instruments, Recorders, Relative Humidity Measurement Instruments, PT100 Probes, PT100 Elements, Temperature & Process Meters, Timers and Counters, Temperature and Process Controllers and Power Switching Devices, Thermistor Elements, Probes and Assemblies, Thermocouples, Thermowells and Head and Well Assemblies, Transmitters, Thermocouple Wire, RTD Probes

• Flow and Level

Air Velocity Indicators, Doppler Flowmeters, Level Measurement, Magnetic Flowmeters, Mass Flowmeters, Pitot Tubes, Pumps, Rotameters, Turbine and Paddle Wheel Flowmeters, Ultrasonic Flowmeters, Valves, Variable Area Flowmeters, Vortex Shedding Flowmeters

• pH and Conductivity

Conductivity Instrumentation, Dissolved Oxygen Instrumentation, Environmental Instrumentation, pH Electrodes and Instruments, Water and Soil Analysis Instrumentation

• Data Acquisition

Communication Products and Converters, Data Acquisition and Analysis Software, Data Loggers, Plug-in Cards, Signal Conditioners, USB, RS232, RS485, Ethernet and Parallel Port Data Acquisition Systems, Wireless Transmitters and Receivers

• Pressure, Strain and Force

Displacement Transducers, Dynamic Measurement Force Sensors, Instrumentation for Pressure and Strain Measurements, Load Cells, Pressure Gauges, Pressure Reference Section, Pressure Switches, Pressure Transducers, Proximity Transducers, Regulators, Pressure Transmitters, Strain Gauges, Torque Transducers, Valves

• Heaters

Band Heaters, Cartridge Heaters, Circulation Heaters, Comfort Heaters, Controllers, Meters and Switching Devices, Flexible Heaters, General Test and Measurement Instruments, Heater Hook-up Wire, Heating Cable Systems, Immersion Heaters, Process Air and Duct, Heaters, Radiant Heaters, Strip Heaters, Tubular Heaters