


STRIP HEATER ACCESSORIES



Terminal Covers and Insulators

Secondary Insulation Bushing: (All types except NS) Must be used when strips are mounted for air heating only or when connected in series on line voltages above 480V. (**Note:** To accommodate bushings, a $\frac{17}{32} \times \frac{1}{16}$ " Dia. mounting hole in tabs should be specified for heaters. Delivery from stock. To order secondary insulation bushings, add suffix "/PCN255716" to model no. and add \$15 to price).

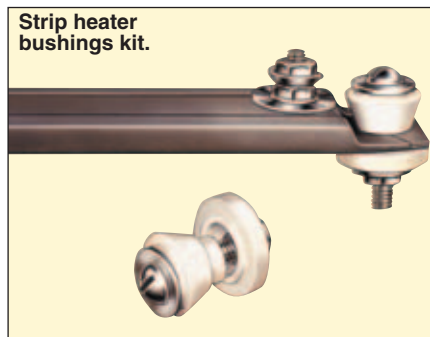

Secondary Insulation Bushing Kit: Kit includes bushing and hardware for one strip: **\$14.**

Ceramic Post Terminal Insulators: All types except NS and SN. Use with insulated wire to protect against electrical shock. Wires can leave terminal at any angle. For strip heaters only. H-TP: **\$14.**

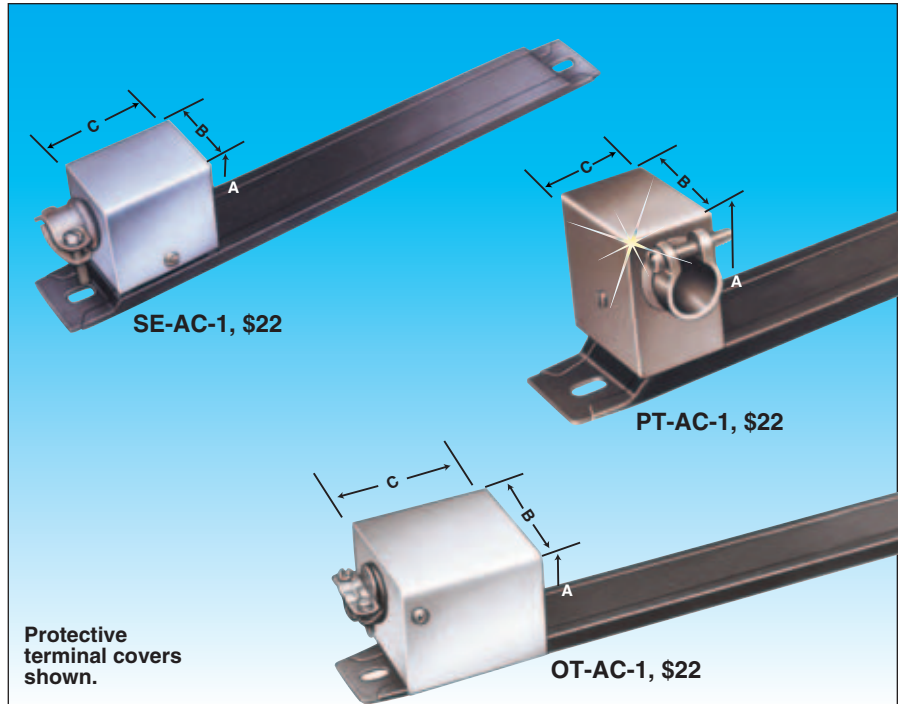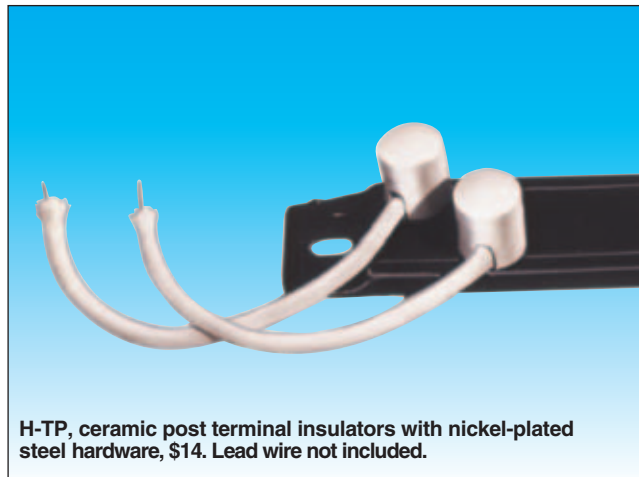

Protective Terminal Covers: OT, PT, SE, WS, and seamless types SSE, SSEM, SSNH, and SSNHM. Guards terminals from spillovers, dripping, grounding or short circuiting. Removable sheet-metal cover with Bx fitting is shipped separately.

Strip heaters can be provided with a lengthwise bend or cross-section

curve, without mounting tabs or with extra strong mounting tabs. Special strip heater lengths, special length terminals, special voltages and/or wattages, special wattage distributions, and special sheath materials (stainless steel or Monel®) can be provided. Contact OMEGALUX®: call 1-800-USA-HEAT.

AVAILABLE FOR FAST DELIVERY!

To Order (Specify Model Number)

Strip Heater Accessories

Model No.	Price	Description
PCN255716	\$15/2 Pack	Secondary insulation bushing
H-TP	14/2 Pack	Ceramic post terminal insulators
OT-AC-1	22	Terminal cover for OT Series strip heaters
PT-AC-1	22	Terminal cover for PT Series strip heaters
SE-AC-1	22	Terminal cover for SE Series strip heaters

Dimensions: cm (in) - Terminal Covers

Model Number	A	B	C
OT-AC-1	5 (2)	6 (2½)	6 (2½)
PT-AC-1	2 (1⅞)	3 (1⅞)	4 (1¾)
SE-AC-1*	5 (2⅛)	4 (1½)	5 (2)

* Alloys used on type WS (mounted sideways).

Ordering Examples: PCN255716, insulation bushing, \$15/2 pack.
H-TP, ceramic post terminal insulators, \$14/2 pack.

omega.co.uk®

Your One-Stop Source for Process Measurement and Control!

Freephone 0800 488 488 | International +44(0) 161 777 6622 | Fax +44(0) 161 777 6622 | Sales@omega.co.uk

www.omega.co.uk



UNITED STATES

www.omega.com

1-800-TC-OMEGA
Stamford, CT.

CANADA

www.omega.ca

Laval(Quebec)
1-800-TC-OMEGA

GERMANY

www.omega.de

Deckenpfronn, Germany
0800-8266342

UNITED KINGDOM

www.omega.co.uk

Manchester, England
0800-488-488
+44-(0)161-777-6611

FRANCE

www.omega.fr

0800-466-342

BENELUX

www.omega.nl

0800-099-33-44



More than 100,000 Products Available!

• Temperature

Calibrators, Connectors, General Test and Measurement Instruments, Handheld Instruments for Temperature Measurement, Ice Point References, Indicating Labels, Crayons, Cements and Lacquers, Infrared Temperature Measurement Instruments, Recorders, Relative Humidity Measurement Instruments, PT100 Probes, PT100 Elements, Temperature & Process Meters, Timers and Counters, Temperature and Process Controllers and Power Switching Devices, Thermistor Elements, Probes and Assemblies, Thermocouples, Thermowells and Head and Well Assemblies, Transmitters, Thermocouple Wire, RTD Probes

• Flow and Level

Air Velocity Indicators, Doppler Flowmeters, Level Measurement, Magnetic Flowmeters, Mass Flowmeters, Pitot Tubes, Pumps, Rotameters, Turbine and Paddle Wheel Flowmeters, Ultrasonic Flowmeters, Valves, Variable Area Flowmeters, Vortex Shedding Flowmeters

• pH and Conductivity

Conductivity Instrumentation, Dissolved Oxygen Instrumentation, Environmental Instrumentation, pH Electrodes and Instruments, Water and Soil Analysis Instrumentation

• Data Acquisition

Communication Products and Converters, Data Acquisition and Analysis Software, Data Loggers, Plug-in Cards, Signal Conditioners, USB, RS232, RS485, Ethernet and Parallel Port Data Acquisition Systems, Wireless Transmitters and Receivers

• Pressure, Strain and Force

Displacement Transducers, Dynamic Measurement Force Sensors, Instrumentation for Pressure and Strain Measurements, Load Cells, Pressure Gauges, Pressure Reference Section, Pressure Switches, Pressure Transducers, Proximity Transducers, Regulators, Pressure Transmitters, Strain Gauges, Torque Transducers, Valves

• Heaters

Band Heaters, Cartridge Heaters, Circulation Heaters, Comfort Heaters, Controllers, Meters and Switching Devices, Flexible Heaters, General Test and Measurement Instruments, Heater Hook-up Wire, Heating Cable Systems, Immersion Heaters, Process Air and Duct, Heaters, Radiant Heaters, Strip Heaters, Tubular Heaters