

# RUGGED SCREW PLUG IMMERSION HEATERS




## For Small Tanks TM/TMO Series

- ✓ 1" NPT Screw Plug
- ✓ Tubular Element Design
- ✓ 350 to 1500 W
- ✓ Heavy Duty Construction

These screw plug immersion heaters feature a dead front Nylon Twist Lock grounded plug with receptacle. This makes power connection easier.

### Dimensions inches (cm)

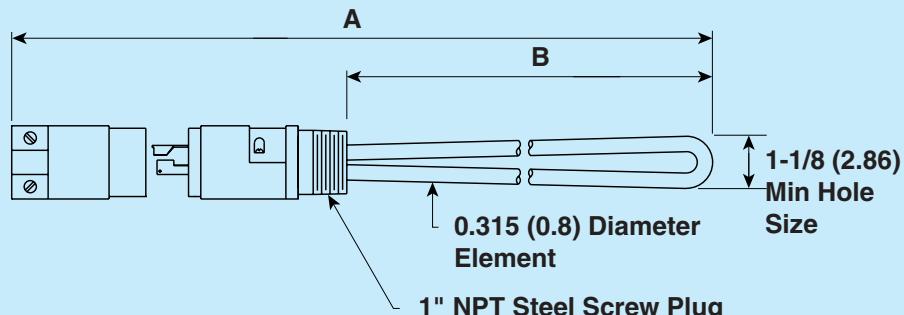

### SPECIFICATIONS

**Wattage:** 350 to 1500 watts

**Power:** 120 or 240 Vac

**Watt Density:** 20 - 86 W/in<sup>2</sup>

**Sheath Material:** Type TM has a high watt density copper sheath, ideal for water heating applications. Type TMO has a lower watt density steel sheath for oil heating applications.

**Screw Plug:** Type TM has a 1"brass screw plug. Type TMO has 1" steel screw plug.

### CAUTION AND WARNING!

Fire and electrical shock may result if products are used improperly or installed or used by non-qualified personnel. See inside back cover for additional warnings.

### To Order (Specify Model Number) HIGHLIGHTED MODELS STOCKED!

Watts	Volts	Phase	W/in <sup>2</sup>	Dimensions—In. (cm)		Std. Pipe Thd.	Model No.	Price	Wt. oz
				A	B				
<b>TM Series - Copper sheath element for water heating - Brass Screw Plug</b>									
350	120	1	46	8 $\frac{1}{2}$ (22)	4 $\frac{1}{2}$ (11)	1	TM-1036G/120	111	14
500	120	1	43	10 $\frac{1}{4}$ (27)	6 $\frac{1}{2}$ (17)	1	TM-1051G/120	116	14
750	120	1	64	10 $\frac{1}{4}$ (27)	6 $\frac{1}{2}$ (17)	1	TM-1076G/120	125	16
750	240	1	64	10 $\frac{1}{4}$ (27)	6 $\frac{1}{2}$ (17)	1	TM-1076G/240	125	16
1000	120	1	85	10 $\frac{1}{4}$ (27)	6 $\frac{1}{2}$ (17)	1	TM-1101G/120	137	16
1000	240	1	85	10 $\frac{1}{4}$ (27)	6 $\frac{1}{2}$ (17)	1	TM-1101G/240	137	16
1500	120	1	86	13 $\frac{1}{2}$ (35)	9 $\frac{1}{2}$ (24)	1	TM-1415G/120	164	17
1500	240	1	86	13 $\frac{1}{2}$ (35)	9 $\frac{1}{2}$ (24)	1	TM-1415G/240	164	17
<b>TMO Series - Steel sheath element for oil heating - Steel Screw Plug</b>									
350	120	1	20	13 $\frac{1}{2}$ (35)	8 $\frac{1}{2}$ (23)	1	TMO-1036G/120	114	16
500	120	1	20	17 $\frac{1}{2}$ (44)	13 (33)	1	TMO-1051G/120	136	18
500	240	1	20	17 $\frac{1}{2}$ (44)	13 (33)	1	TMO-1051G/240	136	18
750	120	1	20	23 $\frac{1}{2}$ (59)	18 $\frac{1}{2}$ (48)	1	TMO-1076G/120	153	20
750	240	1	20	23 $\frac{1}{2}$ (59)	18 $\frac{1}{2}$ (48)	1	TMO-1076G/240	153	20
900	120	1	21	25 $\frac{1}{2}$ (65)	21 $\frac{1}{2}$ (54)	1	TMO-1091G/120	166	22
900	240	1	21	25 $\frac{1}{2}$ (65)	21 $\frac{1}{2}$ (54)	1	TMO-1091G/240	166	22

*Ordering Example: Model TM-1036G/120 is a 350 Watt, 120 V heater, \$111.*



#### UNITED STATES

[www.omega.com](http://www.omega.com)

1-800-TC-OMEGA  
Stamford, CT.

#### CANADA

[www.omega.ca](http://www.omega.ca)

Laval(Quebec)  
1-800-TC-OMEGA

#### GERMANY

[www.omega.de](http://www.omega.de)

Deckenpfronn, Germany  
0800-8266342

#### UNITED KINGDOM

[www.omega.co.uk](http://www.omega.co.uk)

Manchester, England  
0800-488-488  
+44-(0)161-777-6611

#### FRANCE

[www.omega.fr](http://www.omega.fr)

0800-466-342

#### BENELUX

[www.omega.nl](http://www.omega.nl)

0800-099-33-44



## More than 100,000 Products Available!

### • Temperature

Calibrators, Connectors, General Test and Measurement Instruments, Handheld Instruments for Temperature Measurement, Ice Point References, Indicating Labels, Crayons, Cements and Lacquers, Infrared Temperature Measurement Instruments, Recorders, Relative Humidity Measurement Instruments, PT100 Probes, PT100 Elements, Temperature & Process Meters, Timers and Counters, Temperature and Process Controllers and Power Switching Devices, Thermistor Elements, Probes and Assemblies, Thermocouples, Thermowells and Head and Well Assemblies, Transmitters, Thermocouple Wire, RTD Probes

### • Flow and Level

Air Velocity Indicators, Doppler Flowmeters, Level Measurement, Magnetic Flowmeters, Mass Flowmeters, Pitot Tubes, Pumps, Rotameters, Turbine and Paddle Wheel Flowmeters, Ultrasonic Flowmeters, Valves, Variable Area Flowmeters, Vortex Shedding Flowmeters

### • pH and Conductivity

Conductivity Instrumentation, Dissolved Oxygen Instrumentation, Environmental Instrumentation, pH Electrodes and Instruments, Water and Soil Analysis Instrumentation

### • Data Acquisition

Communication Products and Converters, Data Acquisition and Analysis Software, Data Loggers, Plug-in Cards, Signal Conditioners, USB, RS232, RS485, Ethernet and Parallel Port Data Acquisition Systems, Wireless Transmitters and Receivers

### • Pressure, Strain and Force

Displacement Transducers, Dynamic Measurement Force Sensors, Instrumentation for Pressure and Strain Measurements, Load Cells, Pressure Gauges, Pressure Reference Section, Pressure Switches, Pressure Transducers, Proximity Transducers, Regulators, Pressure Transmitters, Strain Gauges, Torque Transducers, Valves

### • Heaters

Band Heaters, Cartridge Heaters, Circulation Heaters, Comfort Heaters, Controllers, Meters and Switching Devices, Flexible Heaters, General Test and Measurement Instruments, Heater Hook-up Wire, Heating Cable Systems, Immersion Heaters, Process Air and Duct, Heaters, Radiant Heaters, Strip Heaters, Tubular Heaters