

# SUBMINIATURE TENSION OR COMPRESSION LOAD CELLS HIGH ACCURACY, 19 AND 25 mm DIAMETER

**LCMFD Series**  
Tension/Compression  
(Calibrated in Tension)  
10 N to 5000 N

All Models  
**£505**




LCMFD-20N, £505,  
shown actual size.



LCMFD-1KN, £505,  
shown actual size.

Small and capable of highly accurate readings, the LCMFD Series subminiature load cells are designed for precision industrial applications. They are all stainless steel, measure both tension and compression loads, and have male thread studs for load attachment. The exclusive internal design provides superior long-term stability and minimises the effects of small off-axis loads.

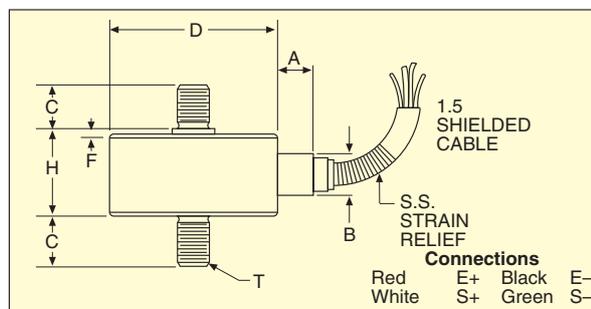

## SPECIFICATIONS

### Excitation:

10 to 50 N: 5 Vdc  
100 N: 10 Vdc

### Output:

10 to 50 N: 1.5 mV/V (nom.)  
100 N: 2 mV/V (nom.)

### Accuracy (Linearity and Hysteresis Combined):

±0.15% FSO: 500 N  
±0.20% FSO: 1000 N

### Repeatability: 0.20% FSO

### 5-Point Calibration (in Tension):

0%, 50%, 100%, 50%, 0%

### Zero Balance: ±2% FSO

### Deflection: 0.025 to 0.075 mm

### Operating Temp Range:

-54 to 121°C

### Compensated Temp Range:

16 to 71°C

### Thermal Effects:

Span: ±0.009% FSO/°C  
Zero: 0.009% FSO/°C

### Safe Overload: 150% of capacity

### Ultimate Overload: 300% of capacity

### Bridge Resistance: 350 Ω minimum

### Construction: Stainless steel

### Electrical Connection: 1.5 m

 
### 4-conductor screened cable

50N: Stainless steel overbraided  
with temperature compensation board

### Dimensions: mm

CAPACITY (N)	T	F	D DIA.	H	A	B DIA.	C
10 to 50	M5 x .8	4.6	19.1	18.5	12.7	6.35	6.35
100 to 5000	M6 x 1.00	2.3	25.4	13.5	12.7	6.35	9.7

### MOST POPULAR MODELS HIGHLIGHTED!



### To Order (Specify Model Number)

CAPACITY		MODEL NO.	PRICE	COMPATIBLE METERS*	ACCESSORY ROD ENDS	PRICE
N	lb					
10	2.2	LCMFD-10N	£505	DP41-S, DP25B-S	MREC-M5F	£6.70
20	4.5	LCMFD-20N	505	DP41-S, DP25B-S	MREC-M5F	6.70
50	11	LCMFD-50N	505	DP41-S, DP25B-S	MREC-M5F	6.70
100	22	LCMFD-100N	505	iSeries, DP41-S, DP25B-S	MREC-M6F	10.00
200	45	LCMFD-200N	505	iSeries, DP41-S, DP25B-S	MREC-M6F	10.00
500	112	LCMFD-500N	505	iSeries, DP41-S, DP25B-S	MREC-M6F	10.00
1000	225	LCMFD-1KN	505	iSeries, DP41-S, DP25B-S	MREC-M6F	10.00
2000	450	LCMFD-2KN	505	iSeries, DP41-S, DP25B-S	MREC-M6F	10.00
5000	1124	LCMFD-5KN	505	iSeries, DP41-S, DP25B-S	MREC-M6F	10.00

Comes with 5-point traceable calibration.

\* See page 291 for compatible meters.

Ordering Examples: LCMFD-20N, 20 N capacity load cell, £505.

MREC-M5F, matching rod end, £6.70 ea. LCMFD-500N, 500 N capacity load cell, £505.

MREC-M6F, matching rod end, £10 ea.

### ACCESSORY

MODEL NO.	PRICE	DESCRIPTION
ME-0013	£184	Reference Book: Mechanical Engineer's Handbook

# omega.co.uk<sup>®</sup>

Your One-Stop Source for Process Measurement and Control!

Freephone 0800 488 488 | International +44(0) 161 777 6622 | Fax +44(0) 161 777 6622 | Sales@omega.co.uk

[www.omega.co.uk](http://www.omega.co.uk)



#### UNITED STATES

[www.omega.com](http://www.omega.com)

1-800-TC-OMEGA

Stamford, CT.

#### CANADA

[www.omega.ca](http://www.omega.ca)

Laval(Quebec)

1-800-TC-OMEGA

#### GERMANY

[www.omega.de](http://www.omega.de)

Deckenpfronn, Germany

0800-8266342

#### UNITED KINGDOM

[www.omega.co.uk](http://www.omega.co.uk)

Manchester, England

0800-488-488

#### FRANCE

[www.omega.fr](http://www.omega.fr)

088-466-342

#### CZECH REPUBLIC

[www.omegaeng.cz](http://www.omegaeng.cz)

Karviná, Czech Republic

596-311-899

#### BENELUX

[www.omega.nl](http://www.omega.nl)

0800-099-33-44



## More than 100,000 Products Available!

### • Temperature

Calibrators, Connectors, General Test and Measurement Instruments, Handheld Instruments for Temperature Measurement, Ice Point References, Indicating Labels, Crayons, Cements and Lacquers, Infrared Temperature Measurement Instruments, Recorders, Relative Humidity Measurement Instruments, PT100 Probes, PT100 Elements, Temperature & Process Meters, Timers and Counters, Temperature and Process Controllers and Power Switching Devices, Thermistor Elements, Probes and Assemblies, Thermocouples, Thermowells and Head and Well Assemblies, Transmitters, Thermocouple Wire, RTD Probes

### • Flow and Level

Air Velocity Indicators, Doppler Flowmeters, Level Measurement, Magnetic Flowmeters, Mass Flowmeters, Pitot Tubes, Pumps, Rotameters, Turbine and Paddle Wheel Flowmeters, Ultrasonic Flowmeters, Valves, Variable Area Flowmeters, Vortex Shedding Flowmeters

### • pH and Conductivity

Conductivity Instrumentation, Dissolved Oxygen Instrumentation, Environmental Instrumentation, pH Electrodes and Instruments, Water and Soil Analysis Instrumentation

### • Data Acquisition

Auto-Dialers and Alarm Monitoring Systems, Communication Products and Converters, Data Acquisition and Analysis Software, Data Loggers Plug-in Cards, Signal Conditioners, USB, RS232, RS485 and Parallel Port Data Acquisition Systems, Wireless Transmitters and Receivers

### • Pressure, Strain and Force

Displacement Transducers, Dynamic Measurement Force Sensors, Instrumentation for Pressure and Strain Measurements, Load Cells, Pressure Gauges, Pressure Reference Section, Pressure Switches, Pressure Transducers, Proximity Transducers, Regulators, Pressure Transmitters, Strain Gauges, Torque Transducers, Valves

### • Heaters

Band Heaters, Cartridge Heaters, Circulation Heaters, Comfort Heaters, Controllers, Meters and Switching Devices, Flexible Heaters, General Test and Measurement Instruments, Heater Hook-up Wire, Heating Cable Systems, Immersion Heaters, Process Air and Duct, Heaters, Radiant Heaters, Strip Heaters, Tubular Heaters