

VACUUM/PRESSURE FEEDTHROUGHS

NPT FITTINGS, PLUG OR COUPLE MODELS

1/2 NPT Plug
1/2 NPT Couple

PFT2 Series



- ✓ Copper and Thermocouple Wire
- ✓ 1-, 2-, and 4-Wire Pairs
- ✓ PTFE Insulated Wire
- ✓ 10⁻⁸ torr/120 psi (8 bar) Rating
- ✓ Each Unit Tested for Reliability

SPECIFICATIONS

Material: Brass

Maximum Pressure: 120 psi (8 bar)

Leak Rates, Pressure: 1 x 10⁻⁶ cc air/s at 120 psi; 1 x 10⁻⁷ cc air/s at 29 inHg vacuum

Vacuum Limit: 1 x 10⁻⁸ torr


Leak Rates, Vacuum: 1 x 10⁻⁸ cc He/s at 15 psi; 1 x 10⁻¹¹ cc He/s at 10⁻⁸ torr

Temperature Limits: -40 to 120°C (-40 to 250°F)

Out Gassing: <0.003% VCM; <0.34% weight loss; sample at 125°C, cold surface at 25°C

T/C Wire: 20 AWG solid with PTFE insulation; 48 inL, -200 to 200°C rating

Copper wire: 20 AWG stranded with PTFE insulation, 600V rating

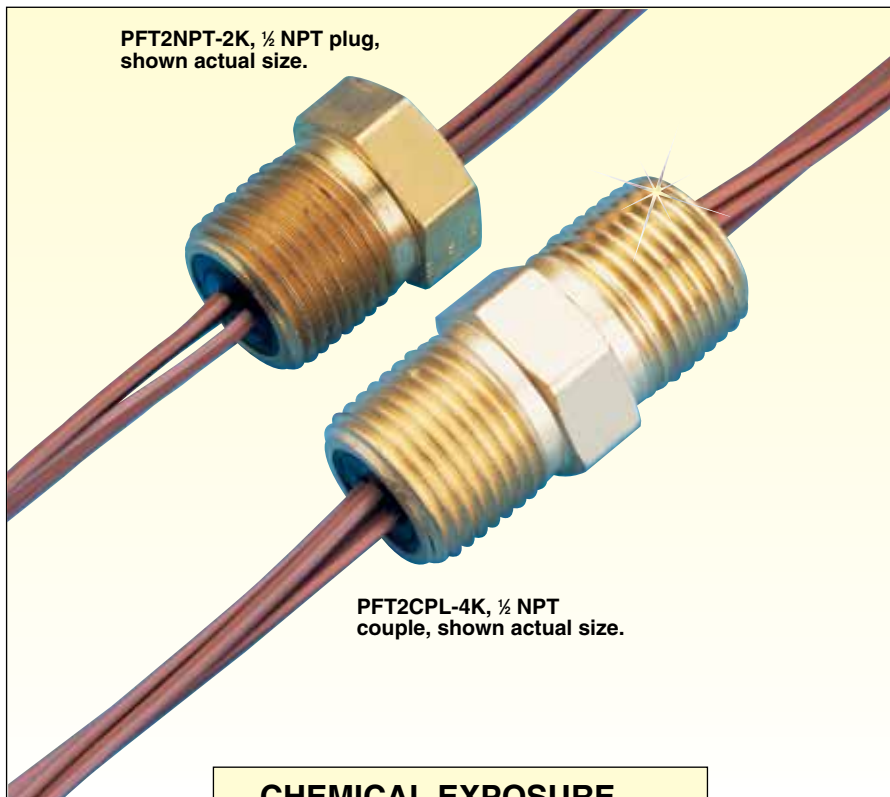

PFT2NPT-2K, 1/2 NPT plug, shown actual size.

PFT2CPL-4K, 1/2 NPT couple, shown actual size.

CHEMICAL EXPOSURE

Compatible: Oils, solvents, refrigerants, water, non-corrosive gases

Avoid: Strong acids and bases

Dimensions: mm (inch)


MODEL NO.	AREA	THREAD	HEX	LENGTH
PFT2NPT	4.8 (0.189)	1/2 NPT	22.4 (0.88)	27.7 (1.09)
PFT2CPL	4.8 (0.189)	1/2 NPT	22.4 (0.88)	48.0 (1.89)

To Order Visit omega.com/pft2 for Pricing and Details

MODEL NO.	WIRE	NO. OF PAIRS	DESCRIPTION
PFT2NPT-1CU	Cu	1	1/2 NPT plug
PFT2NPT-2CU		2	
PFT2NPT-4CU		4	
PFT2NPT-1(*)	T/C	1	1/2 NPT plug
PFT2NPT-2(*)		2	
PFT2NPT-4(*)		4	
PFT2CPL-1CU	Cu	1	1/2 NPT couple
PFT2CPL-2CU		2	
PFT2CPL-4CU		4	
PFT2CPL-1(*)	T/C	1	1/2 NPT couple
PFT2CPL-2(*)		2	
PFT2CPL-4(*)		4	

* Specify thermocouple type: J, K, T, or E.

Ordering Example: PFT2CPL-4K, hermetic feedthrough, 1/2 NPT couple design, for 4 Type K thermocouple wire pairs.

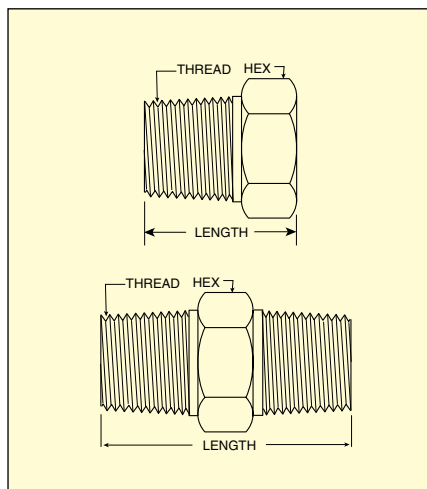

omega.co.uk®

Your One-Stop Source for Process Measurement and Control!

Freephone 0800 488 488 | International +44(0) 161 777 6622 | Fax +44(0) 161 777 6622 | Sales@omega.co.uk

www.omega.co.uk



UNITED STATES

www.omega.com

1-800-TC-OMEGA
Stamford, CT.

UNITED KINGDOM

www.omega.co.uk

Manchester, England
0800-488-488
+44-(0)161-777-6611

CANADA

www.omega.ca

Laval(Quebec)
1-800-TC-OMEGA

FRANCE

www.omega.fr

0800-466-342

GERMANY

www.omega.de

Deckenfronn, Germany
0800-8266342

BENELUX

www.omega.nl

0800-099-33-44



More than 100,000 Products Available!

• Temperature

Calibrators, Connectors, General Test and Measurement Instruments, Handheld Instruments for Temperature Measurement, Ice Point References, Indicating Labels, Crayons, Cements and Lacquers, Infrared Temperature Measurement Instruments, Recorders, Relative Humidity Measurement Instruments, PT100 Probes, PT100 Elements, Temperature & Process Meters, Timers and Counters, Temperature and Process Controllers and Power Switching Devices, Thermistor Elements, Probes and Assemblies, Thermocouples, Thermowells and Head and Well Assemblies, Transmitters, Thermocouple Wire, RTD Probes

• Flow and Level

Air Velocity Indicators, Doppler Flowmeters, Level Measurement, Magnetic Flowmeters, Mass Flowmeters, Pitot Tubes, Pumps, Rotameters, Turbine and Paddle Wheel Flowmeters, Ultrasonic Flowmeters, Valves, Variable Area Flowmeters, Vortex Shedding Flowmeters

• pH and Conductivity

Conductivity Instrumentation, Dissolved Oxygen Instrumentation, Environmental Instrumentation, pH Electrodes and Instruments, Water and Soil Analysis Instrumentation

• Data Acquisition

Communication Products and Converters, Data Acquisition and Analysis Software, Data Loggers Plug-in Cards, Signal Conditioners, USB, RS232, RS485, Ethernet and Parallel Port Data Acquisition Systems, Wireless Transmitters and Receivers

• Pressure, Strain and Force

Displacement Transducers, Dynamic Measurement Force Sensors, Instrumentation for Pressure and Strain Measurements, Load Cells, Pressure Gauges, Pressure Reference Section, Pressure Switches, Pressure Transducers, Proximity Transducers, Regulators, Pressure Transmitters, Strain Gauges, Torque Transducers, Valves

• Heaters

Band Heaters, Cartridge Heaters, Circulation Heaters, Comfort Heaters, Controllers, Meters and Switching Devices, Flexible Heaters, General Test and Measurement Instruments, Heater Hook-up Wire, Heating Cable Systems, Immersion Heaters, Process Air and Duct, Heaters, Radiant Heaters, Strip Heaters, Tubular Heaters