

DUCT PRESSURE TRANSDUCER WITH FIELD-SELECTABLE RANGES

PX279 Series 0-1.25 to 0-15 inH₂O

All Ranges
\$250




- ✓ Duct Pressure Transducer and Static Pressure Probe Integrated as One Unit
- ✓ Up to 3 Field-Selectable Ranges in a Single Unit
- ✓ Rugged NEMA 4 (IP65) Enclosure with External Mounting Bracket
- ✓ Short Circuit and Reverse Polarity Protected

The PX279 is a rugged duct pressure transducer that offers up to 3 field-selectable ranges in one unit. The PX279 incorporates a NEMA 4 (IP65) enclosure and a static pressure probe in one unit for ease of installation and accurate static duct pressure readings.

SPECIFICATIONS


Excitation: 12 to 35 Vdc
Output: 0 to 5 or 0 to 10 Vdc selectable
Accuracy: ±1.0% FS
Operating Temperature: -18 to 80°C (0 to 175°F)
Compensated Temperature: -4 to 65°C (25 to 150°F)
Thermal Effects: 0.02% FS/°C (±0.0125% FS/°F)
Proof Pressure: 10 psi
Media Compatibility: Clean, dry air or inert gas
Termination: Screw terminal
Enclosure: Enamel-coated, 18 GA steel enclosure with 6061T aluminum probe. NEMA 4 (IP65) rating.
Weight: 454 g (1.0 lb)

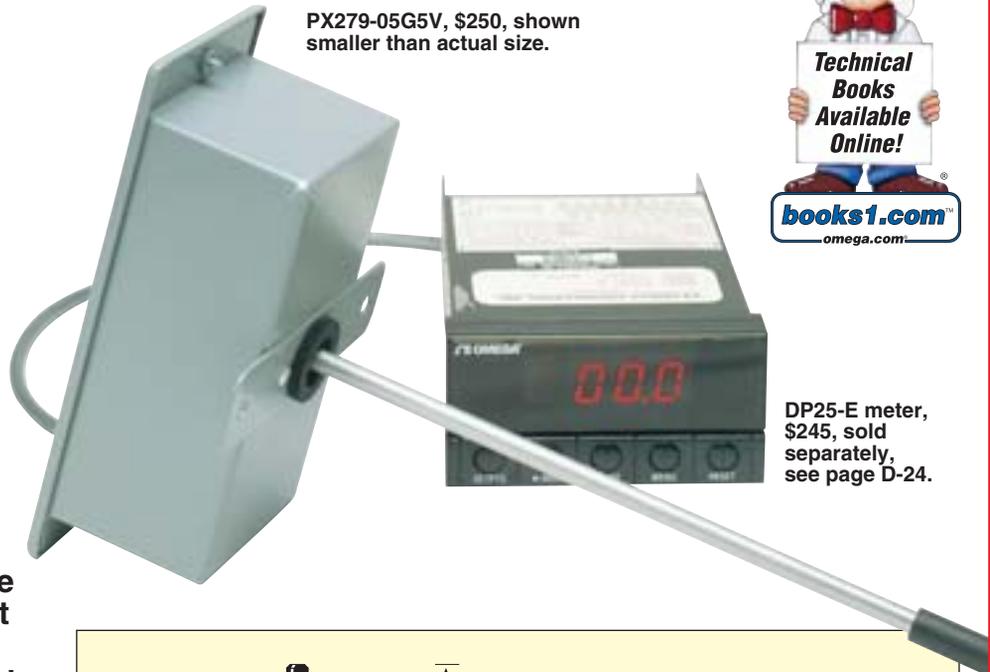

PX279-05G5V, \$250, shown smaller than actual size.



DP25-E meter, \$245, sold separately, see page D-24.

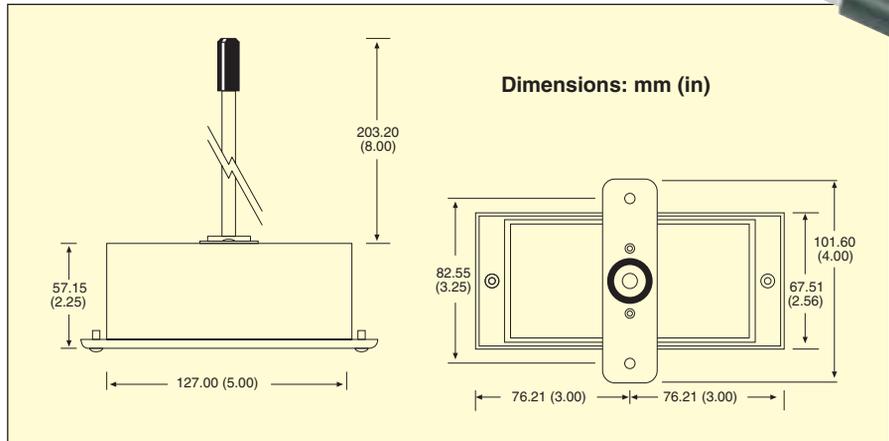

ALL MODELS AVAILABLE FOR FAST DELIVERY!

To Order (Specify Model Number)

MODEL NO.	SELECTABLE RANGES (inH ₂ O)	PRICE	COMPATIBLE METERS*
PX279-05G5V	0 to 5.0, 0 to 2.5, 0 to 1.25	\$250	DP24-E, DP25B-E, DP41-E
PX279-15G5V	0 to 15.0, 0 to 7.5, 0 to 3.75	250	DP24-E, DP25B-E, DP41-E

Comes with operator's manual.

* See section D for compatible meters.

Ordering Example: PX279-05G5V, duct pressure transducer with user-selectable ranges of 0 to 5.0, 0 to 2.5 and 0 to 1.25 inH₂O, \$250.

ACCESSORY

MODEL NO.	PRICE	DESCRIPTION
EE-2582	\$110	Reference Book: Mechanical Variables Measurement

VOLTAGE OUTPUT
PRESSURE TRANSDUCERS
B

omega.co.uk[®]

Your One-Stop Source for Process Measurement and Control!

Freephone 0800 488 488 | International +44(0) 161 777 6622 | Fax +44(0) 161 777 6622 | Sales@omega.co.uk

www.omega.co.uk



UNITED STATES

www.omega.com

1-800-TC-OMEGA
Stamford, CT.

CANADA

www.omega.ca

Laval(Quebec)
1-800-TC-OMEGA

GERMANY

www.omega.de

Deckenfronn, Germany
0800-8266342

UNITED KINGDOM

www.omega.co.uk

Manchester, England
0800-488-488
+44-(0)161-777-6611

FRANCE

www.omega.fr

0800-466-342

BENELUX

www.omega.nl

0800-099-33-44



More than 100,000 Products Available!

• Temperature

Calibrators, Connectors, General Test and Measurement Instruments, Handheld Instruments for Temperature Measurement, Ice Point References, Indicating Labels, Crayons, Cements and Lacquers, Infrared Temperature Measurement Instruments, Recorders, Relative Humidity Measurement Instruments, PT100 Probes, PT100 Elements, Temperature & Process Meters, Timers and Counters, Temperature and Process Controllers and Power Switching Devices, Thermistor Elements, Probes and Assemblies, Thermocouples, Thermowells and Head and Well Assemblies, Transmitters, Thermocouple Wire, RTD Probes

• Flow and Level

Air Velocity Indicators, Doppler Flowmeters, Level Measurement, Magnetic Flowmeters, Mass Flowmeters, Pitot Tubes, Pumps, Rotameters, Turbine and Paddle Wheel Flowmeters, Ultrasonic Flowmeters, Valves, Variable Area Flowmeters, Vortex Shedding Flowmeters

• pH and Conductivity

Conductivity Instrumentation, Dissolved Oxygen Instrumentation, Environmental Instrumentation, pH Electrodes and Instruments, Water and Soil Analysis Instrumentation

• Data Acquisition

Communication Products and Converters, Data Acquisition and Analysis Software, Data Loggers Plug-in Cards, Signal Conditioners, USB, RS232, RS485, Ethernet and Parallel Port Data Acquisition Systems, Wireless Transmitters and Receivers

• Pressure, Strain and Force

Displacement Transducers, Dynamic Measurement Force Sensors, Instrumentation for Pressure and Strain Measurements, Load Cells, Pressure Gauges, Pressure Reference Section, Pressure Switches, Pressure Transducers, Proximity Transducers, Regulators, Pressure Transmitters, Strain Gauges, Torque Transducers, Valves

• Heaters

Band Heaters, Cartridge Heaters, Circulation Heaters, Comfort Heaters, Controllers, Meters and Switching Devices, Flexible Heaters, General Test and Measurement Instruments, Heater Hook-up Wire, Heating Cable Systems, Immersion Heaters, Process Air and Duct, Heaters, Radiant Heaters, Strip Heaters, Tubular Heaters