

# Ready-Made Insulated Thermocouples with Stripped Leads

MEETS OR EXCEEDS  
SPECIAL LIMITS  
OF ERROR (SLE)  
AND EN 60584-2:  
Tolerance Class 1

Convenient  
Packages  
of 5

Custom Lengths,  
Insulations, and  
Configurations  
Available

## 5TC Series

Shown shown actual size.



- ✓ Available from Stock in Convenient 5-Packs
- ✓ PFA, Kapton®, or Glass Braid Insulation
- ✓ 20, 24, 30, 36 and 40 AWG Wires
- ✓ 1 and 2 m (40 and 80") Lengths Standard
- ✓ NIST Calibration Available
- ✓ OEM Quantities Available

"TT" PFA  
insulation



"GG" Glass  
braid insulation



Fine 40-Gage  
PFA Wire

KAPTON®  
Insulation


Now Available!

M8/M12  
CONNECTORS

### Also Available TAP Adhesive Labels!

Thermocouple Adhesive Labels secure wire probes to surfaces. TAP adhesive labels have a thickness of 0.064 mm (0.0022") and can be used at a maximum temperature of 180°C (356°F). They are made of a polyimide film with a silicone pressure sensitive adhesive.

Visit [omega.co.uk/5tc](http://omega.co.uk/5tc) for additional details and ordering information.

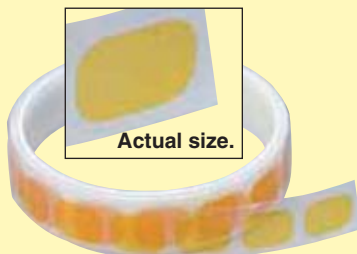

Model TAP, roll of 100 adhesive labels, shown smaller than actual size.

### To Order Visit [omega.com/5tc](http://omega.com/5tc) for Pricing and Details

Model No. ANSI Color Code	AWG Gage	Diameter mm (in)	Insulation
5TC-GG-(*)-20-(**)	20	0.81 (0.032)	Glass Braid
5TC-GG-(*)-24-(**)	24	0.51 (0.020)	Glass Braid
5TC-GG-(*)-30-(**)	30	0.25 (0.010)	Glass Braid
5TC-GG-(*)-36-(**)	36	0.13 (0.005)	Glass Braid
5TC-TT-(*)-20-(**)	20	0.81 (0.032)	PFA
5TC-TT-(*)-24-(**)	24	0.51 (0.020)	PFA
5TC-TT-(*)-30-(**)	30	0.25 (0.010)	PFA
5TC-TT-(*)-36-(**)	36	0.13 (0.005)	PFA
5TC-TT-(*)-40-(**)	40	0.08 (0.003)	PFA
5TC-KK-(*)-20-(**)	20	0.81 (0.032)	Kapton®
5TC-KK-(*)-24-(**)	24	0.51 (0.020)	Kapton®
5TC-KK-(*)-30-(**)	30	0.25 (0.010)	Kapton®

\* Insert calibration **J**, **K**, **I**, **T**, or **E**. \*\* Specify length, insert "1M" for 1 m or "2M" for 2 m length.

**Note:** For GG or TT wire, additional cost per additional 300 mm (12") per package of 5.

For KK wire, additional cost per additional 300 mm (12") per package of 5.

For a male straight M8 plug add "M8-S-M" to the model number for additional cost, for a male straight M12 plug add "M12-S-M" to the model number for additional cost.

For a male right-angled M8 plug add "M8-R-M" to the model number for additional cost, for a male right-angled M12 plug add "M12-S-M" to the model number for additional cost.

**Ordering Example:** 5TC-TT-KI-30-1M, 5 pack, PFA insulated thermocouples, Type K calibration (CHROMEGA®-ALOMEGA®), 30 AWG, 1 m (40") long, stripped lead termination.

# omega.co.uk®

Your One-Stop Source for Process Measurement and Control!

Freephone 0800 488 488 | International +44(0) 161 777 6622 | Fax +44(0) 161 777 6622 | Sales@omega.co.uk

**www.omega.co.uk**



#### UNITED STATES

[www.omega.com](http://www.omega.com)

1-800-TC-OMEGA  
Stamford, CT.

#### CANADA

[www.omega.ca](http://www.omega.ca)

Laval(Quebec)  
1-800-TC-OMEGA

#### GERMANY

[www.omega.de](http://www.omega.de)

Deckenfronn, Germany  
0800-8266342

#### UNITED KINGDOM

[www.omega.co.uk](http://www.omega.co.uk)

Manchester, England  
0800-488-488  
+44-(0)161-777-6611

#### FRANCE

[www.omega.fr](http://www.omega.fr)

0800-466-342

#### BENELUX

[www.omega.nl](http://www.omega.nl)

0800-099-33-44



## More than 100,000 Products Available!

### • Temperature

Calibrators, Connectors, General Test and Measurement Instruments, Handheld Instruments for Temperature Measurement, Ice Point References, Indicating Labels, Crayons, Cements and Lacquers, Infrared Temperature Measurement Instruments, Recorders, Relative Humidity Measurement Instruments, PT100 Probes, PT100 Elements, Temperature & Process Meters, Timers and Counters, Temperature and Process Controllers and Power Switching Devices, Thermistor Elements, Probes and Assemblies, Thermocouples, Thermowells and Head and Well Assemblies, Transmitters, Thermocouple Wire, RTD Probes

### • Flow and Level

Air Velocity Indicators, Doppler Flowmeters, Level Measurement, Magnetic Flowmeters, Mass Flowmeters, Pitot Tubes, Pumps, Rotameters, Turbine and Paddle Wheel Flowmeters, Ultrasonic Flowmeters, Valves, Variable Area Flowmeters, Vortex Shedding Flowmeters

### • pH and Conductivity

Conductivity Instrumentation, Dissolved Oxygen Instrumentation, Environmental Instrumentation, pH Electrodes and Instruments, Water and Soil Analysis Instrumentation

### • Data Acquisition

Communication Products and Converters, Data Acquisition and Analysis Software, Data Loggers, Plug-in Cards, Signal Conditioners, USB, RS232, RS485, Ethernet and Parallel Port Data Acquisition Systems, Wireless Transmitters and Receivers

### • Pressure, Strain and Force

Displacement Transducers, Dynamic Measurement Force Sensors, Instrumentation for Pressure and Strain Measurements, Load Cells, Pressure Gauges, Pressure Reference Section, Pressure Switches, Pressure Transducers, Proximity Transducers, Regulators, Pressure Transmitters, Strain Gauges, Torque Transducers, Valves

### • Heaters

Band Heaters, Cartridge Heaters, Circulation Heaters, Comfort Heaters, Controllers, Meters and Switching Devices, Flexible Heaters, General Test and Measurement Instruments, Heater Hook-up Wire, Heating Cable Systems, Immersion Heaters, Process Air and Duct, Heaters, Radiant Heaters, Strip Heaters, Tubular Heaters