



Extruder RTD Probes With Compression Fittings

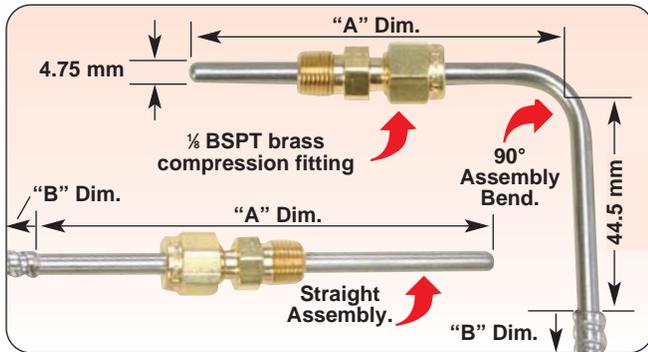

- ✓ Ideal for Plastic Process Machinery
- ✓ 100 Ω Class "A" DIN Platinum Element
- ✓ 4.75 mm Diameter, 304 Stainless Steel Sheath
- ✓ 1/8 BSPT Brass Compression Fitting Standard
- ✓ 1.5 m Flex Cable With BX Armour Standard
- ✓ Temperature Range to 260°C Continuous (Optional 480°C Cable Available)


Starts at
£61

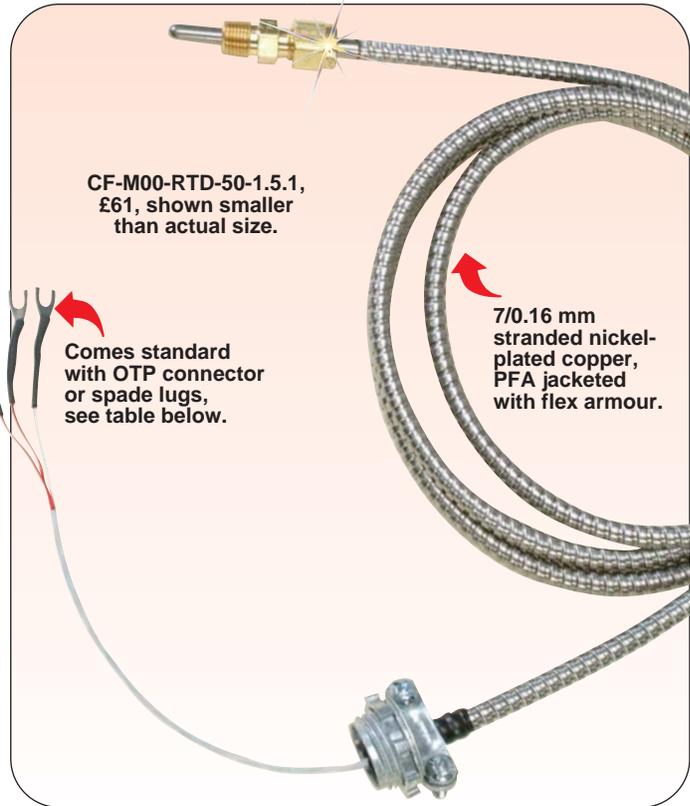

MOST POPULAR MODEL HIGHLIGHTED!

To Order (Specify Model Number)				
Model Number	Termination	Bend	"A" Dimension	Price
CF-M00-RTD-50-1.5-1	Spade lugs	Straight	50 mm	£61
CF-M00-RTD-50-1.5-2	OTP connector	Straight	50 mm	63
CF-M00-RTD-100-1.5-1	Spade lugs	Straight	100 mm	61
CF-M00-RTD-100-1.5-2	OTP connector	Straight	100 mm	63
CF-M90-RTD-50-1.5-1	Spade lugs	90°	50 mm	62
CF-M90-RTD-50-1.5-2	OTP connector	90°	50 mm	64
CF-M90-RTD-100-1.5-1	Spade lugs	90°	100 mm	62
CF-M90-RTD-100-1.5-2	OTP connector	90°	100 mm	64

Ordering Example: CF-M00-RTD-50-1.5-1, straight compression style, 1.5 m cable with lug terminations, £61.
 * For other lengths of armoured cable, change "1.5" in model number to length desired and add £7.50 per metre over 1.5 m (60").
 ** Other A lengths available, price £7 per 50 mm over 150 mm.

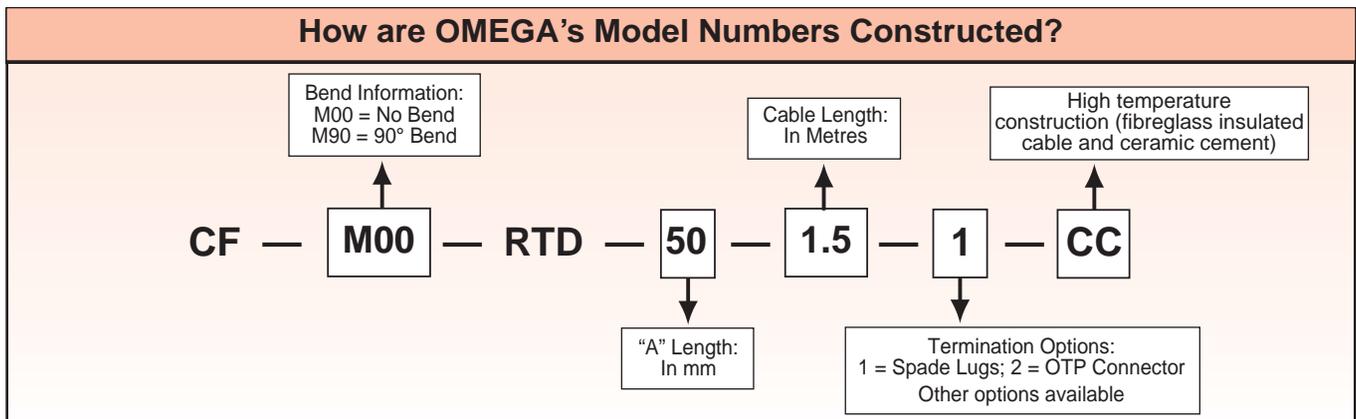

Ordering Example: CF-M00-RTD-50-1.5-1, £61.



UNITED STATES

www.omega.com

1-800-TC-OMEGA

Stamford, CT.

CANADA

www.omega.ca

Laval(Quebec)

1-800-TC-OMEGA

GERMANY

www.omega.de

Deckenpfronn, Germany

0800-8266342

UNITED KINGDOM

www.omega.co.uk

Manchester, England

0800-488-488

FRANCE

www.omega.fr

088-466-342

CZECH REPUBLIC

www.omegaeng.cz

Karviná, Czech Republic

596-311-899

BENELUX

www.omega.nl

0800-099-33-44



More than 100,000 Products Available!

• Temperature

Calibrators, Connectors, General Test and Measurement Instruments, Handheld Instruments for Temperature Measurement, Ice Point References, Indicating Labels, Crayons, Cements and Lacquers, Infrared Temperature Measurement Instruments, Recorders, Relative Humidity Measurement Instruments, PT100 Probes, PT100 Elements, Temperature & Process Meters, Timers and Counters, Temperature and Process Controllers and Power Switching Devices, Thermistor Elements, Probes and Assemblies, Thermocouples, Thermowells and Head and Well Assemblies, Transmitters, Thermocouple Wire, RTD Probes

• Flow and Level

Air Velocity Indicators, Doppler Flowmeters, Level Measurement, Magnetic Flowmeters, Mass Flowmeters, Pitot Tubes, Pumps, Rotameters, Turbine and Paddle Wheel Flowmeters, Ultrasonic Flowmeters, Valves, Variable Area Flowmeters, Vortex Shedding Flowmeters

• pH and Conductivity

Conductivity Instrumentation, Dissolved Oxygen Instrumentation, Environmental Instrumentation, pH Electrodes and Instruments, Water and Soil Analysis Instrumentation

• Data Acquisition

Auto-Dialers and Alarm Monitoring Systems, Communication Products and Converters, Data Acquisition and Analysis Software, Data Loggers Plug-in Cards, Signal Conditioners, USB, RS232, RS485 and Parallel Port Data Acquisition Systems, Wireless Transmitters and Receivers

• Pressure, Strain and Force

Displacement Transducers, Dynamic Measurement Force Sensors, Instrumentation for Pressure and Strain Measurements, Load Cells, Pressure Gauges, Pressure Reference Section, Pressure Switches, Pressure Transducers, Proximity Transducers, Regulators, Pressure Transmitters, Strain Gauges, Torque Transducers, Valves

• Heaters

Band Heaters, Cartridge Heaters, Circulation Heaters, Comfort Heaters, Controllers, Meters and Switching Devices, Flexible Heaters, General Test and Measurement Instruments, Heater Hook-up Wire, Heating Cable Systems, Immersion Heaters, Process Air and Duct, Heaters, Radiant Heaters, Strip Heaters, Tubular Heaters