

Ceramic Kiln Thermocouples Industrial Probe Assembly with Ceramic Sheath




NB12-CP Series
Starts at
£65



- ✓ For Furnaces, Kilns and Other High Temperature Applications
- ✓ Types R and S with Recrystallised Alumina Sheaths, Rated to 1600°C
- ✓ Types K and N with Aluminous Porcelain Sheaths, Rated to 1400°C
- ✓ 12 mm Diameter Ceramic Sheath with 21mm OD Support tube, 100mm long
- ✓ IP67 Rated Industrial Protection Head with Cable Entry and Screw Terminal Block
- ✓ Cast Iron Mounting Flange available
- ✓ Rugged 20 Gauge Wire for Increased Life

These thermocouple assemblies are available from stock with the dimensions shown in the "to order" table below. Other dimensions and configurations are available on request, with short delivery times.

The 100 mm long stainless steel support tube attaches the ceramic sheath to the industrial head and is included in the overall sheath length. A cast iron mounting flange with two 8.6 mm diameter mounting holes on 70 mm centres clamps the protection tube for ease of mounting at the required depth.

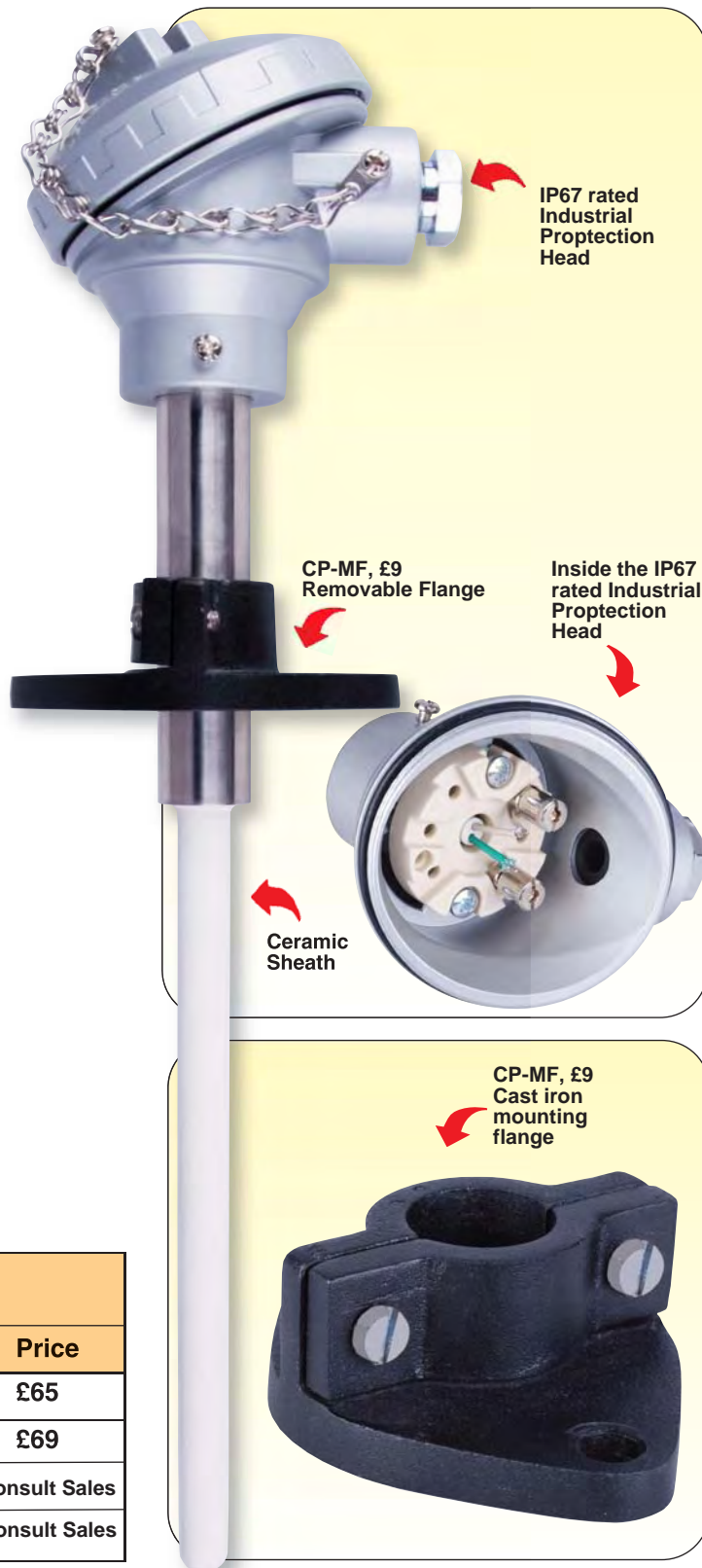

To Order (Specify Model Number)		
Model No.	Sheath Length	Price
NB12-CP-K-M12U-300	Type K 300 mm Long	£65
NB12-CP-K-M12U-600	Type K 600 mm Long	£69
NB12-CP-R-M12U-300	Type R 300 mm Long	Consult Sales
NB12-CP-R-M12U-600	Type R 600 mm Long	Consult Sales

To order type N change K in part number to N. For type S change R in part number to S.

Other sheath and cable lengths available on request. Contact sales to discuss your specific requirements.

Ordering Example: HNB12-CP-K-M12U-300 Type K ceramic probe, CP-MF mounting flange, £65 + £9 = £74.

omega.co.uk[®]

Your One-Stop Source for Process Measurement and Control!

Freephone 0800 488 488 | International +44(0) 161 777 6622 | Fax +44(0) 161 777 6622 | Sales@omega.co.uk

www.omega.co.uk



UNITED STATES

www.omega.com

1-800-TC-OMEGA
Stamford, CT.

CANADA

www.omega.ca

Laval(Quebec)
1-800-TC-OMEGA

GERMANY

www.omega.de

Deckenfronn, Germany
0800-8266342

UNITED KINGDOM

www.omega.co.uk

Manchester, England
0800-488-488
+44-(0)161-777-6611

FRANCE

www.omega.fr

0800-466-342

BENELUX

www.omega.nl

0800-099-33-44



More than 100,000 Products Available!

• Temperature

Calibrators, Connectors, General Test and Measurement Instruments, Handheld Instruments for Temperature Measurement, Ice Point References, Indicating Labels, Crayons, Cements and Lacquers, Infrared Temperature Measurement Instruments, Recorders, Relative Humidity Measurement Instruments, PT100 Probes, PT100 Elements, Temperature & Process Meters, Timers and Counters, Temperature and Process Controllers and Power Switching Devices, Thermistor Elements, Probes and Assemblies, Thermocouples, Thermowells and Head and Well Assemblies, Transmitters, Thermocouple Wire, RTD Probes

• Flow and Level

Air Velocity Indicators, Doppler Flowmeters, Level Measurement, Magnetic Flowmeters, Mass Flowmeters, Pitot Tubes, Pumps, Rotameters, Turbine and Paddle Wheel Flowmeters, Ultrasonic Flowmeters, Valves, Variable Area Flowmeters, Vortex Shedding Flowmeters

• pH and Conductivity

Conductivity Instrumentation, Dissolved Oxygen Instrumentation, Environmental Instrumentation, pH Electrodes and Instruments, Water and Soil Analysis Instrumentation

• Data Acquisition

Communication Products and Converters, Data Acquisition and Analysis Software, Data Loggers Plug-in Cards, Signal Conditioners, USB, RS232, RS485, Ethernet and Parallel Port Data Acquisition Systems, Wireless Transmitters and Receivers

• Pressure, Strain and Force

Displacement Transducers, Dynamic Measurement Force Sensors, Instrumentation for Pressure and Strain Measurements, Load Cells, Pressure Gauges, Pressure Reference Section, Pressure Switches, Pressure Transducers, Proximity Transducers, Regulators, Pressure Transmitters, Strain Gauges, Torque Transducers, Valves

• Heaters

Band Heaters, Cartridge Heaters, Circulation Heaters, Comfort Heaters, Controllers, Meters and Switching Devices, Flexible Heaters, General Test and Measurement Instruments, Heater Hook-up Wire, Heating Cable Systems, Immersion Heaters, Process Air and Duct, Heaters, Radiant Heaters, Strip Heaters, Tubular Heaters