

Standard Snap-In Panel Sockets For Type SPJ

SPJ Series
Starts at
£280

- ✓ No Installation Tools Needed
- ✓ Interlocking
- ✓ Colour-Coded
- ✓ Numbered
- ✓ Reusable
- ✓ Accepts All Mini and Standard Size Plugs
- ✓ Combination Phillips/Slot Screws

Mounting hardware has been eliminated in the SPJ-style panel socket by including retaining spring clips as part of the body design. A small tab and notch are provided to maintain straight, even rows without the need for precision matching.

SPJ colour-coded nylon connectors accept any mini or standard size thermocouple plug and are available in all IEC calibrations as well as tungsten alloys.

We make running changes when technical advances allow. Check at time of ordering for additional features.



Extra Supply of Our Patented Design Dust Caps SPJ-CAP £4/pkg of 12


Discount Schedule

1-10Net
11-2410%
25-4915%
50-9920%
100-99925%
1000 and upConsult Sales


Extra ID Number Labels:

Model 1-6L, £0.85 for 1 thru 6
 Model 1-12L, £1.00 for 1 thru 12
 Model 1-18L, £1.15 for 1 thru 18
 Model 1-24L, £1.35 for 1 thru 24
 Model 1-50L, £1.70 for 1 thru 50
 Model 1-100L, £2.00 for 1 thru 100

Aluminium Panel Not Included.
For Panel Punches,
See omega.co.uk

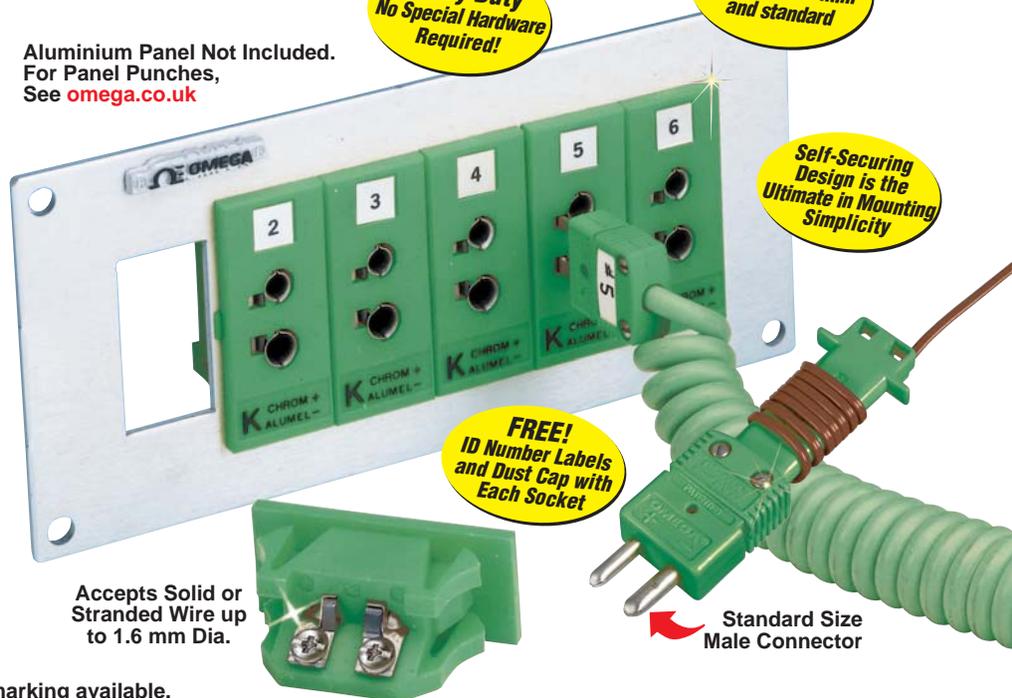

Custom marking available.
Consult Sales Department for
pricing and quantities.

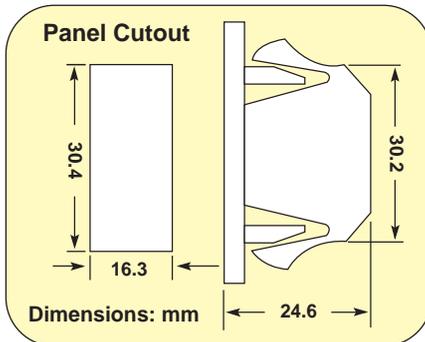

Removal Tool

Model Number SIRT-1 £10

For the large volume user who requires the ability to quickly remove installed connectors, the SIRT-1 removal tool is invaluable. Operating easily even in densely packed panels, the tool compresses all spring clips together, allowing the SPJ to be pushed out of the panel from the rear.



MOST POPULAR MODEL HIGHLIGHTED!

To Order (Specify Model Number)

Alloy Code [†]	Type of Thermocouple Used With Connector	Compensating Alloy Used in Connector		Shell Colour	Model Number (Female)	Price of Socket
		+	-			
K	CHROMEALLOY™-ALOMEALLOY™	CHROMEALLOY™	ALOMEALLOY™	Green	SPJ-KI-F	£2.80
T	Copper-Constantan	Copper	Constantan	Brown	SPJ-TI-F	2.80
J	Iron-Constantan	Iron	Constantan	Black	SPJ-J-F	2.80
E	CHROMEALLOY™-Constantan	CHROMEALLOY™	Constantan	Purple	SPJ-E-F	2.80
R,S	Pt-Pt/13%Rh	Copper	RNX/SNX	Orange	SPJ-R/SI-F	2.80
G	W-W/26%Re	GPX	GNX	Red	SPJ-G-F	7.40
C	W/5%Re-W/26%Re	CPX	CNX	Red	SPJ-C-F	7.40
D	W/3%Re-W/25%Re	DPX	DNX	Red	SPJ-D-F	7.40
U	Uncompensated	Copper	Copper	White	SPJ-U-F	2.80
N	OMEGALLOY™	OMEGA-P™	OMEGA-N™	Pink	SPJ-NI-F	2.80

[†] K, T, J, E, R, S and B are IEC designations. Also available with male pins. Change "F" in model number to "M". Example: SPJ-KI-M (same price).

Note: Type U (Uncompensated) connectors are used with type B thermocouples (Platinum/6% Rhodium-Platinum/ 30% Rhodium).

Ordering Example: SPJ-KI-F, snap-in panel socket for use with Type K thermocouple plugs, £2.80.



UNITED STATES

www.omega.com

1-800-TC-OMEGA

Stamford, CT.

CANADA

www.omega.ca

Laval(Quebec)

1-800-TC-OMEGA

GERMANY

www.omega.de

Deckenpfronn, Germany

0800-8266342

UNITED KINGDOM

www.omega.co.uk

Manchester, England

0800-488-488

FRANCE

www.omega.fr

088-466-342

CZECH REPUBLIC

www.omegaeng.cz

Karviná, Czech Republic

596-311-899

BENELUX

www.omega.nl

0800-099-33-44



More than 100,000 Products Available!

• Temperature

Calibrators, Connectors, General Test and Measurement Instruments, Handheld Instruments for Temperature Measurement, Ice Point References, Indicating Labels, Crayons, Cements and Lacquers, Infrared Temperature Measurement Instruments, Recorders, Relative Humidity Measurement Instruments, PT100 Probes, PT100 Elements, Temperature & Process Meters, Timers and Counters, Temperature and Process Controllers and Power Switching Devices, Thermistor Elements, Probes and Assemblies, Thermocouples, Thermowells and Head and Well Assemblies, Transmitters, Thermocouple Wire, RTD Probes

• Flow and Level

Air Velocity Indicators, Doppler Flowmeters, Level Measurement, Magnetic Flowmeters, Mass Flowmeters, Pitot Tubes, Pumps, Rotameters, Turbine and Paddle Wheel Flowmeters, Ultrasonic Flowmeters, Valves, Variable Area Flowmeters, Vortex Shedding Flowmeters

• pH and Conductivity

Conductivity Instrumentation, Dissolved Oxygen Instrumentation, Environmental Instrumentation, pH Electrodes and Instruments, Water and Soil Analysis Instrumentation

• Data Acquisition

Auto-Dialers and Alarm Monitoring Systems, Communication Products and Converters, Data Acquisition and Analysis Software, Data Loggers Plug-in Cards, Signal Conditioners, USB, RS232, RS485 and Parallel Port Data Acquisition Systems, Wireless Transmitters and Receivers

• Pressure, Strain and Force

Displacement Transducers, Dynamic Measurement Force Sensors, Instrumentation for Pressure and Strain Measurements, Load Cells, Pressure Gauges, Pressure Reference Section, Pressure Switches, Pressure Transducers, Proximity Transducers, Regulators, Pressure Transmitters, Strain Gauges, Torque Transducers, Valves

• Heaters

Band Heaters, Cartridge Heaters, Circulation Heaters, Comfort Heaters, Controllers, Meters and Switching Devices, Flexible Heaters, General Test and Measurement Instruments, Heater Hook-up Wire, Heating Cable Systems, Immersion Heaters, Process Air and Duct, Heaters, Radiant Heaters, Strip Heaters, Tubular Heaters