

Thermocouple Extension Cables With Molded Connectors

Starts at
\$15




- ✓ Retractable Cable in 1 and 4' Lengths with 5:1 Stretch
- ✓ 24 Gage (0.020" Dia.) PFA Coated or Glass Overbraid Stranded Wire in 10 and 25' Lengths
- ✓ Molded Quick Disconnect or Subminiature Thermocouple Connectors for Low Cost
- ✓ Available in J, K, T and E Calibrations

To order extension cables, specify desired connector combination from chart below

Style Number	Connector #1	Connector #2
1	OSTW, female	OSTW, female
2	OSTW, female	OST, male
3	OSTW, female	SMPW, female
4	OSTW, female	SMP, male
5	OST, male	OST, male
6	OST, male	SMPW, female
7	OST, male	SMP, male
8	SMPW, female	SMPW, female
9	SMPW, female	SMP, male
10	SMP, male	SMP, male
11	OSTW, female	Stripped leads
12	OST, male	Stripped leads
13	SMPW, female	Stripped leads
14	SMP, male	Stripped leads
15	OSTW, female	Spade lug
16	OST, male	Spade lug
17	SMPW, female	Spade lug
18	SMP, male	Spade lug

Note: OST and OSTW connectors are standard size; SMP and SMPW connectors are subminiature size. All male connectors will be molded onto the wire with a molded strain relief.

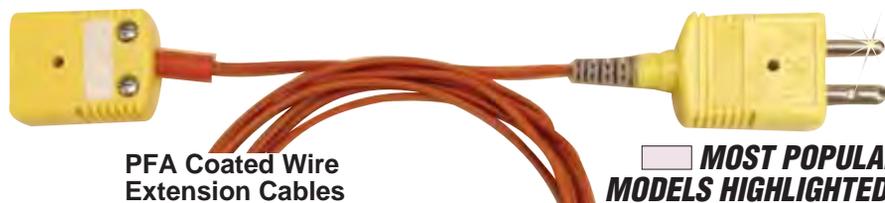

Shown smaller than actual size.

PFA Coated Wire Extension Cables

MOST POPULAR MODELS HIGHLIGHTED!

Model No.	Price	Calibration	Length
TECJ10-(*)	\$15	J Iron-Constantan	3 m (10')
TECJ25-(*)	30		7.5 m (25')
TECK10-(*)	15	K CHROME [®] GA-ALOMEGA [®]	3 m (10')
TECK25-(*)	30		7.5 m (25')
TECT10-(*)	15	T Copper-Constantan	3 m (10')
TECT25-(*)	30		7.5 m (25')
TECE10-(*)	15	E CHROME [®] GA-Constantan	3 m (10')
TECE25-(*)	30		7.5 m (25')

* Insert connector code from chart. Constructed from 24 gage stranded wire.



Shown smaller than actual size.

Glass Braid Wire Extension Cables

Model No.	Price	Calibration	Length
GECJ10-(*)	\$15	J Iron-Constantan	3 m (10')
GECJ25-(*)	30		7.5 m (25')
GECK10-(*)	15	K CHROME [®] GA-ALOMEGA [®]	3 m (10')
GECK25-(*)	30		7.5 m (25')
GECT10-(*)	15	T Copper Constantan	3 m (10')
GECT25-(*)	30		7.5 m (25')
GECE10-(*)	15	E CHROME [®] GA-Constantan	3 m (10')
GECE25-(*)	30		7.5 m (25')

* Insert connector code from chart. Constructed from 24 gage stranded wire.

Retractable Extension Cables

Model No.	Price	Calibration	Length
RECJ1-(*)	\$18.50	J Iron-Constantan	30 cm (1')
RECJ4-(*)	33.50		120 cm (4')
RECK1-(*)	18.50	K CHROME [®] GA-ALOMEGA [®]	30 cm (1')
RECK4-(*)	33.50		120 cm (4')
RECT1-(*)	18.50	T Copper-Constantan	30 cm (1')
RECT4-(*)	33.50		120 cm (4')
RECE1-(*)	18.50	E CHROME [®] GA-Constantan	30 cm (1')
RECE4-(*)	33.50		120 cm (4')

* Insert connector code from chart.

Note: Retractable cables are expandable 5:1, so one foot will expand to 5' in length. **Ordering Example:** RECK1-9, retractable extension cable, SMPW subminiature male or female, \$18.50.

Shown smaller than actual size.

omega.co.uk[®]

Your One-Stop Source for Process Measurement and Control!

Freephone 0800 488 488 | International +44(0) 161 777 6622 | Fax +44(0) 161 777 6622 | Sales@omega.co.uk

www.omega.co.uk



UNITED STATES

www.omega.com

1-800-TC-OMEGA
Stamford, CT.

CANADA

www.omega.ca

Laval(Quebec)
1-800-TC-OMEGA

GERMANY

www.omega.de

Deckenfronn, Germany
0800-8266342

UNITED KINGDOM

www.omega.co.uk

Manchester, England
0800-488-488
+44-(0)161-777-6611

FRANCE

www.omega.fr

0800-466-342

BENELUX

www.omega.nl

0800-099-33-44



More than 100,000 Products Available!

• Temperature

Calibrators, Connectors, General Test and Measurement Instruments, Handheld Instruments for Temperature Measurement, Ice Point References, Indicating Labels, Crayons, Cements and Lacquers, Infrared Temperature Measurement Instruments, Recorders, Relative Humidity Measurement Instruments, PT100 Probes, PT100 Elements, Temperature & Process Meters, Timers and Counters, Temperature and Process Controllers and Power Switching Devices, Thermistor Elements, Probes and Assemblies, Thermocouples, Thermowells and Head and Well Assemblies, Transmitters, Thermocouple Wire, RTD Probes

• Flow and Level

Air Velocity Indicators, Doppler Flowmeters, Level Measurement, Magnetic Flowmeters, Mass Flowmeters, Pitot Tubes, Pumps, Rotameters, Turbine and Paddle Wheel Flowmeters, Ultrasonic Flowmeters, Valves, Variable Area Flowmeters, Vortex Shedding Flowmeters

• pH and Conductivity

Conductivity Instrumentation, Dissolved Oxygen Instrumentation, Environmental Instrumentation, pH Electrodes and Instruments, Water and Soil Analysis Instrumentation

• Data Acquisition

Communication Products and Converters, Data Acquisition and Analysis Software, Data Loggers Plug-in Cards, Signal Conditioners, USB, RS232, RS485, Ethernet and Parallel Port Data Acquisition Systems, Wireless Transmitters and Receivers

• Pressure, Strain and Force

Displacement Transducers, Dynamic Measurement Force Sensors, Instrumentation for Pressure and Strain Measurements, Load Cells, Pressure Gauges, Pressure Reference Section, Pressure Switches, Pressure Transducers, Proximity Transducers, Regulators, Pressure Transmitters, Strain Gauges, Torque Transducers, Valves

• Heaters

Band Heaters, Cartridge Heaters, Circulation Heaters, Comfort Heaters, Controllers, Meters and Switching Devices, Flexible Heaters, General Test and Measurement Instruments, Heater Hook-up Wire, Heating Cable Systems, Immersion Heaters, Process Air and Duct, Heaters, Radiant Heaters, Strip Heaters, Tubular Heaters